


# CUSTOM TRAY

Tray Code	RENESAS Code	Previous Code
PT816AM	PRQP0080GD-A	FP-80 / FP-80V
	PRQP0080GD-B	FP-80B / FP-80BV
	PRQP0100JE-A	FP-100 / FP-100V
	PRQP0100JE-B	FP-100A / FP-100AV
	PRQP0100JF-A	FP-100L / FP-100LV

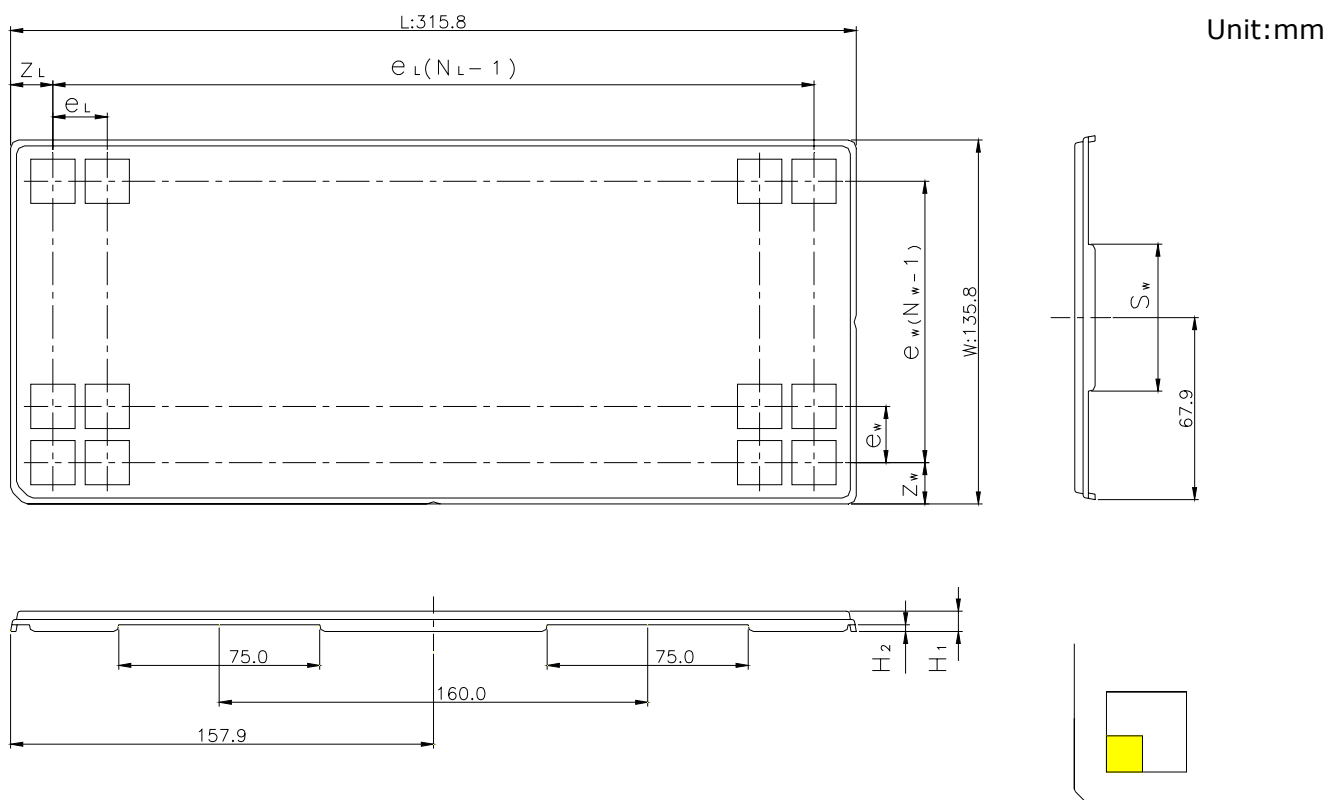

The pin1 is located in the hatching portion

Position dimension of cells (mm)	$Z_w$	17.9
	$Z_L$	18.4
	$e_w$	25
	$e_L$	31
	$S_w$	25
Thickness (mm)	$H_1$	7.6
	$H_2$	2.5
Number of cells	$N_w$	5
	$N_L$	10
Maximum storage No. IC/Tray		50
Maximum storage No. IC/Inner box		500
Material		Carbon PS
Surface resistance		Less than $1 \times 10^{11} \Omega / \square$
Heat resistant temperature		125°C24h
Packing form		Dry pack