


JEDEC TRAY

Tray Code	RENESAS Code	Previous Code
L196-76A	PRBG0297FA-A	297F7X-A
	PRBG0345FA-A	345F7X-A
	PRBG0345FB-A	345FHP
	PRBG0441FA-A	441FHP

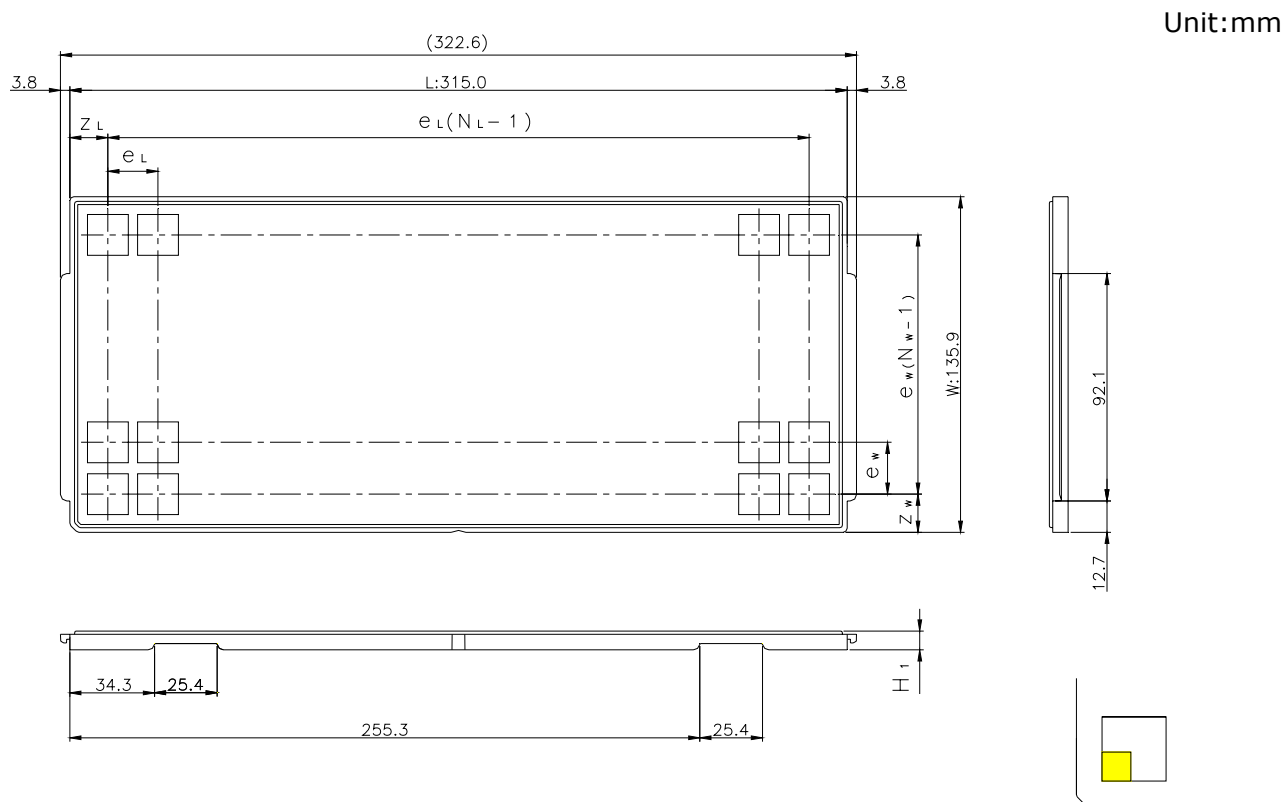

The pin1 is located in the hatching portion

Note : Numbers in parentheses are the numbers of ICs contained in five trays per inner box, and those without parentheses are the numbers of ICs contained in eight trays per inner box.

Position dimension of cells (mm)	Z _w	16.95
	Z _L	17.25
	e _w	25.5
	e _L	25.5
Thickness (mm)	H ₁	7.62
Number of cells	N _w	5
	N _L	12
Maximum storage No. IC/Tray		60
Maximum storage No. IC/Inner box (Note)		480(300)
Material		Carbon PPE
Surface resistance		Less than 1x10 ¹¹ Ω/□
Heat resistant temperature		125°C24h
Packing form		Dry pack