


TRAY

Tray code	RENESAS Code	Previous Code
L196-93	PTSB0032DA-A	32P3Y-H
	PTSB0032DA-B	32P3Y-J
	PTSB0032DC-A	32PTY-A

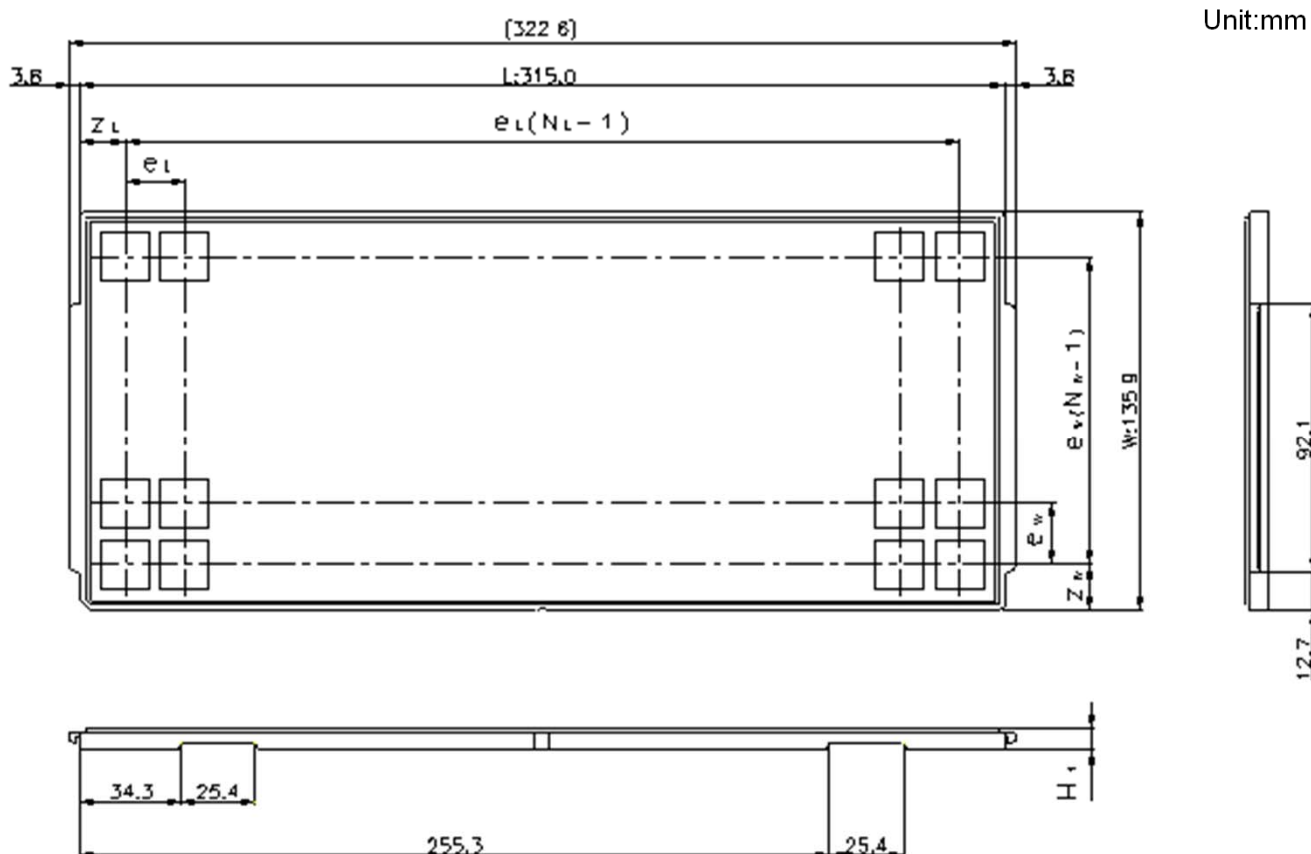

Note : Numbers in parentheses are the numbers of ICs contained in five trays per inner box, and those without parentheses are the numbers of ICs contained in eight trays per inner box.

Position dimension of cells (mm)	Z_w	13.27
	Z_L	19.74
	e_w	13.67
	e_L	22.96
Thickness (mm)	H_1	7.62
Number of cells	N_w	9
	N_L	13
Maximum storage No. IC/Tray		117
Maximum storage No. IC/Inner box (Note)		936(585)
Material		Carbon PPE
Surface resistance		Less than $1 \times 10^{11} \Omega/\square$
Heat resistant temperature		125°C24h
Packing form		Dry pack

The pin1 is located in the hatching portion

