


JEITA Package Code	RENESAS Code	Previous Code	MASS (TYP.) [g]
P-HFQFP208-28x28-0.50	PRQP0208KG-E	P208GD-50-WML	5

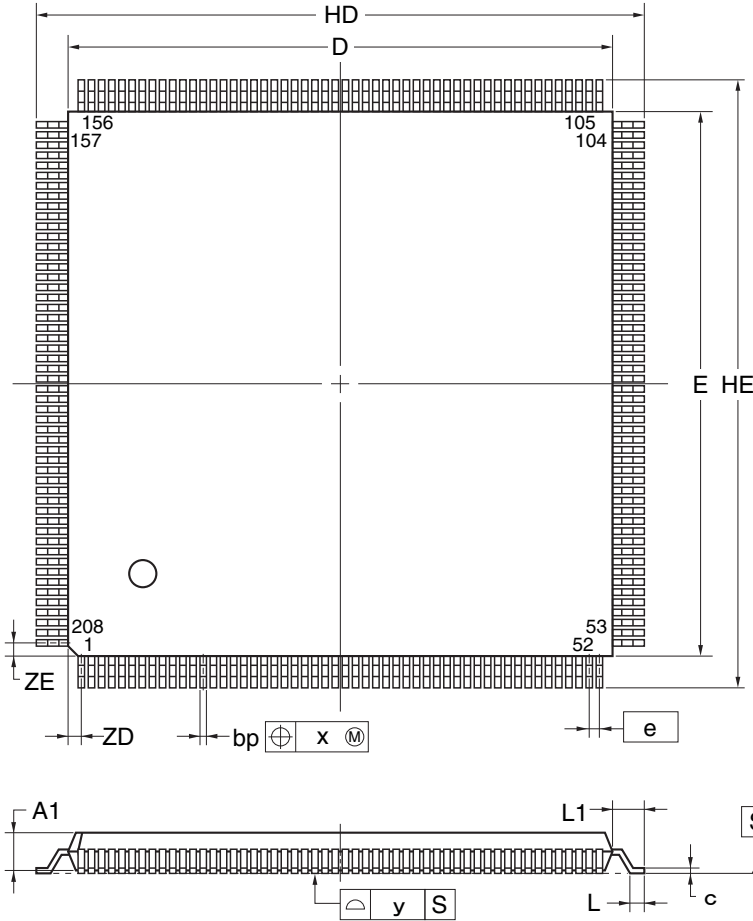

detail of lead end

(UNIT:mm)

ITEM	DIMENSIONS
D	28.00±0.20
E	28.00±0.20
HD	30.60±0.20
HE	30.60±0.20
A	3.80 MAX.
A1	0.40±0.10
A2	3.20±0.10
bp	0.22 <sup>+0.05</sup> <sub>-0.04</sub>
c	0.17 <sup>+0.03</sup> <sub>-0.07</sub>
L	0.50±0.20
L1	1.30±0.20
θ	5°±5°
e	0.50
x	0.10
y	0.10
ZD	1.25
ZE	1.25

**NOTE**

Each lead centerline is located within 0.10 mm of its true position (T.P.) at maximum material condition.