
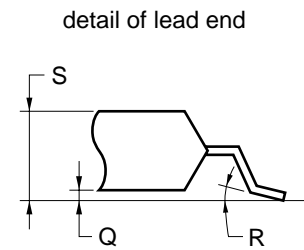


# 120-PIN PLASTIC QFP (28x28)

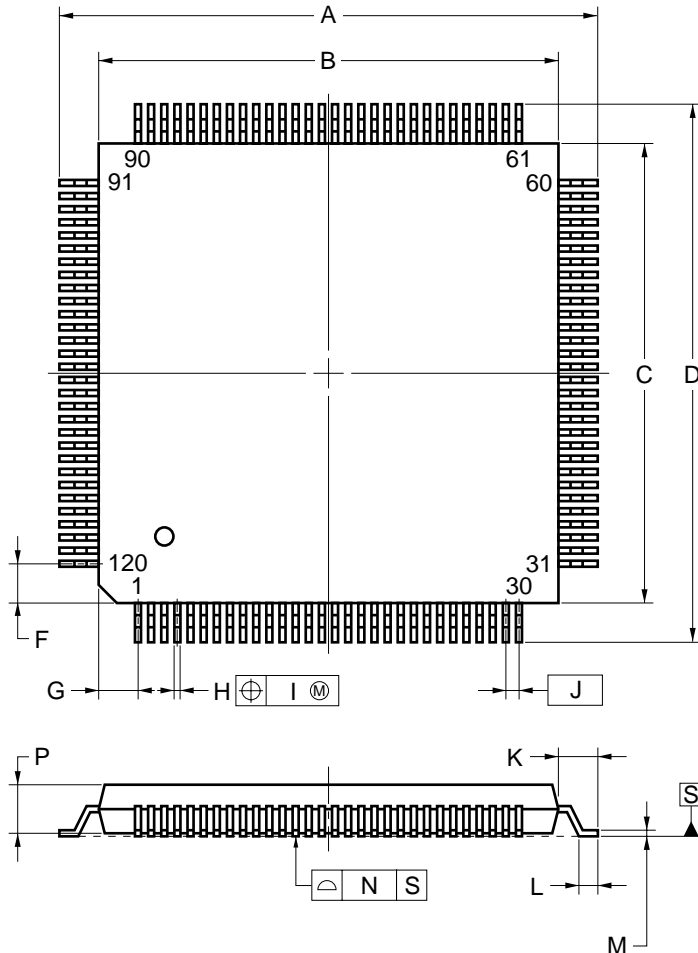

## NOTE

Each lead centerline is located within 0.15 mm of its true position (T.P.) at maximum material condition.

ITEM	MILLIMETERS
A	32.0±0.4
B	28.0±0.2
C	28.0±0.2
D	32.0±0.4
F	2.4
G	2.4
H	0.35±0.10
I	0.15
J	0.8 (T.P.)
K	2.0±0.2
L	0.8±0.2
M	0.15 <sup>+0.10</sup> <sub>-0.05</sub>
N	0.10
P	3.7
Q	0.1±0.1
R	5°±5°
S	4.0 MAX.

P120GD-80-5BB-4