
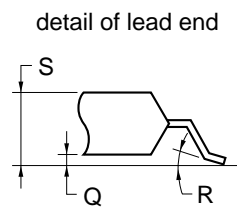


## 208-PIN PLASTIC QFP (40x40)

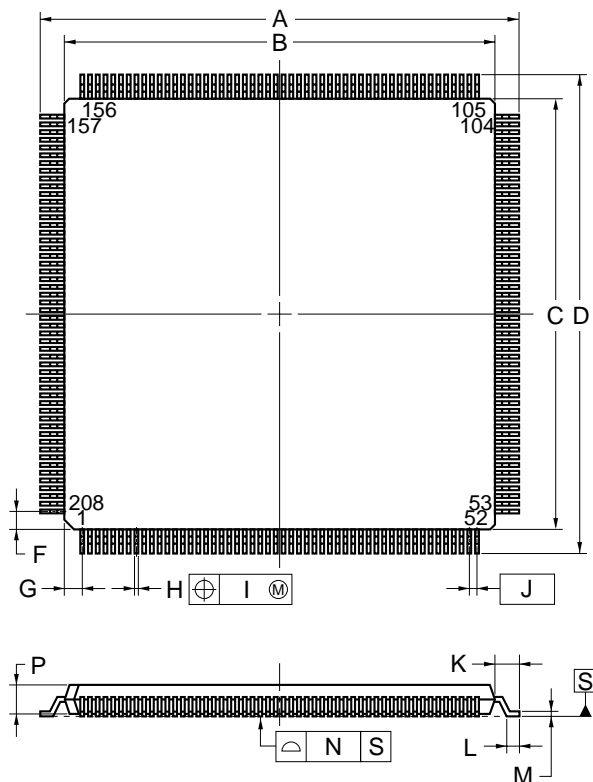

### NOTE

Each lead centerline is located within 0.15 mm of its true position (T.P.) at maximum material condition.

ITEM	MILLIMETERS
A	43.2±0.4
B	40.0±0.2
C	40.0±0.2
D	43.2±0.4
F	3.4
G	3.4
H	0.30±0.10
I	0.15
J	0.65 (T.P.)
K	1.6±0.2
L	0.8±0.2
M	0.15 $\begin{matrix} +0.10 \\ -0.05 \end{matrix}$
N	0.10
P	4.2
Q	0.4±0.1
R	5°±5°
S	4.8 MAX.

S208GL-65-6GL-2