

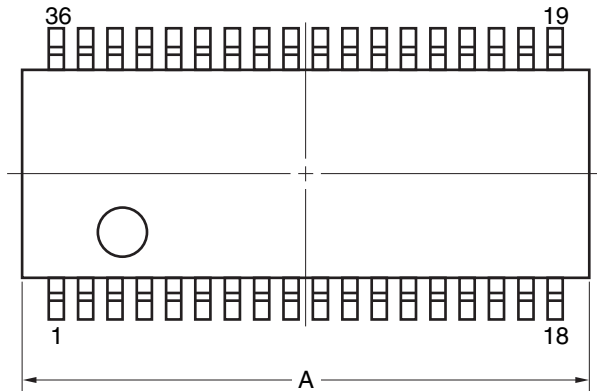
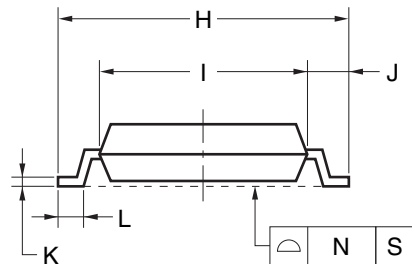


JEITA Package Code	RENESAS Code	Previous Code	MASS (TYP.) [g]
P-SSOP36-0300-0.80	PRSP0036GD-A	P36GM-80-300B-7	0.34

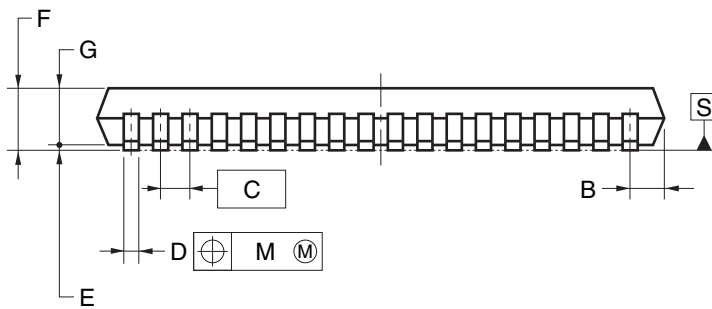

detail of lead end

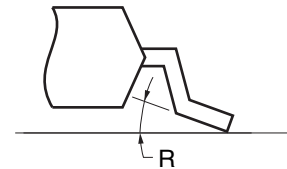

(UNIT:mm)

ITEM	DIMENSIONS
A	15.3±0.24
B	0.97 MAX.
C	0.8 (T.P.)
D	0.37 <sup>+0.08</sup> <sub>-0.07</sub>
E	0.125±0.075
F	1.675 <sup>+0.125</sup> <sub>-0.175</sub>
G	1.55
H	7.7±0.3
I	5.6±0.15
J	1.05±0.2
K	0.22 <sup>+0.08</sup> <sub>-0.07</sub>
L	0.6±0.2
M	0.10
N	0.10
R	5°±5°

**NOTE**

Each lead centerline is located within 0.10 mm of its true position (T.P.) at maximum material condition.