


### 32-PIN PLASTIC TSOP (II) (10.16mm(400))

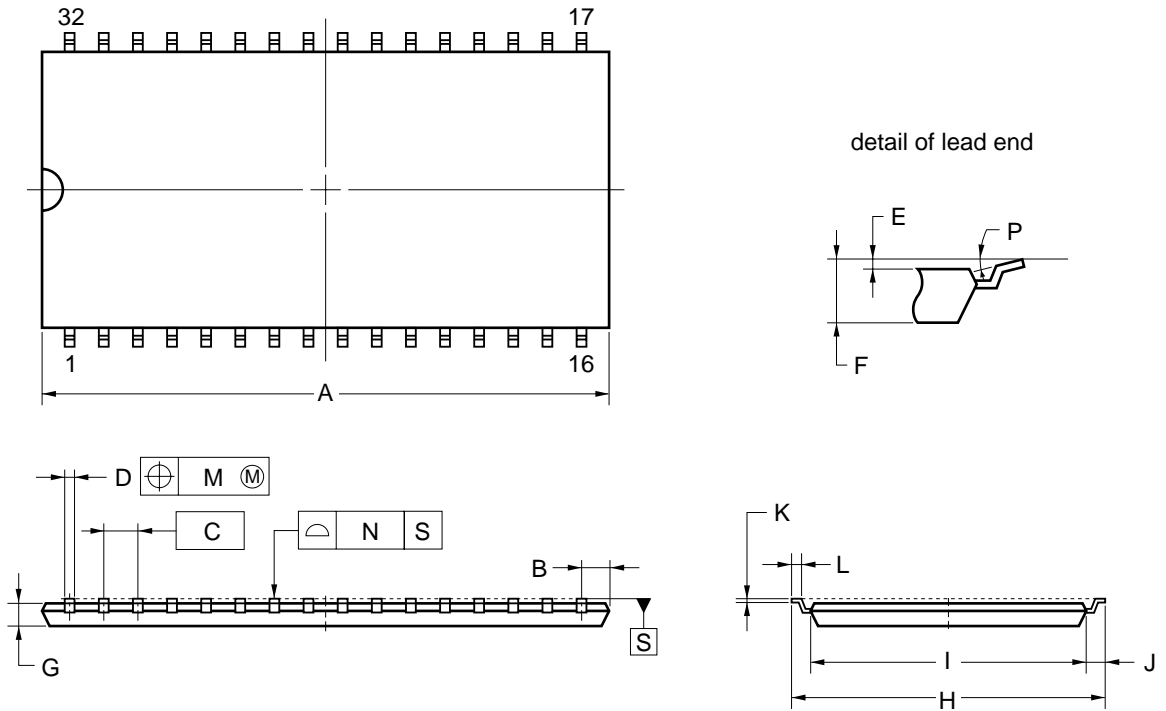

**NOTE**

Each lead centerline is located within 0.21 mm of its true position (T.P.) at maximum material condition.

| ITEM | MILLIMETERS                               |
|------|---|
| A    | 21.17 MAX.                                |
| B    | 1.075 MAX.                                |
| C    | 1.27 (T.P.)                               |
| D    | 0.42 <sup>+0.08</sup> <sub>-0.07</sub>    |
| E    | 0.1±0.05                                  |
| F    | 1.2 MAX.                                  |
| G    | 0.97                                      |
| H    | 11.76±0.2                                 |
| I    | 10.16±0.1                                 |
| J    | 0.8±0.2                                   |
| K    | 0.145 <sup>+0.025</sup> <sub>-0.015</sub> |
| L    | 0.5±0.1                                   |
| M    | 0.21                                      |
| N    | 0.10                                      |
| P    | 3° <sup>+7°</sup> <sub>-3°</sub>          |

S32G5-50-7KD2-1