

PQFN Tape and Reel Information


Table of Contents

- **1. GEN III 8X8mm PQFN TAPE & REEL INFORMATION 2**
 - Part I: Product Orientation 2
 - Part II: Carrier Tape Dimension 3
 - Part III: Reel Dimension 3
 - Part IV: Box Size 4
 - Part V: Package POD for LDG Version 5
 - Part VI: Package POD for LSG Version & Laser Marking Sample 6
 - Part VII: Tape and Reel Packing Information 8
 - Part VIII: Internal Shipping Box Information..... 9
 - Part IX: External Shipping Box Information 10
- **2. GEN IV 8X8mm PQFN TAPE & REEL INFORMATION 12**
 - Part I: Performance Product Orientation 12
 - Part II: Industry Standard Product Orientation 12
 - Part III: Carrier Tape Dimension..... 13
 - Part IV: Reel Dimension..... 14
 - Part V: Box Size 14
 - Part VI: Package POD for Performance Version & Laser Marking Sample 16
 - Part VII: Package POD for Industry Standard Version & Laser Marking 17
 - Part VIII: Tape and Reel Packaging Information..... 18
 - Part IX: Internal Shipping Box Information 19
 - Part X: External Shipping Box Information..... 19
- **3. GEN IV 5X6mm PQFN TAPE & REEL INFORMATION 22**
 - Part I: Performance Product Orientation 22
 - Part II: Industry Standard Product Orientation 22
 - Part III: Carrier Tape Dimension..... 23
 - Part IV: Reel Dimension..... 24
 - Part V: Box Size 24
 - Part VI: Package POD for Performance Version & Laser Marking Sample 25
 - Part VII: Package POD for Industry Standard LSGB Version & Laser Marking 27
 - Part VIII: Tape and Reel Packing Information 28
 - Part IX: Internal Shipping Box Information 28
 - Part X: External Shipping Box Information..... 29
- **4. TO-220 Shipping Information..... 32**
 - Part I: Shipping Tube..... 32
 - Part II: Tube Quantity 32
 - Part III: Box Size 34
 - Part IV: Internal Shipping Box Information 34

- Part V: External Shipping Box Information 35
- Part VI: Assembly Lot Number Information 37
- **5. TO-247 Shipping Information..... 37**
 - Part I: Shipping Tube 37
 - Part II: Tube Quantity 38
 - Part III: Box Size 39
 - Part IV: Internal Shipping Box Information 40
 - Part V: External Shipping Box Information 40
 - Part VI: Assembly Lot Number Information 42
- **6. TOLL TAPE & REEL INFORMATION..... 42**
 - Part I: Product Orientation 43
 - Part II: Carrier Tape Dimension 44
 - Part III: Reel Dimension 44
 - Part IV: Box Dimension..... 45
 - Part V: Package POD 46
 - Part VI: Tape and Reel Packing Information..... 48
 - Part VII: Internal Shipping Box Information..... 48
 - Part VIII: External Shipping Box Information 49


1. GEN III 8X8mm PQFN TAPE & REEL INFORMATION

Part I: Product Orientation

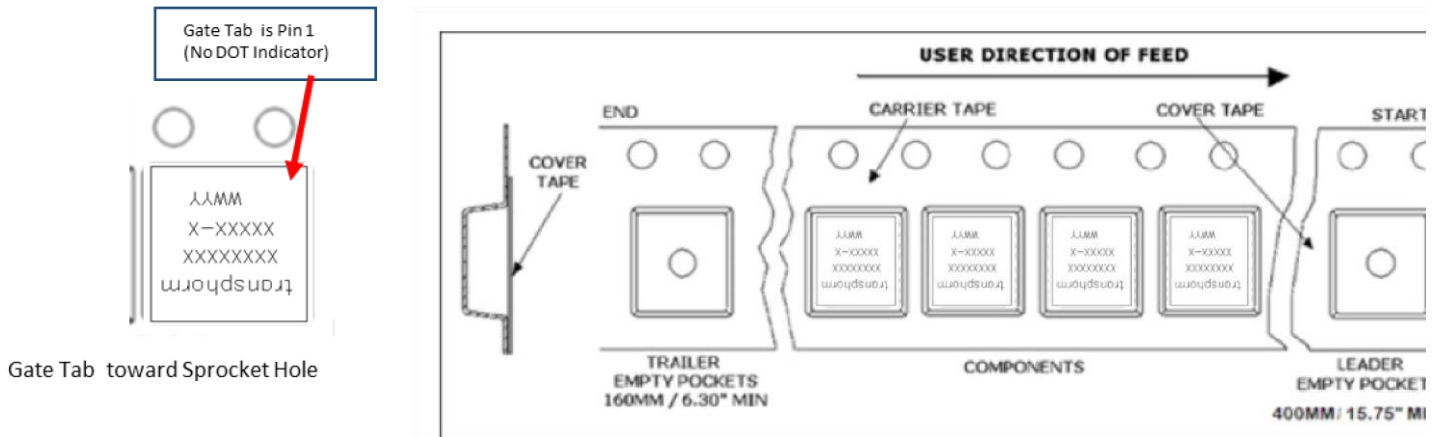

- Leader Empty Pockets: 400mm / 15.75" min
- Trailer Empty Pockets: 160mm / 6.30" min
 - Quantity per Reel: 500pcs

• Part II: Carrier Tape Dimension

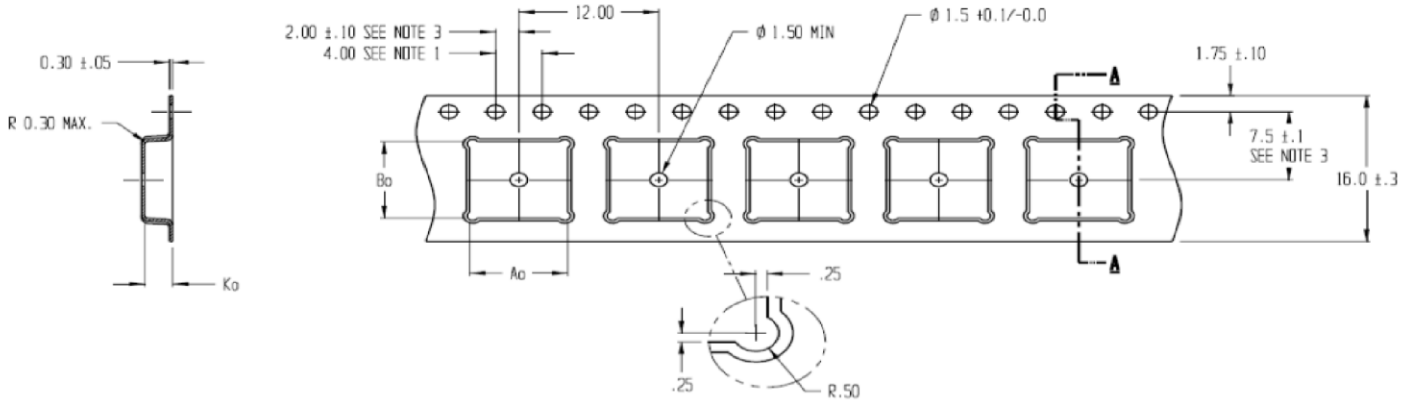

$A_o = 8.40$

$B_o = 8.40$

$K_o = 2.40$


Notes:

- 10 Sprocket Hole pitch cumulative tolerance ± 0.2
- Camber in compliance with EIA 481

- Pocket position relative to Sprocket Hole measured as true position of Pocket not Pocket Hole

• Part III: Reel Dimension


- Reel Size: 178mm

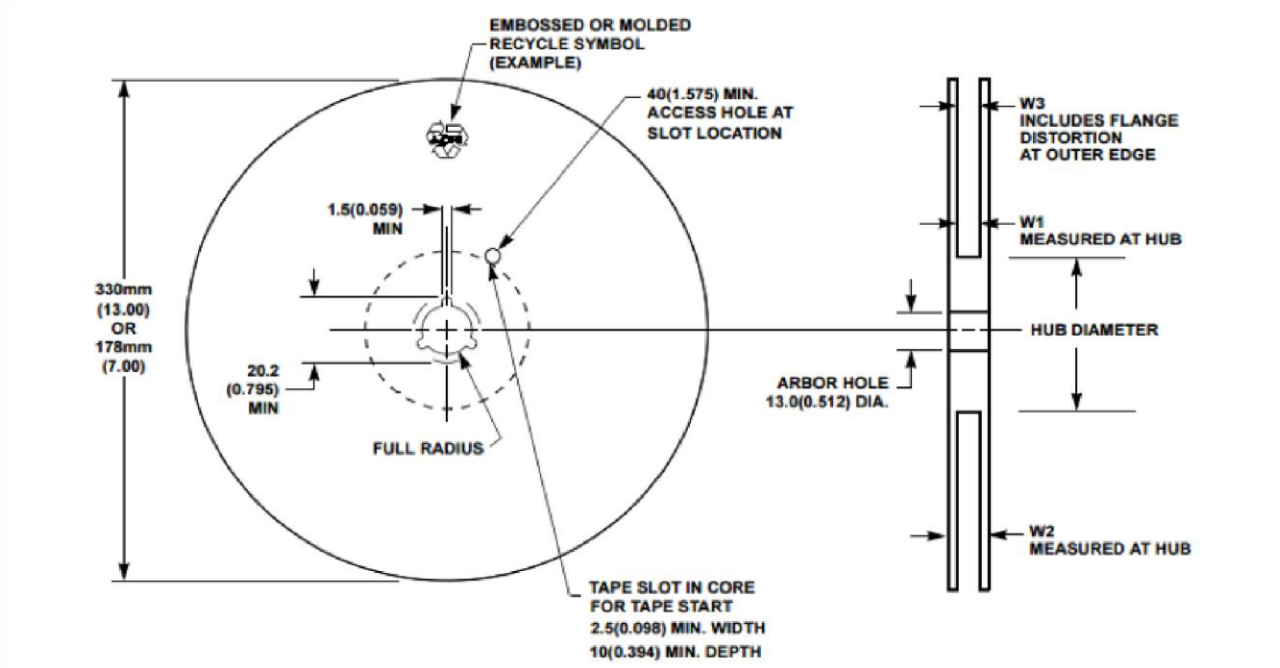

TAPE WIDTH	W1 (NOMINAL)	W2 (MAXIMUM)	W3 (MAXIMUM)
8mm (0.315)	8.4 (0.331)	14.4 (0.567)	10.9 (0.429)
12mm (0.472)	12.4 (0.488)	18.4 (0.724)	15.4 (0.606)
16mm (0.629)	16.4 (0.646)	22.4 (0.882)	19.4 (0.764)
24mm (0.945)	24.4 (0.961)	30.4 (1.197)	27.4 (1.079)
32mm (1.260)	32.4 (1.276)	38.4 (1.512)	35.4 (1.394)
44mm (1.732)	44.4 (1.748)	50.4 (1.984)	47.4 (1.866)



Dimensions are in millimeters (inches are in brackets for reference only).

- Part IV: Box Size

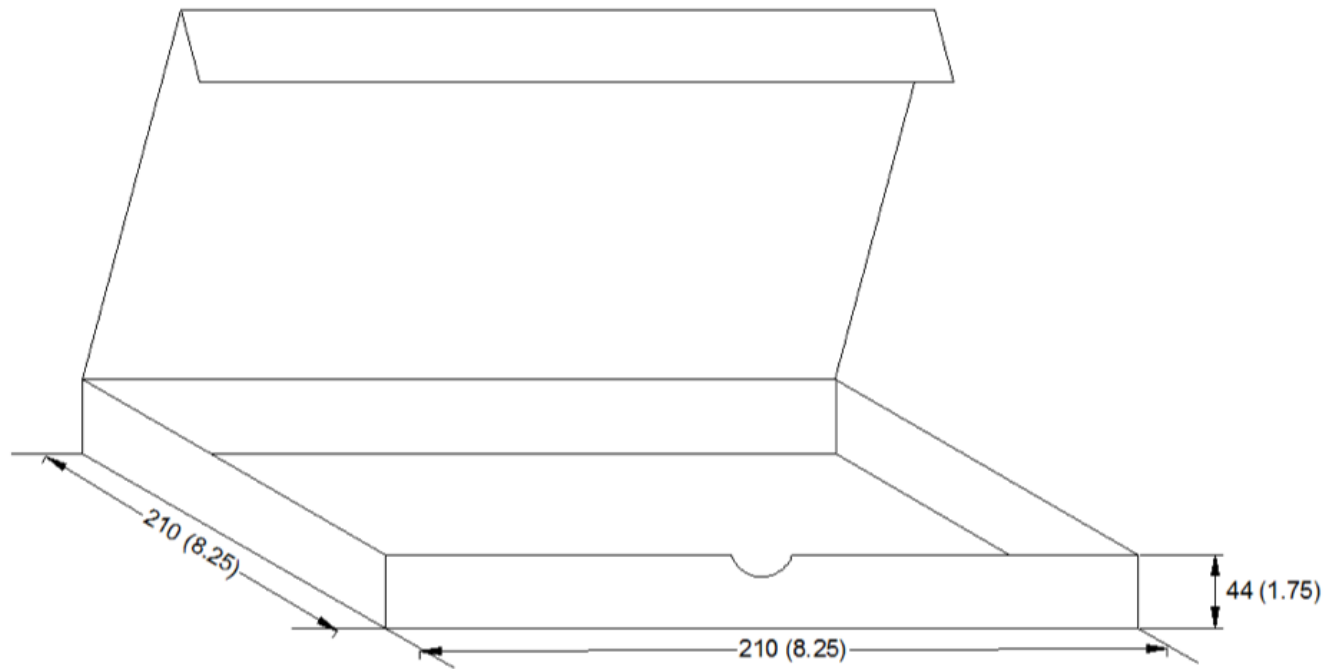

Dimensions are in millimeters (inches are in brackets for reference only).

- Part V: Package POD for LDG Version

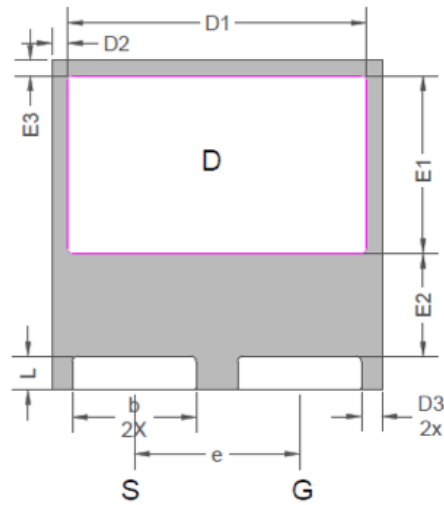
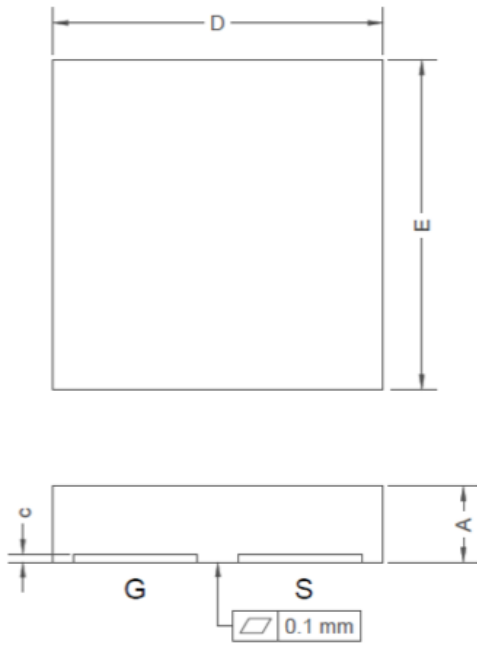


G: Gate
 S: Source
 D: Drain
 Lead finish: Sn plating

DIM	mm		inch	
	min	max	min	max
A	1.73	1.97	0.068	0.078
b	2.90	3.10	0.114	0.122
c	0.10	0.30	0.004	0.012
D	7.90	8.10	0.311	0.319
D1	7.11	7.37	0.280	0.290
E	7.90	8.10	0.311	0.319
E1	4.18	4.44	0.165	0.175
E2	2.40	2.60	0.094	0.102
E3/D2	0.28	0.48	0.011	0.019
D3	0.45	0.55	0.018	0.022
e	4.00 (BSC)		0.157 (BSC)	
L	0.76	0.86	0.030	0.034

PQFN 8mm x 8mm POD (TPHxxxxLDG)

- Part VI: Package POD for LSG Version & Laser Marking Sample

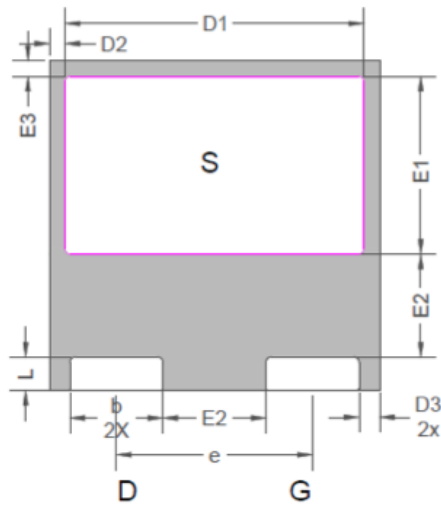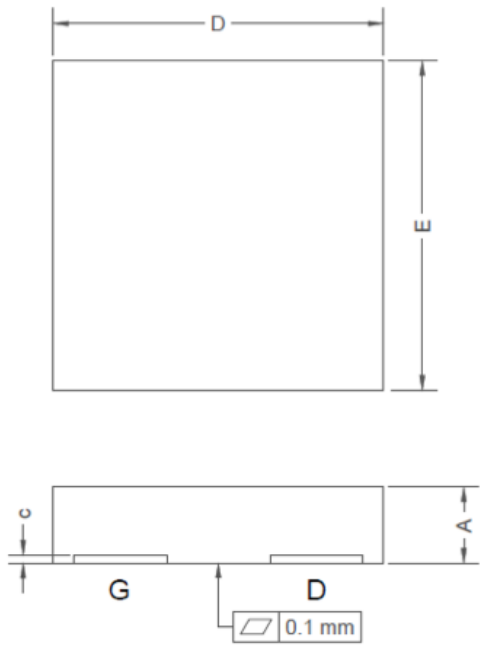


G: Gate
 S: Source
 D: Drain
 Lead finish: Sn plating

DIM	mm		inch	
	min	max	min	max
A	1.73	1.97	0.068	0.078
b	2.15	2.35	0.085	0.093
c	0.10	0.30	0.004	0.012
D	7.90	8.10	0.311	0.319
D1	7.11	7.37	0.280	0.290
E	7.90	8.10	0.311	0.319
E1	4.18	4.44	0.165	0.175
E2	2.40	2.60	0.094	0.102
E3/D2	0.28	0.48	0.011	0.019
D3	0.45	0.55	0.018	0.022
e	4.75 (BSC)		0.187 (BSC)	
L	0.76	0.86	0.030	0.034

PQFN 8mm x 8mm POD (TPHxxxxLSG)

Laser Marking Sample

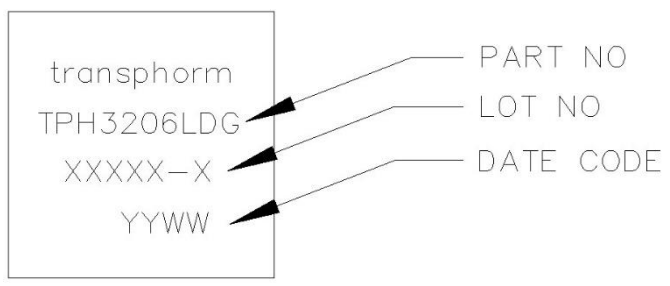

TOP MARKING (LASER)


- Part VII: Tape and Reel Packing Information



Tape and Reel Shielding Bag


- 500units/reel
- Maximum 1 reel/box
- Place Tape and Reel inside moisture barrier bag
- Seal moisture bag

- Part VIII: Internal Shipping Box Information

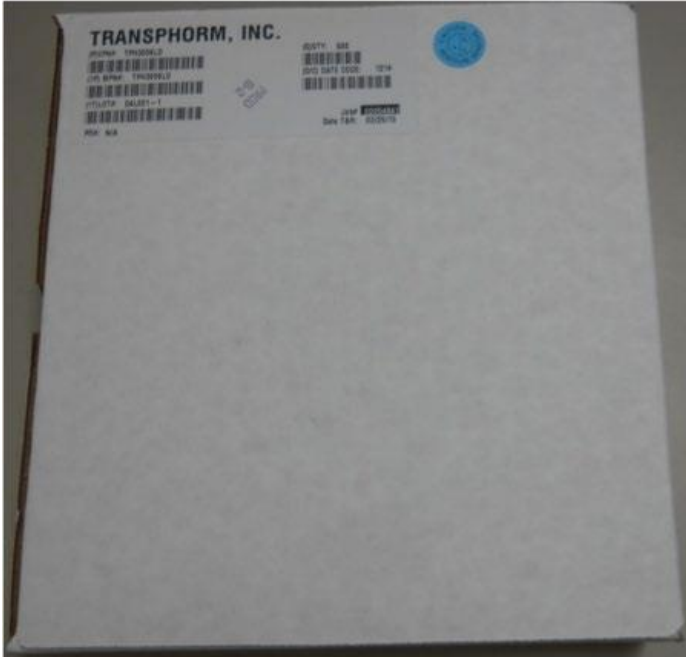

Internal Shipping Box

- Tape internal box closed using ESD Label.
- Place Internal Shipping Label.

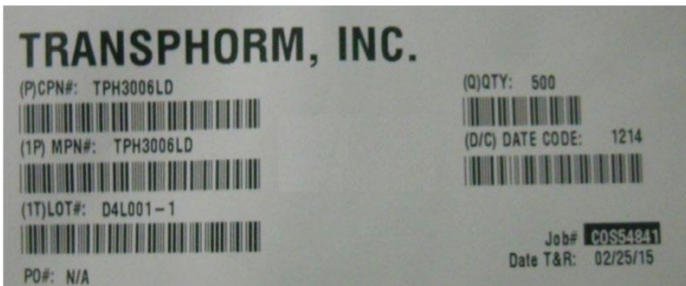

- Internal Shipping Box Label

CPN: Customer Part Number

MPN: Renesas Part Number

Lot #: Assembly Lot Number

QTY: Quantity contained inside the

box

D/C: Date Code

Job #: Tape and Reel job number

Date T&R: Bag seal date

• Part IX: External Shipping Box Information



External Shipping Box Label

From: Renesas shipping address

To: Customer name, address attention to, and phone number

Customer PO: Customer Purchase Order Number

Customer P/N: Customer Part Number

Quantity: Total product quantity contain in external shipping box

Renesas P/N: Renesas Product Number





Country of Origin: Country of Origin where product was manufactured

Package Count: Number of External Shipping Boxes contained in shipment

Package Weight: Weight of packed External Shipping

External Shipping Box

- Internal Shipping Boxes inside External Shipping Box.
- Number of Internal Boxes ranges from 3 to 5.
- Place External Shipping Label.



From: Transphorm, Inc. 115 Castilian Drive Goleta, CA 93117	
To: Customer Name Customer Address Line 1 Customer Address Line 2 City & Zip Code	
ATTN: Customer Name Attention TO Customer ATTN TO phone number	
Customer PO:  CUSTOMER 123-A	
Customer P/N:  HEMT-120	
QTY:  1000	
Transphorm P/N:  TPH3205WS	
<u>Country of Origin</u> PH	
<u>Package Count</u> X of X	<u>Package Weight</u> x.x lbs / x.xx kg

Box

Shipping Box Size and Weight



Shipment	Units	Weight	Size	Comments
1 box	500pcs	0.8 (lbs) 0.363 (kgs)		FedEx Shipping box
3 boxes	1500pcs	2.4 (lbs) 1.09 (kgs)	12 in x 12 in x 12 in 304.8mm x 304.8mm x 304.8mm	
4 boxes	2000pcs	3.2 (lbs) 1.45 (kgs)	12 in x 12 in x 12 in 304.8mm x 304.8mm x 304.8mm	
5 boxes	2500pcs	4.0 (lbs) 1.81 (kgs)	12 in x 12 in x 12 in 304.8mm x 304.8mm x 304.8mm	

- 2. GEN IV 8X8mm PQFN TAPE & REEL INFORMATION
- Part I: Performance Product Orientation

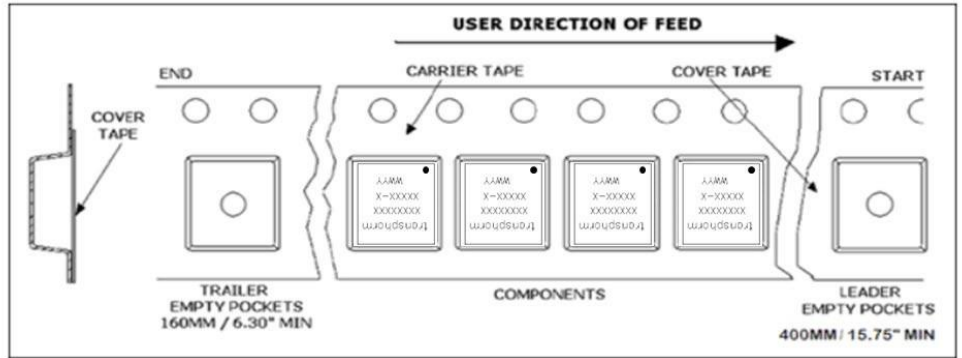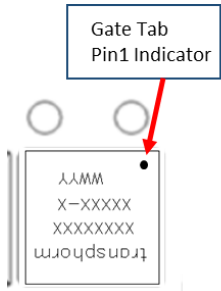


- Leader Empty Pockets: 77
- Trailer Empty Pockets: 37
- Quantity per Reel: 3,000pcs

- Part II: Industry Standard Product Orientation

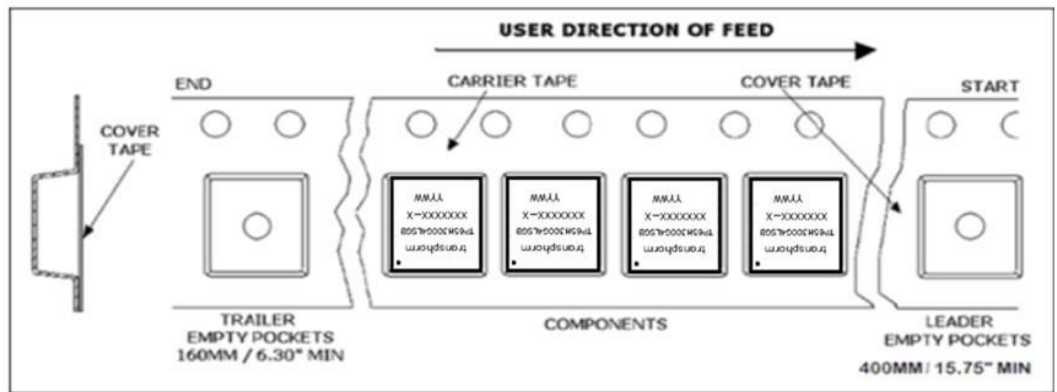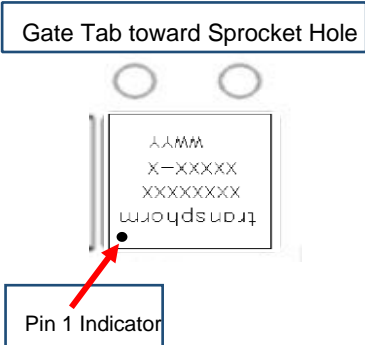

- Leader Empty Pockets: 77
- Trailer Empty Pockets: 37
- Quantity per Reel: 3,000pcs

Part III: Carrier Tape Dimension

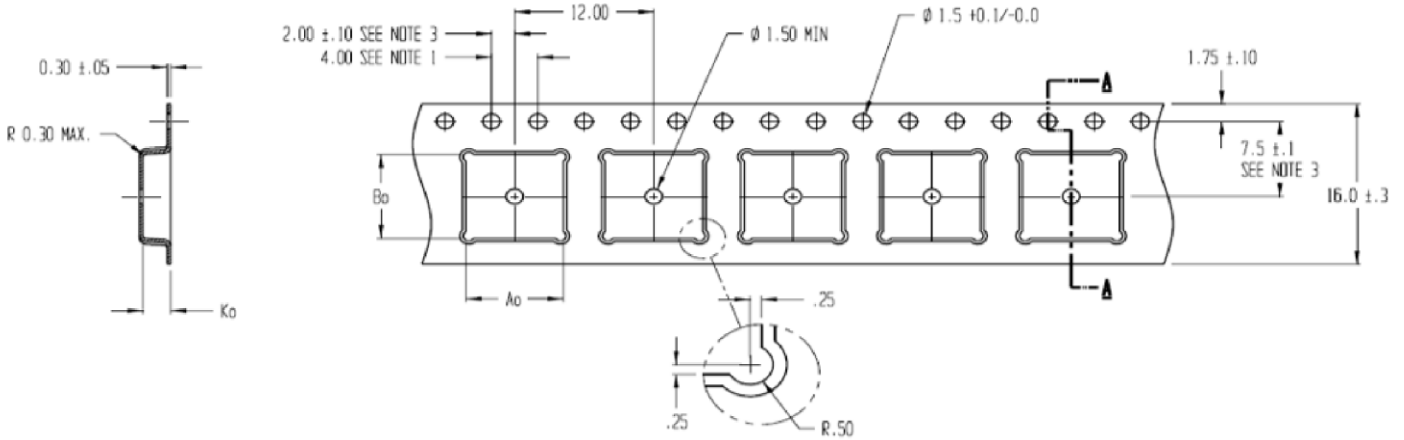

$A_o = 8.40$

Notes:

$B_o = 8.40$

- 10 Sprocket Hole pitch cumulative tolerance ± 0.2 $K_o = 1.20$ •


Camber in compliance with EIA 481

- Pocket position relative to Sprocket Hole measured as true position of Pocket not Pocket Hole

Application Note

Part IV: Reel Dimension


- Reel Size: 330mm

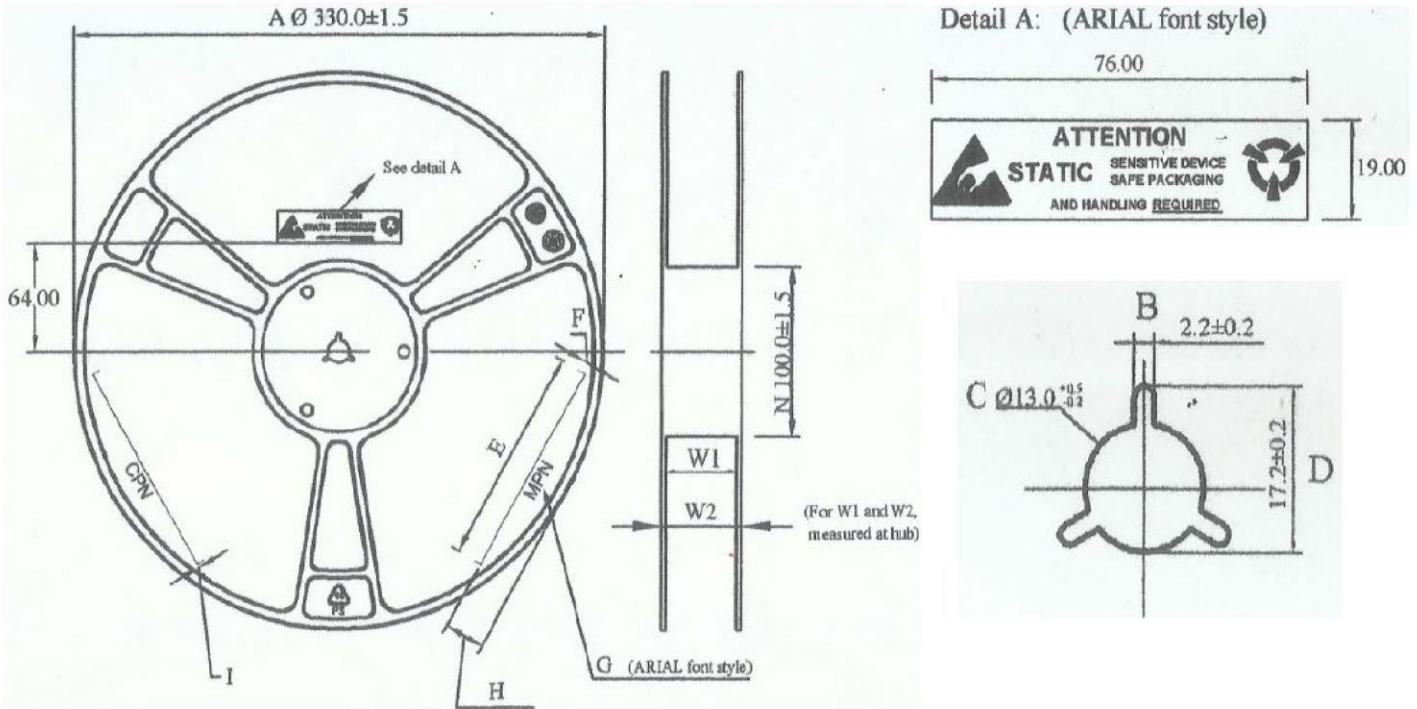

PRODUCT NAME	U-PAK P/N	W1	W2 (Max)	E	F	G	H	I
13" 100*12mm Plastic Reel	MUR-223-BX	12.40 ^{+0.20} _{-0.0}	18.40	130 ± 1.0	5 ± 1.0	8 ± 1.0	25 ± 1.0	0.4 ± 0.5




Color based on customer requirement.
 Material: HIPS (High Impact Polystyrene)
 Need Ultrasonic Welding.
 Surface Resistance: $10^7 \sim 10^{11} \ \Omega/\square$
 All dimensions in millimeters unless otherwise specified.
 Text with ARIAL font style.

Part V: Box Size

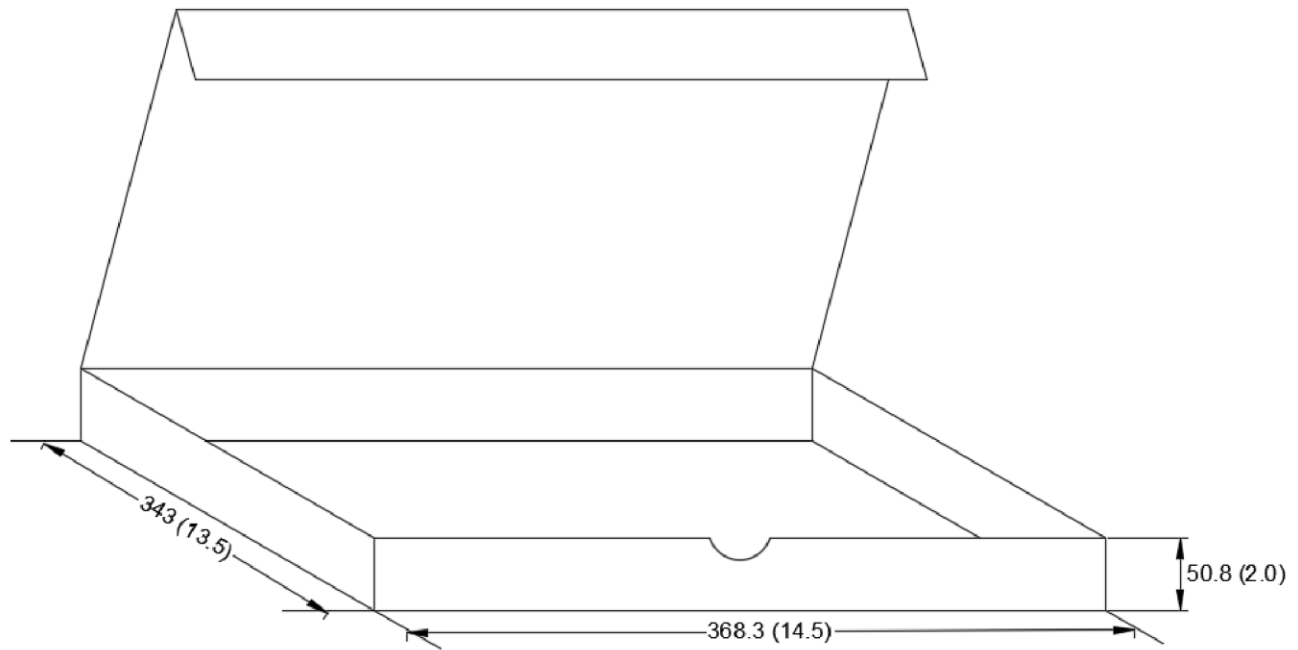

Dimensions are in millimeter (inches are in brackets for reference only)

• Part VI: Package POD for Performance Version & Laser Marking Sample

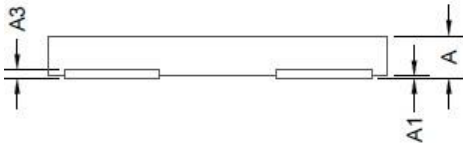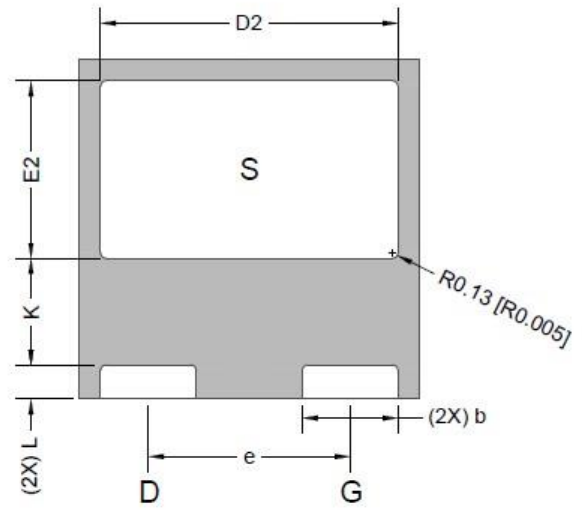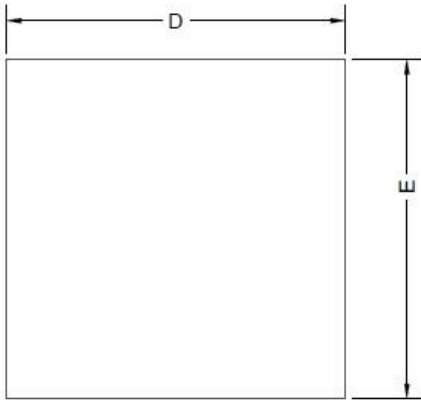


G: Gate
 S: Source
 D: Drain
 Lead finish: Sn plating



DIM	mm			inch		
	MIN	NOM	MAX	MIN	NOM	MAX
A	0.90	1.00	1.10	0.035	0.039	0.043
A1	0.00	-	0.05	0.000	-	0.002
A3	0.20 REF.			0.007 BSC		
b	2.20	2.25	2.30	0.087	0.089	0.091
D	7.90	8.00	8.10	0.311	0.315	0.319
D2	6.85	7.00	7.15	0.270	0.276	0.281
E	7.90	8.00	8.00	0.311	0.315	0.315
e	4.75 BSC			0.187 BSC		
E2	4.03	4.18	4.33	0.159	0.165	0.170
K	2.50	-	-	0.098	-	-
L	0.70	0.80	0.90	0.028	0.031	0.035

PQFN 8mm x 8mm POD (TP65HxxxG4LSG)


Laser Marking Sample

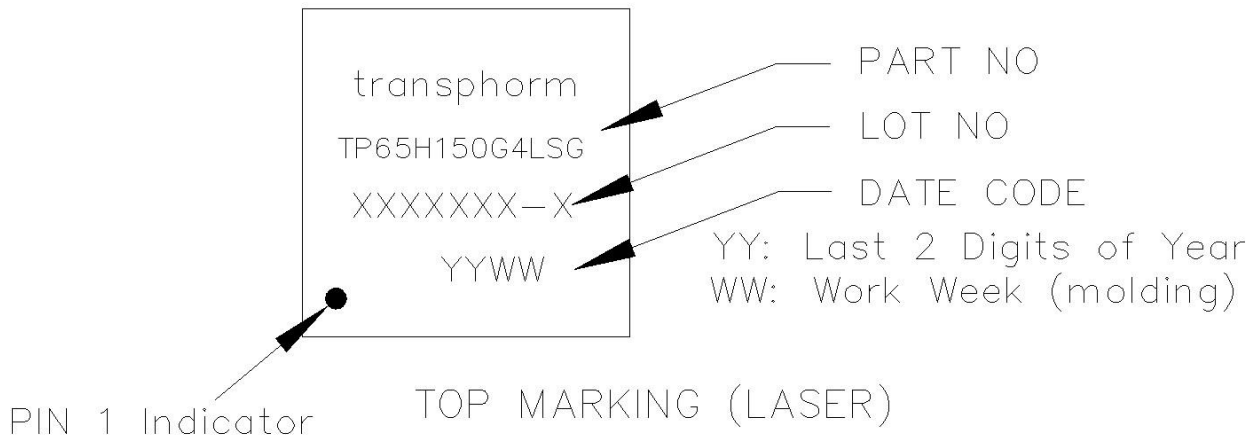

• Part VII: Package POD for Industry Standard Version & Laser Marking

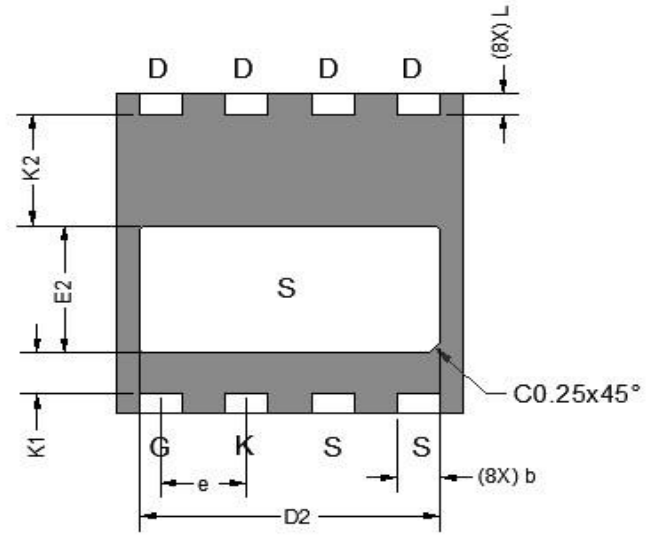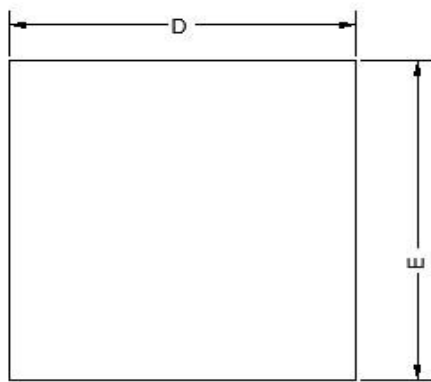


G: Gate
 S: Source
 D: Drain
 K: Kelvin
 Lead finish: Sn plating

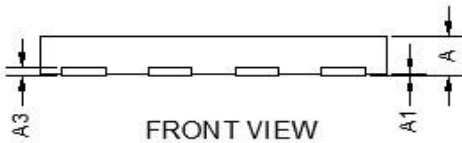

DIM	mm			inch		
	MIN	NOM	MAX	MIN	NOM	MAX
A	0.90	1.00	1.10	0.035	0.039	0.043
A1	0.00	-	0.05	0.000	-	0.002
A3	0.20 REF.			0.007 BSC		
b	0.5	1.00	1.5	0.020	0.039	0.059
D	7.90	8.00	8.10	0.311	0.315	0.319
D2	6.79	6.94	7.09	0.267	0.273	0.279
E	7.90	8.00	8.10	0.311	0.315	0.319
e	2.00 BSC			0.007 BSC		
E2	3.05	3.20	3.35	0.120	0.126	0.132
K1	1.00	-	-	0.039	-	-
K2	2.8	-	-	0.110	-	-
L	0.40	0.50	0.60	0.016	0.020	0.024

PQFN 8mm x 8mm POD (TP65HxxxG4LSGB)

Laser Marking Sample

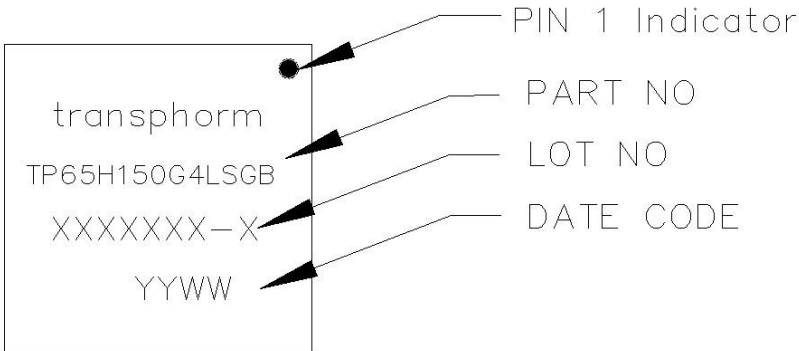

TOP MARKING (LASER)

• Part VIII: Tape and Reel Packaging Information



Tape and Reel Shielding Bag

- 3,000units/reel
- Maximum 1 reel/box
- Place Tape and Reel inside moisture barrier bag
- Seal moisture bag

- Part IX: Internal Shipping Box Information



Internal Shipping Box

- Tape internal box closed using ESD Label
- Place Internal Shipping Label



Internal Shipping Box Label

Supplier P/N: Transphorm Part Number

Quantity: Quantity contained inside the box

Date Code: YYWW

Lot Code: Assembly Lot Number

COO: Country of Origin

2D Barcode: Above information encoded

- Part X: External Shipping Box Information













External Shipping Box

- Internal Shipping Boxes inside External Shipping Box
- Number of Internal Boxes ranges from 2 to 6
- Place External Shipping Label

Application Note

External Shipping Box Label

FROM: Transphorm, Inc. 75 Castilian Drive Goleta, CA 93117	TO: Customer Name ATTN: Attention TO Customer Address Line 1 Customer Address Line 2 City & Zip Code
(K) PO Number: Sample 	
(1P) Supplier Part Number: TP65HxxxG4LSG 	
(Q) Quantity: 3000 	
(4S) Package ID: SO-1288 	
(10D) Data Code: 1452 	(4L) COO: US 
(1T) Lot Code: B9A028 	
  	

From : Renesas shipping address
 To : Customer name, Attention TO, and address number
 PO Number : Customer Purchase Order Number
 Supplier Part Number : Renesas Part Number Quantity : Total product quantity contain in external shipping box
 Package ID : Renesas Assigned Number
 Date Code: YYWW
 Lot Code: Assembly Lot Number
 COO: Country of Origin

2D Barcode: Above information encoded


Shipping Box Size and Weight

Shipment	Units	Weight	Size	Comments
1 box	3,000pcs	3.13 (lbs) 1.42 (kgs)		FedEx Shipping box
3 boxes	9,000pcs	9.39 (lbs) 4.26 (kgs)	15.25 in x 13.5 in x 15.5 in 387.35 mm x 342.9mm x 393.7mm	
4 boxes	12,000pcs	12.52 (lbs) 5.68 (kgs)	15.25 in x 13.5 in x 15.5 in 387.35 mm x 342.9mm x 393.7mm	
5 boxes	15,000pcs	15.65 (lbs) 7.10 (kgs)	15.25 in x 13.5 in x 15.5 in 387.35 mm x 342.9mm x 393.7mm	

Application Note


6-boxes	18,000pcs	18.78 (lbs) 8.52 (kgs)	15.25 in x 13.5 in x 15.5 in 387.35 mm x 342.9mm x 393.7mm
---------	-----------	---------------------------	---

- 3. GEN IV 5X6mm PQFN TAPE & REEL INFORMATION
- Part I: Performance Product Orientation

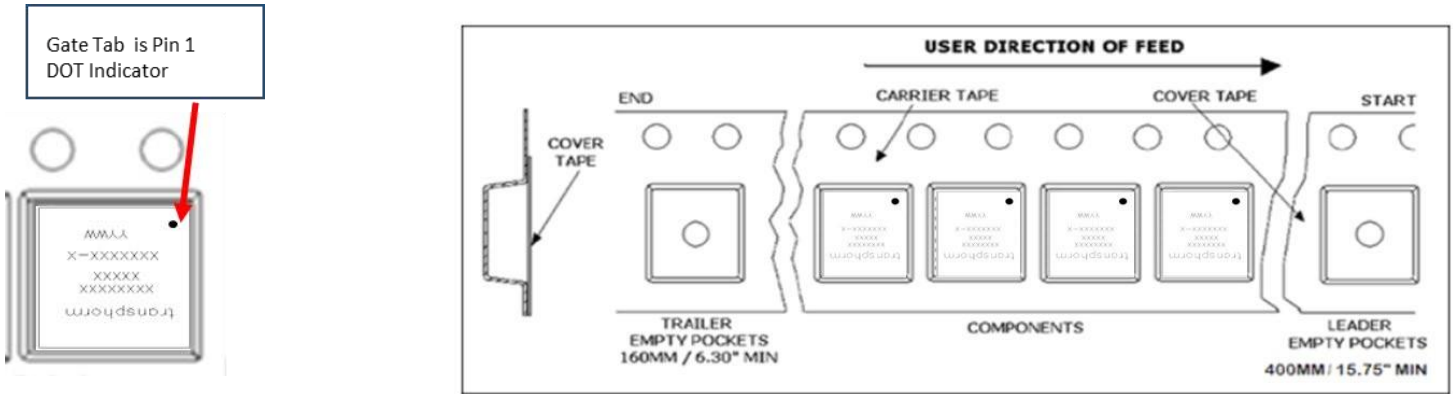


- Leader Empty Pockets: 85
- Trailer Empty Pockets: 40
- Quantity per Reel: 4,000pcs

- Part II: Industry Standard Product Orientation

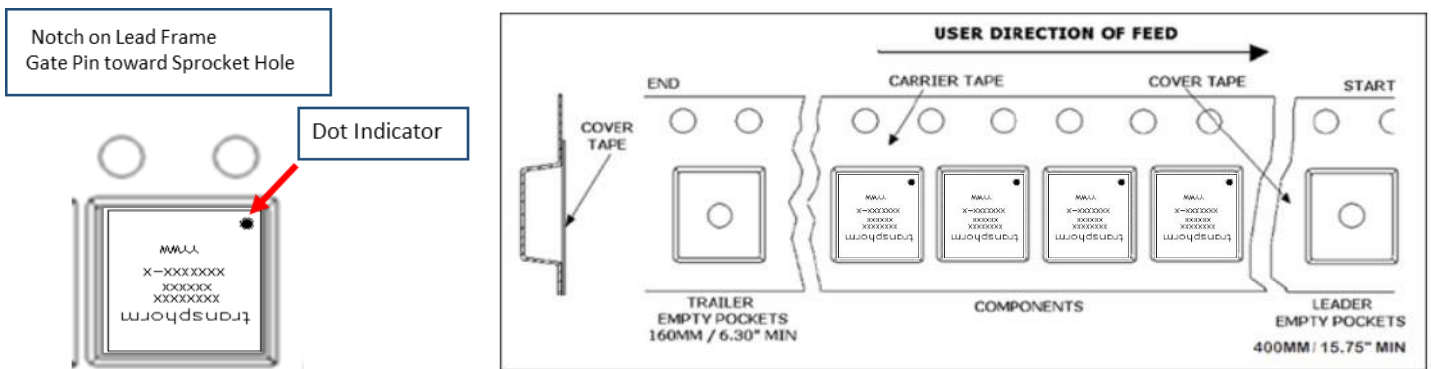

- Leader Empty Pockets: 85
- Trailer Empty Pockets: 40
- Quantity per Reel: 4,000pcs

Part III: Carrier Tape Dimension

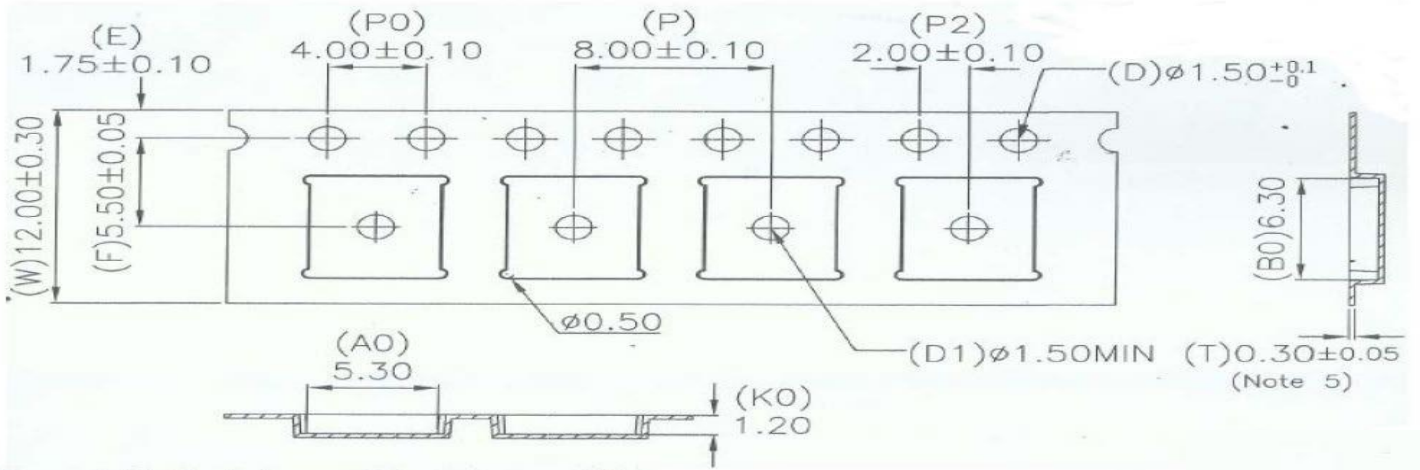

Ao = 5.30

Bo = 6.30


Ko = 1.20

Notes:

- 10 Sprocket Hole pitch cumulative tolerance ± 0.2
- Camber in compliance with EIA 481
- Pocket position relative to Sprocket Hole measured as true position of Pocket not Pocket Hole

Part IV: Reel Dimension


- Reel Size: 330mm

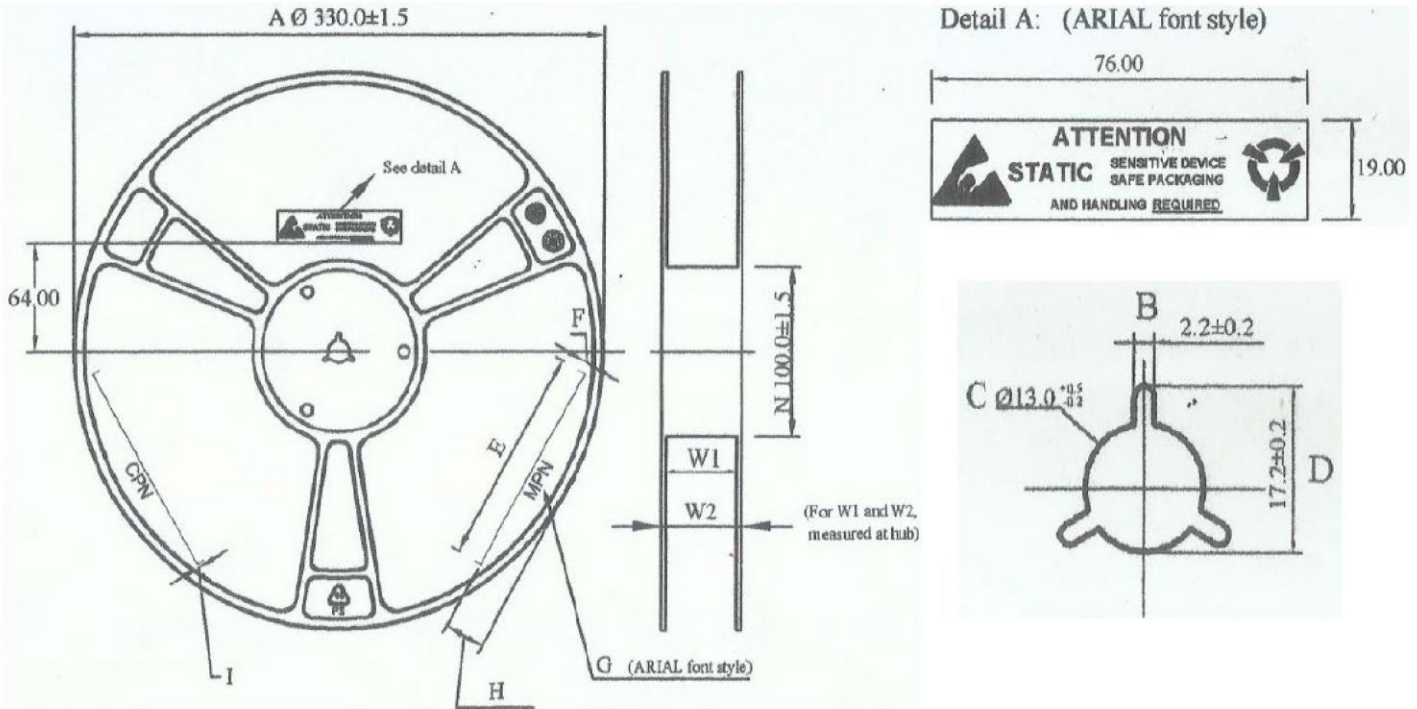

PRODUCT NAME	U-PAK P/N	W1	W2 (Max)	E	F	G	H	I
13" 100*12mm Plastic Reel	MUR-223-BX	12.40 ^{+2.0} _{-0.8}	18.40	130 ± 1.0	5 ± 1.0	8 ± 1.0	25 ± 1.0	0.4 ± 0.5


Color based on customer requirement.
 Material: HIPS (High Impact Polystyrene)
 Need Ultrasonic Welding.
 Surface Resistance: $10^7 \sim 10^{11} \Omega/\square$
 All dimensions in millimeters unless otherwise specified.
 Text with ARIAL font style.

Part V: Box Size

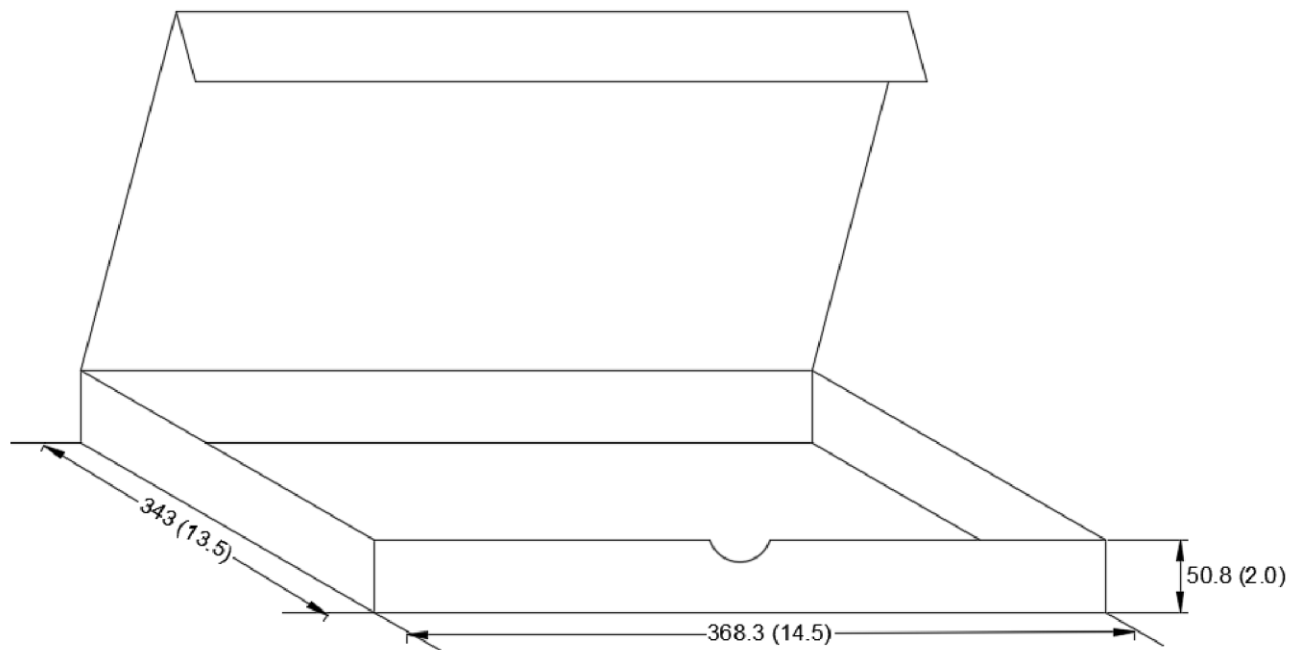


Dimensions are in millimeter (inches are in brackets for reference only)



- Part VI: Package POD for Performance Version & Laser Marking Sample

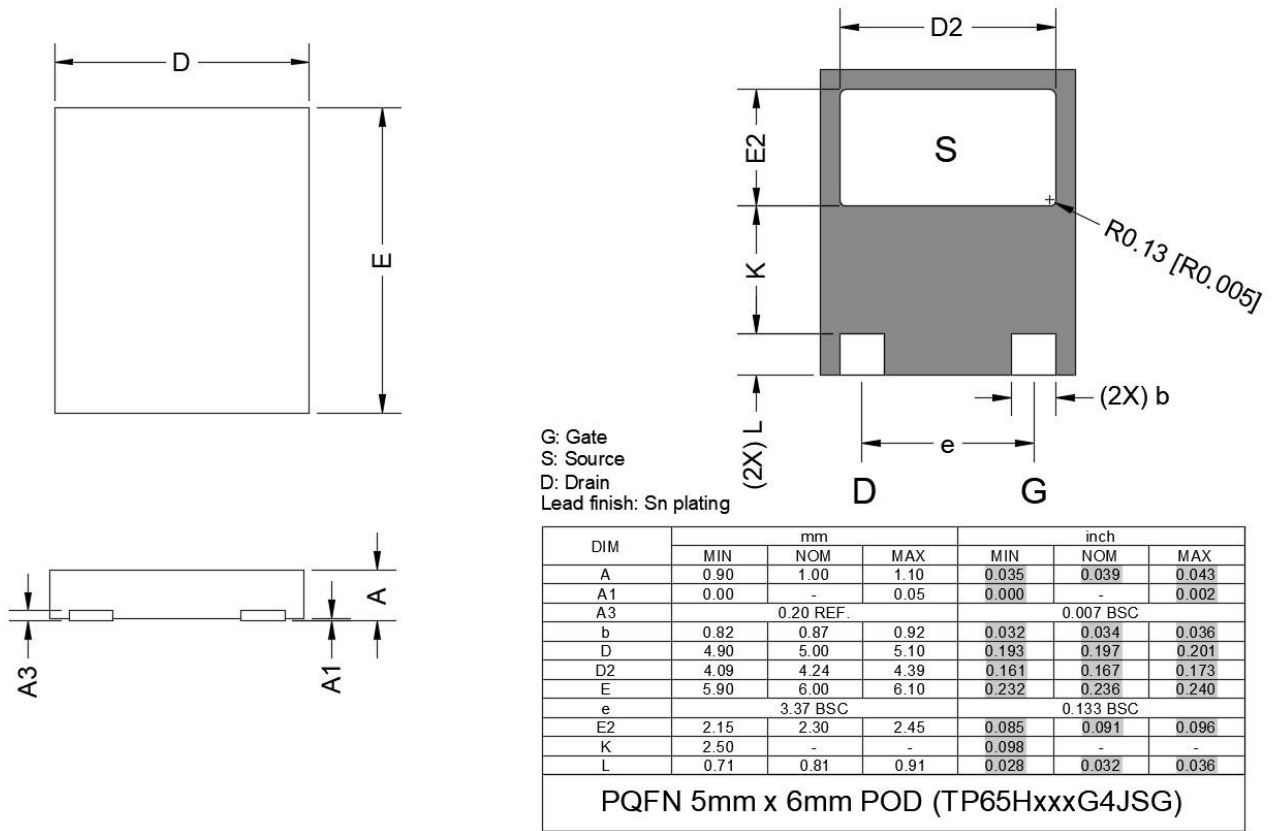

Laser Marking Sample

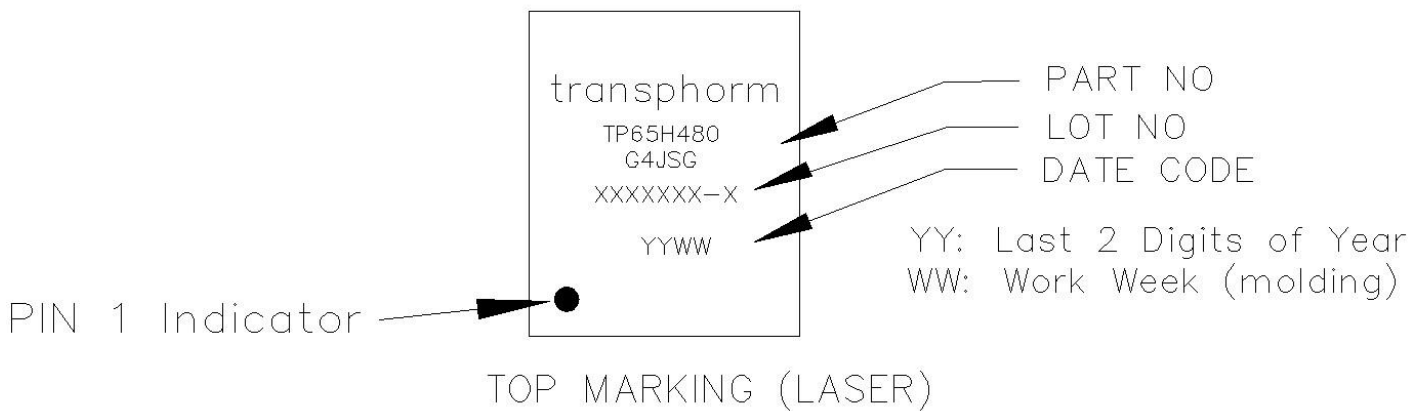

Part VII: Package POD for Industry Standard LSGB Version & Laser Marking

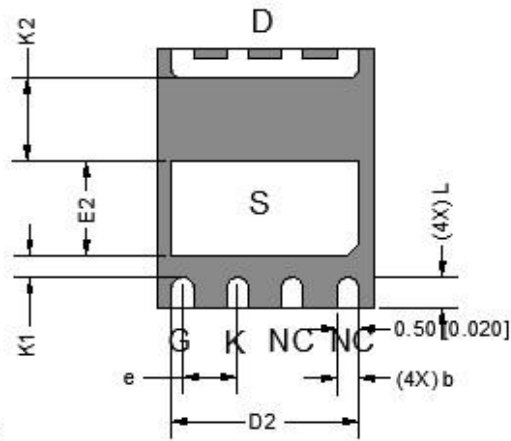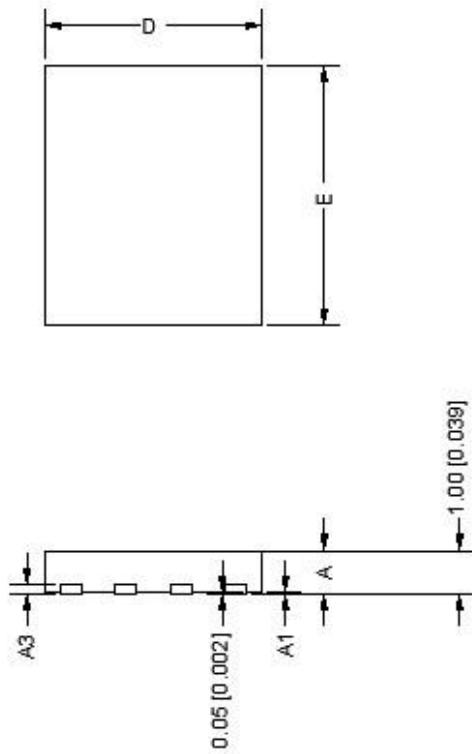


G: Gate
S: Source
D: Drain
K: Kelvin
Lead finish: Sn plating

DIM	mm			inch		
	MIN	NOM	MAX	MIN	NOM	MAX
A	0.90	1.00	1.10	0.035	0.039	0.043
A1	0.00	-	0.05	0.000	-	0.002
A3	0.20 REF.			0.007 BSC		
b	0.45	0.50	0.55	0.018	0.020	0.022
D	4.90	5.00	5.10	0.193	0.197	0.201
D2	4.15	4.30	4.45	0.163	0.169	0.175
E	5.90	6.00	6.10	0.232	0.238	0.240
e	127 BSC			0.133 BSC		
E2	2.05	2.20	2.35	0.081	0.087	0.093
K1	0.50	-	-	0.020	-	-
K2	1.90	-	-	0.075	-	-
L	0.60	0.70	0.80	0.024	0.028	0.031

PQFN 5mm x 6mm POD (TP65HxxxG4JSB)

Note: P/N TP65H150BG4JSG is following this exact POD

Laser Marking Sample

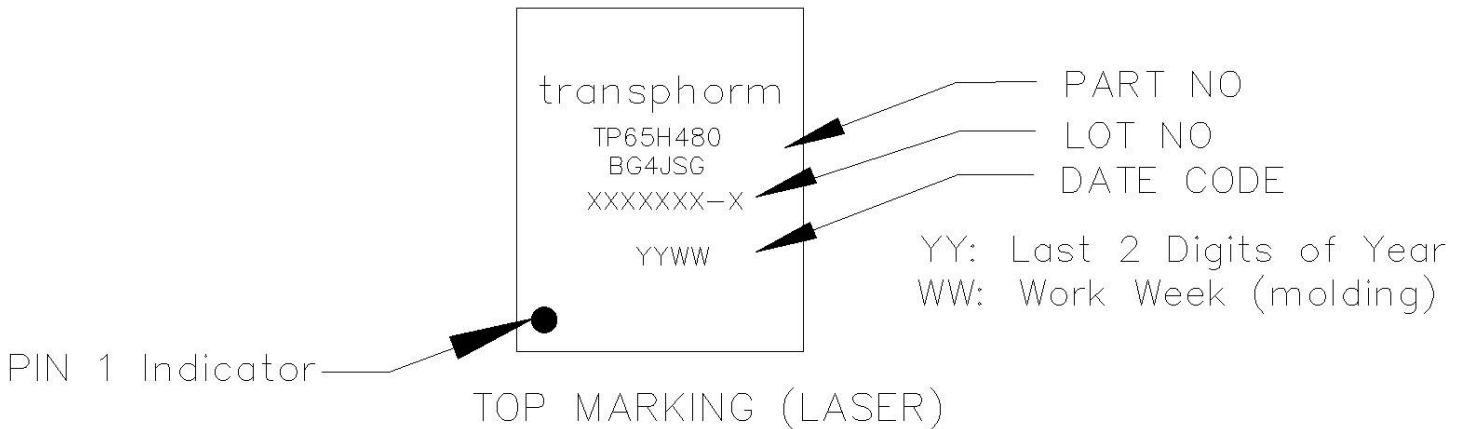

- Part VIII: Tape and Reel Packing Information



Tape and Reel Shielding Bag

- 4,000units/reel
- Maximum 1 reel/box
- Place Tape and Reel inside moisture barrier bag
- Seal moisture bag

- Part IX: Internal Shipping Box Information



Internal Shipping Box

- Tape internal box closed using ESD Label.
- Place Internal Shipping Label.



Internal Shipping Box Label

Supplier P/N: Renesas Part Number

Quantity: Quantity contained inside the box

Date Code: YYWW

Lot Code: Assembly Lot Number

COO: Country of Origin

2D Barcode: Above information encoded











- Part X: External Shipping Box Information



External Shipping Box

- Internal Shipping Boxes inside External Shipping Box
- Number of Internal Boxes ranges from 2 to 6
- Place External Shipping Label

External Shipping Box Label

FROM: Transphorm, Inc. 75 Castilian Drive Goleta, CA 93117	TO: Customer Name ATTN: Attention TO Customer Address Line 1 Customer Address Line 2 City & Zip Code
(K) PO Number: Sample 	
(1P) Supplier Part Number: TP65HxxxG4JSG 	
(Q) Quantity: 4000 	
(4S) Package ID: SO-1288 	
(10D) Data Code: 1452 	(4L) COO: US 
(1T) Lot Code: B9A028 	
  	

From : Renesas shipping address

To : Customer name, Attention TO, and address number

PO Number : Customer Purchase Order Number

Supplier Part Number : Renesas Part Number Quantity : Total product quantity contain in external shipping box

Package ID : Renesas Assigned Number

Date Code: YYWW

Lot Code: Assembly Lot Number

COO: Country of Origin


2D Barcode: Above information encoded

Shipping Box Size and Weight

Shipment	Units	Weight	Size	Comments
1 box	4,000pcs	2.47 (lbs) 1.12 (kgs)		FedEx Shipping box
3 boxes	12,000pcs	7.41 (lbs) 3.36 (kgs)	15.25 in x 13.5 in x 15.5 in 387.35 mm x 342.9mm x 393.7mm	
4 boxes	16,000pcs	9.88 (lbs) 4.48 (kgs)	15.25 in x 13.5 in x 15.5 in 387.35 mm x 342.9mm x 393.7mm	
5 boxes	20,000pcs	12.35 (lbs) 5.60 (kgs)	15.25 in x 13.5 in x 15.5 in 387.35 mm x 342.9mm x 393.7mm	
6-boxes	24,000pcs	14.82 (lbs) 6.72 (kgs)	15.25 in x 13.5 in x 15.5 in 387.35 mm x 342.9mm x 393.7mm	


- 4. TO-220 Shipping Information
- Part I: Shipping Tube

Tubes Length = 21 Inches

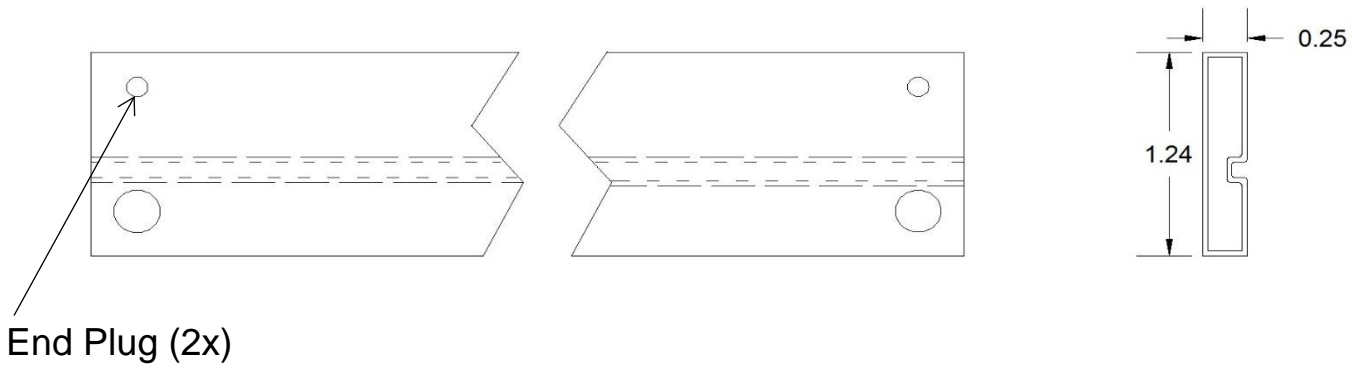


End Plug

Color = Black

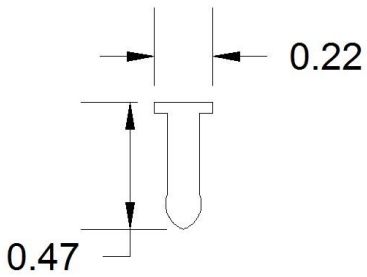

- Part II: Tube Quantity


- 50 units per tube.

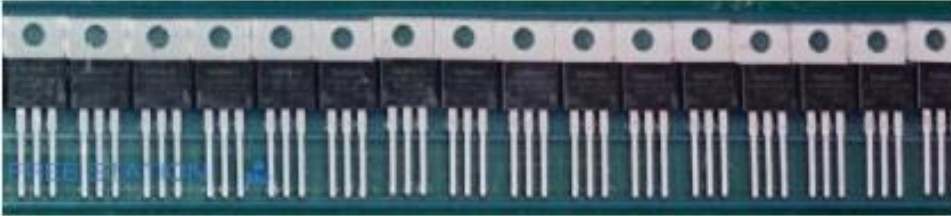

- Maximum tube per anti-static shielding bag and inner box is 20 tubes or 1000 units per inner box.



- Part III: Box Size

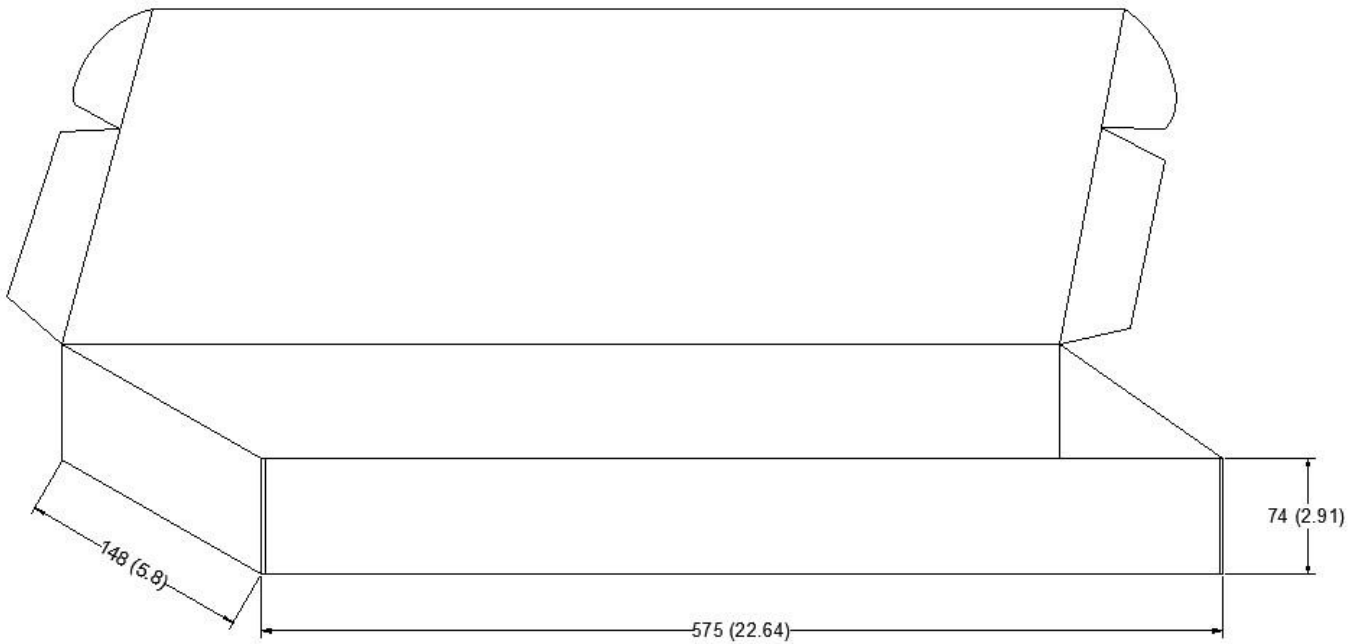


Dimensions are in millimeter (inches are in brackets for reference only)

- Part IV: Internal Shipping Box Information

- Internal Shipping Box

- Tape internal box closed using ESD Label.
- Place Internal Shipping Label.

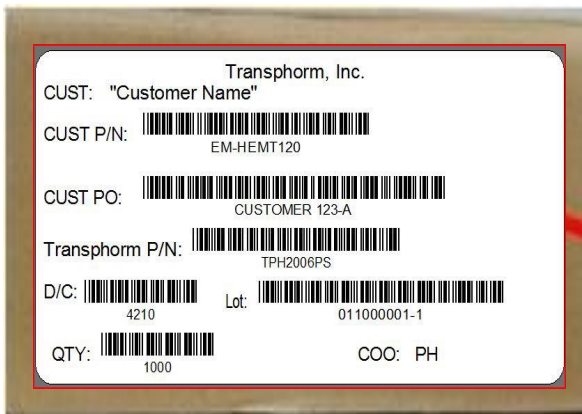

- Internal Shipping Box Label



Description:

Size: 4" x 2"

CUST: "Customer Name"

CUST P/N: "Customer Part Number"

Renesas P/N: "Renesas Part Number"

D/C: "Date Code"

QTY: "Quantity unit contained in inner box"

COO: "Country of Origin"





- Part V: External Shipping Box Information

- External Shipping Box

- Bubble sheets on bottom and on both sides of the master box then place 6 inner boxes inside the master box.
- For 4 inner boxes or less, use small master box.
- Master box shipping label as shown below and seal the master box following the standard operating procedure.



External Shipping Box Label

From: Transphorm, Inc. 115 Castilian Drive Goleta, CA 93117	
To: Customer Name Customer Address Line 1 Customer Address Line 2 City & ZIP Code Country ATTN: Customer Attention TO Customer ATTN TO phone number	
Customer PO:  CUSTOMER 123-A	
Customer P/N:  EM-HEMT120	
Quantity:  1000	
Transphorm P/N:  TPH2006PS	
<u>Country of Origin</u> PH	
<u>Package Count</u> x of x	<u>Package Weight</u> x.x lbs / x.xx kg
PKG Slip: 100007 Tracking: 7342 3458 9572 Invoice: S100008 Ship Date: 1/15/11 Customer: Customer Name	

From: Renesas Shipping address

To: Customer name, address attention to and phone number

Customer PO: Customer Purchase Order Number

Customer P/N: Customer Part Number

Quantity: Total product quantity contains in external shipping box

Renesas P/N: Renesas Product Number

Country of Origin: Country of Origin where product was manufactured.

Package Count: Number of External Shipping boxes contained in shipment


Package Weight: Weight of packed External Shipping Box

Description:

Size: 4" x 6"

Shipment	Units	Weight	Size	Comments
1pack	1000pcs	2.99 (kgs) 6.61(lb)	575mm X 140mm X 73mm 22.6 in x 5.51in x 2.87 in	one inner box
2 ^{packs}	2000pcs	6.7 (kgs) 14.77(lb)	610mm x 310mm x 190mm 24 in x 12.2 in x 7.5 in	master box with two inner boxes
4 ^{packs}	4000pcs	12.25 (kgs) 27.00(lb)	610mm x 310mm x 190mm 24 in x 12.2 in x 7.5 in	master box with four inner boxes
6 ^{packs}	6000pcs	18.24 (kgs) 40.21(lb)	610mm x 310 mm x 340mm 24 in x 12.2 in x 13.4 in	master box with six inner boxes


- Part VI: Assembly Lot Number Information

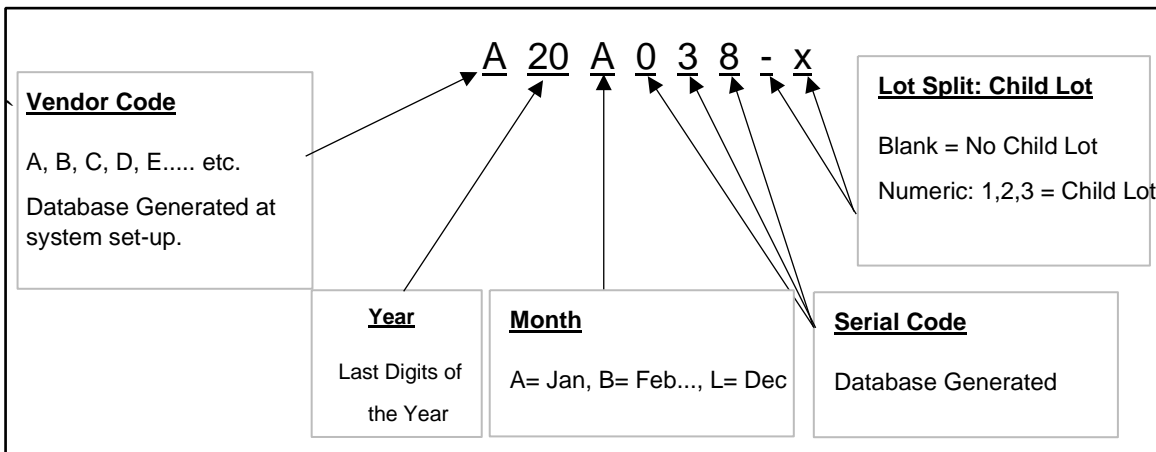

- 5. TO-247 Shipping Information
- Part I: Shipping Tube


Tubes

Length = 21 Inches

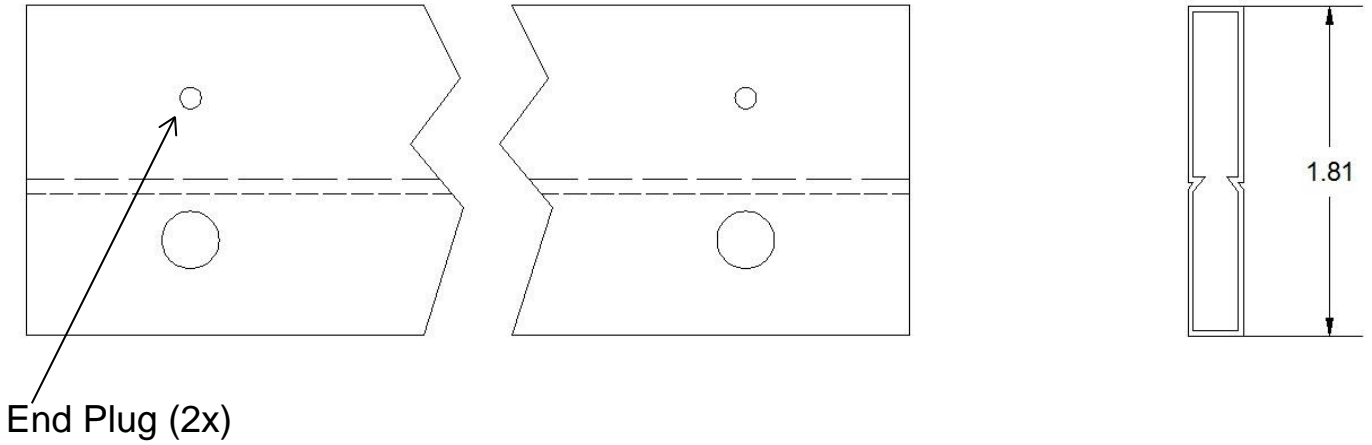

End Plug

Color = Black

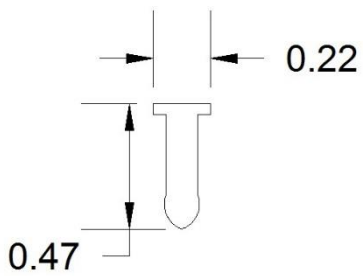


- Part II: Tube Quantity
- 30 units per tube.



- Maximum tube per anti-static shielding bag and inner box is 15 tubes or 450 units per inner box.





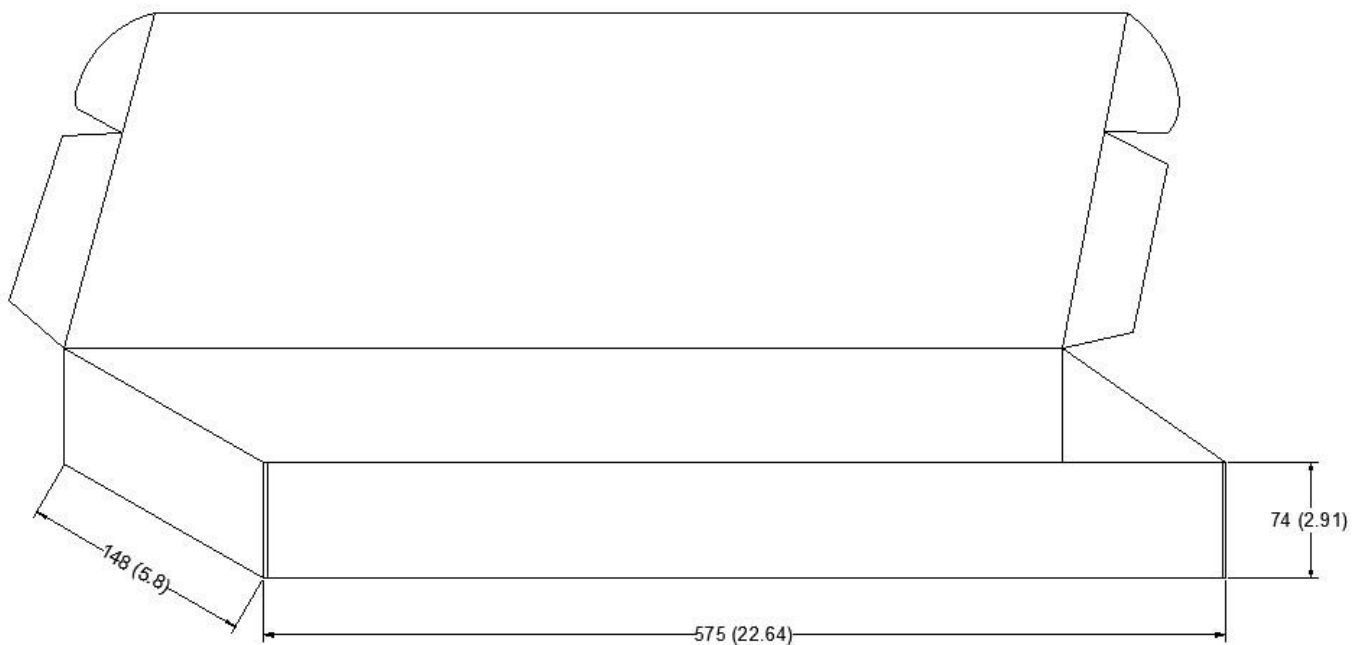



- Part III: Box Size



Dimensions are in millimeter (inches are in brackets for reference only)

Application Note

- Part IV: Internal Shipping Box Information
- Internal Shipping Box
 - Tape internal box closed using ESD Label.
 - Place Internal Shipping Label.

Transphorm, Inc.	
CUST: "Customer Name"	
CUST P/N: 	EM-HEMT120
CUST PO: 	CUSTOMER 123-A
Transphorm P/N: 	TPH2006PS
D/C:  4210	Lot:  011000001-1
QTY:  1000	COO: PH







- Part V: External Shipping Box Information
- External Shipping Box

- Bubble sheets on bottom and on both sides of the master box then place 6 inner boxes inside the master box.
- For 4 inner boxes or less, use small master box.
- Master box shipping label as shown below and seal the master box following the standard operating procedure.



From: Transphorm, Inc. 115 Cantilan Drive Oakdale, CA 95317	
To: Customer Name Customer Address Line 1 Customer Address Line 2 City & ZIP Code Country	
ATTN: Customer Attention TO Customer ATTN TO phone number	
Customer PO:  CUSTOMER 123-A	
Customer P/N:  EM-HEMT120	
Quantity:  1000	
Transphorm P/N:  TPH2006PS	
Country of Origin PH	
Package Count 6 of 6	Package Weight 6.48 lbs / 2.94 kg
PHC Ship: 100007 Invoice: 0100000 Customer: Customer Name	Tracking: 1342 3456 8910 Ship Date: 11/11/11

- External Shipping Box Label

From: Transphorm, Inc. 115 Castilian Drive Goleta, CA 93117	
To: Customer Name Customer Address Line 1 Customer Address Line 2 City & ZIP Code Country ATTN: Customer Attention TO Customer ATTN TO phone number	
Customer PO:  CUSTOMER 123-A	
Customer P/N:  EM-HEMT120	
Quantity:  1000	
Transphorm P/N:  TPH2006PS	
<u>Country of Origin</u> PH	
<u>Package Count</u> x of x	<u>Package Weight</u> x.x lbs / x.xx kg
PKG Slip: 100007 Invoice: S100008 Customer: Customer Name	Tracking: 7342 3458 9572 Ship Date: 1/15/11

Description:

Size: 4" x 6"

From: Renesas Shipping address

To: Customer name, address attention to
and phone number

Customer PO:

Customer Purchase Order
Number

Customer P/N:

Customer Part Number

Quantity: Total product quantity
contains in external shipping box

Renesas P/N: Renesas Product
Number


Country of Origin: Country of Origin where product was manufactured.

Package Count: Number of External
Shipping boxes contained in shipment

Package Weight: Weight of packed
External Shipping Box


Shipment	Units	Weight	Size	Comments
1pack	450pcs	3.90 (kgs) 8.60(lb)	575mm X 140mm X 73mm 22.6 in x 5.51in x 2.87 in	one inner box
2packs	900pcs	8.05 (kgs) 17.75(lb)	610mm x 310mm x 190mm 24 in x 12.2 in x 7.5 in	master box with two inner boxes
4packs	1,800pcs	15.85 (kgs) 34.95(lb)	610mm x 310mm x 190mm 24 in x 12.2 in x 7.5 in	master box with four inner boxes
6packs	2,700pcs	23.65 (kgs) 52.15(lb)	610mm x 310 mm x 340mm 24 in x 12.2 in x 13.4 in	master box with six inner boxes

- Part VI: Assembly Lot Number Information

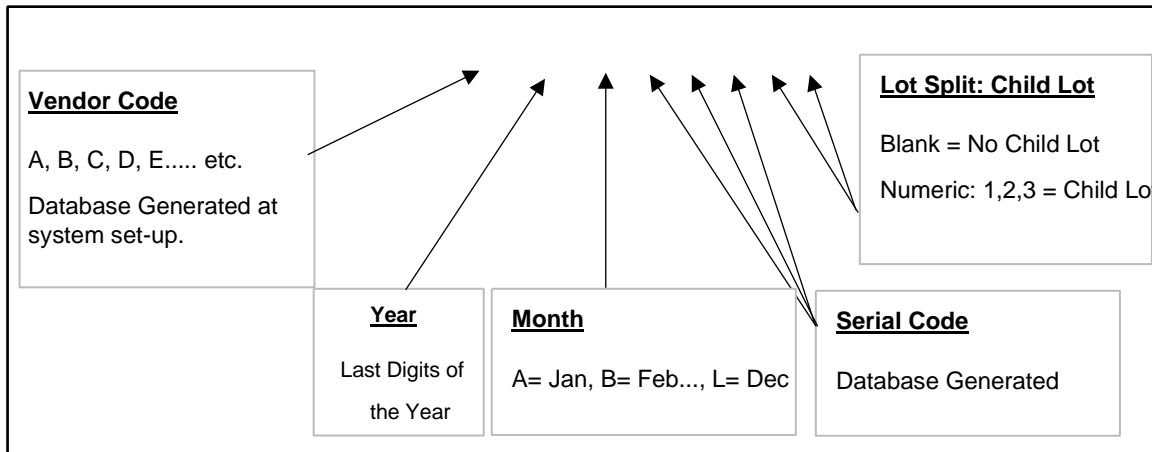


- 6. TOLL TAPE & REEL INFORMATION

- Part I: Product Orientation

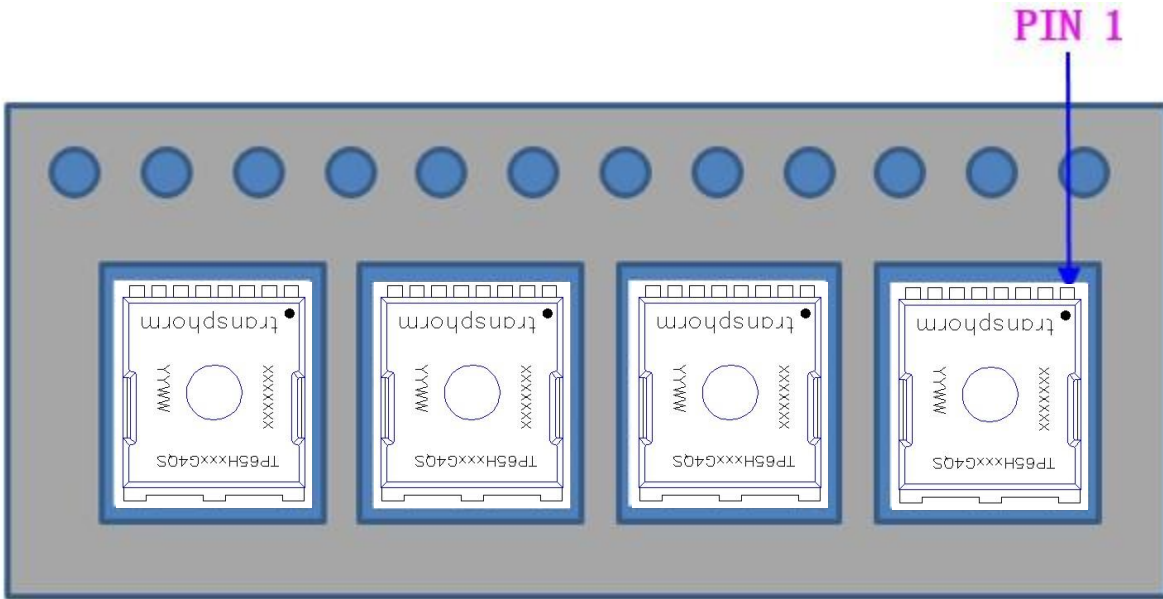

- -Leader Empty Pockets: 400mm / 35 empty pocket
- -Trailer Empty Pockets: 160mm / 15 empty pocket
- -Quantity per Reel: 2,000pcs


- Part II: Carrier Tape Dimension

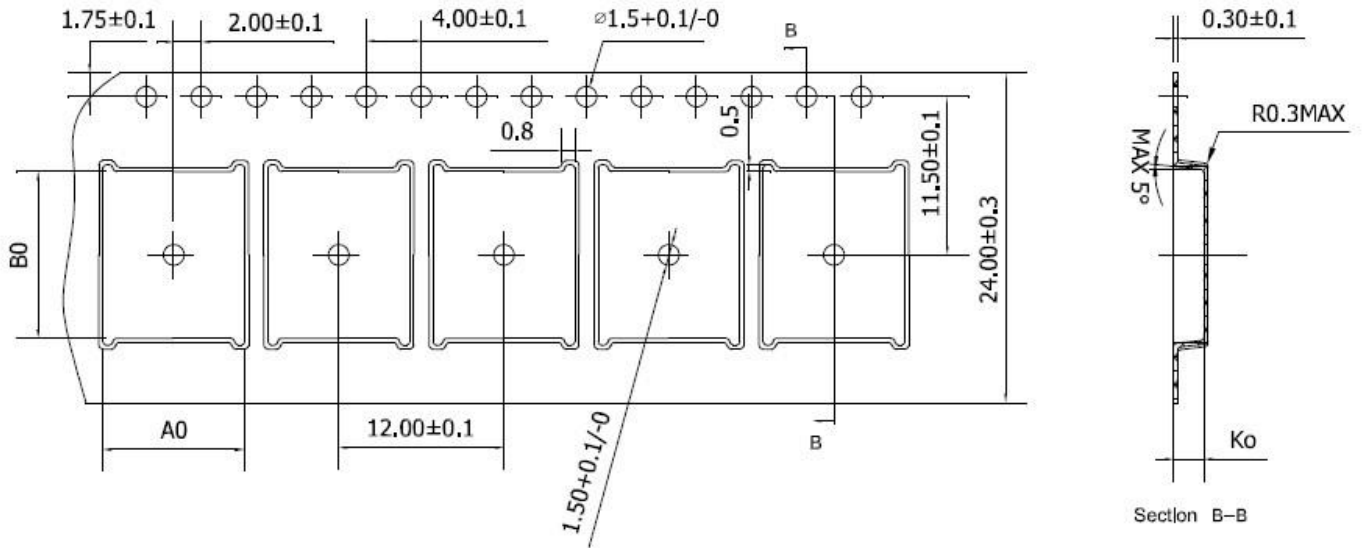


A0=10.30±0.1
B0=12.10±0.1
Ko=2.70±0.1

- Part III: Reel Dimension

- Reel Size: 330mm
- Hub Width: 24mm

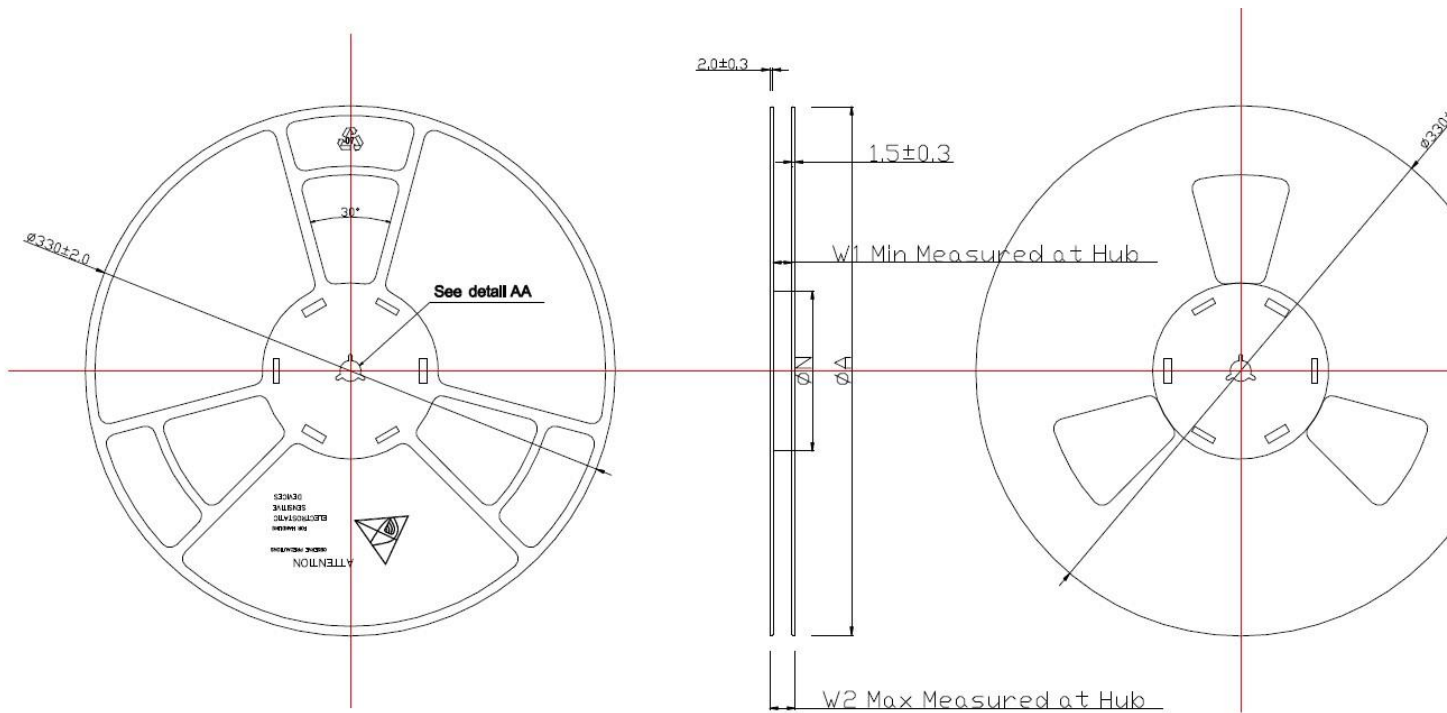


PRODUCT SPECIFICATIONS				
TYPE WIDTH	ϕA	ϕN	W1 (Min)	W2 (Max)
12MM	330mm \pm 2.0	100mm \pm 1.0	12.4mm	19.4mm
16mm	330mm \pm 2.0	100mm \pm 1.0	16.4mm	23.4mm
24MM	330mm \pm 2.0	100mm \pm 1.0	24.4mm	31.4mm
32MM	330mm \pm 2.0	100mm \pm 1.0	32.4mm	39.4mm
44MM	330mm \pm 2.0	100mm \pm 1.0	44.4mm	51.4mm

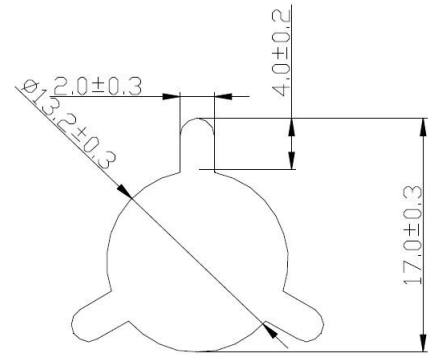


detail AA

- Part IV: Box Dimension

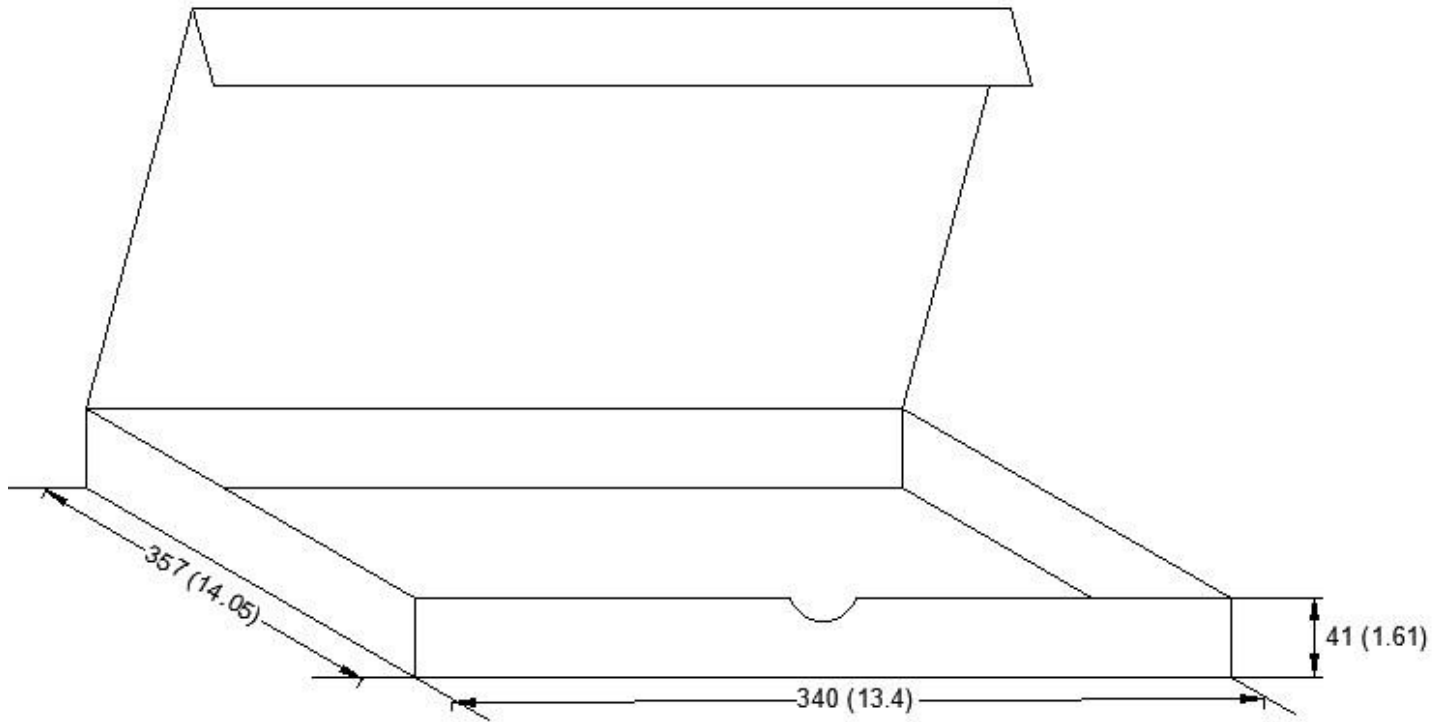

Dimensions are in millimeter (inches are in brackets for reference only)

- Part V: Package POD

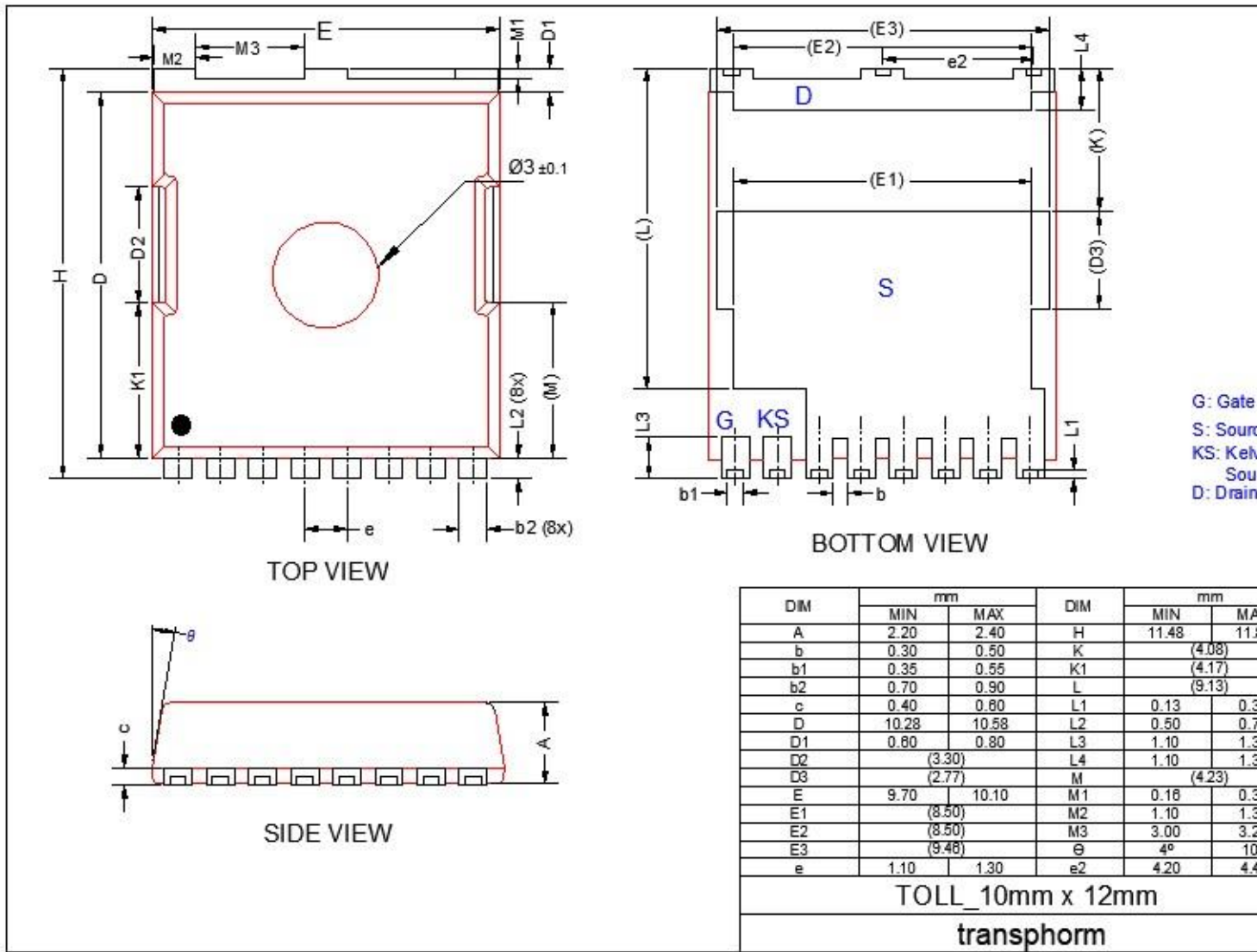


- Part VI: Tape and Reel Packing Information



Tape and Reel Shielding Bag


- 2,000 units / reel
Maximum 1 reel / box
- Place Tape and Reel inside moisture barrier bag
- Seal moisture bag

- Part VII: Internal Shipping Box Information

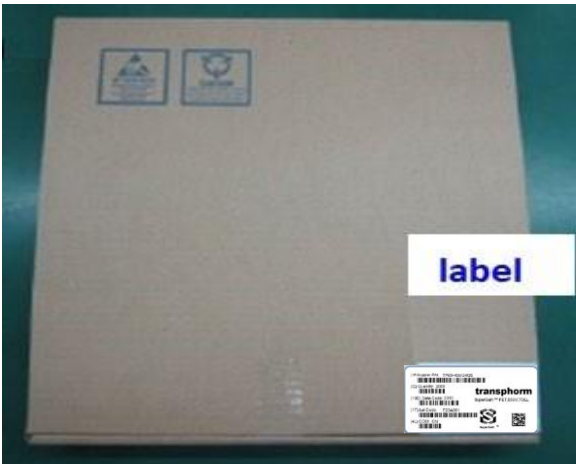

Internal Shipping Box

- Tape internal box closed
- Place Internal Shipping Label

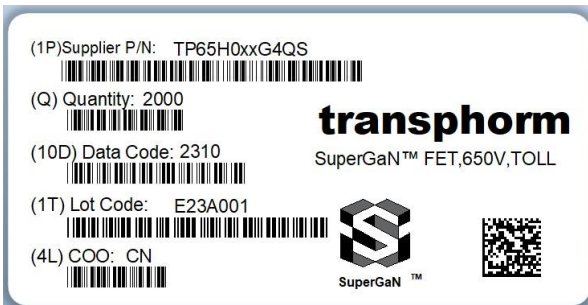

Internal Shipping Box Label

Supplier P/N: Renesas Part Number
Quantity: Quantity contained inside the box
Date Code: YYWW
Lot Code: Assembly Lot Number
COO: Country of Origin











2D Barcode: Above information encoded

- Part VIII: External Shipping Box Information



External Shipping Box

- Internal Shipping Boxes inside External Shipping Box
- Number of Internal Boxes ranges from 2 to 4
- Place External Shipping Label

FROM: Transphorm, Inc. 75 Castilian Drive Goleta, CA 93117	TO: Customer Name ATTN: Attention TO Customer Address Line 1 Customer Address Line 2 City & Zip Code
(K) PO Number: Sample 	
(1P) Supplier Part Number: TP65H0xxG4QS 	
(Q) Quantity: 2000 	
(4S) Package ID: SO-1288 	
(10D) Data Code: 2310 	(4L) COO: CN 
(1T) Lot Code: E23A001 	
  	

External Shipping Box Label

- **From:** Renesas shipping address
- **To:** Customer name, Attention TO, and address number
- **PO Number:** Customer Purchase Order Number
- **Supplier Part Number:** Renesas Part Number
- **Quantity:** Total product quantity contain in external shipping box
- **Package ID:** Renesas Assigned Number
- **Date Code:** YYWW
- **Lot Code:** Assembly Lot Number
- **COO:** Country of Origin

- **2D Barcode:** Above information encoded