


CUSTOM TRAY

Tray Code	RENESAS Code	Previous Code
PT846B	PRQP0240KC-A	FP-240 / FP-240V
	PRQP0240KC-B	FP-240B / FP-240BV
	PRQP0296LA-A	FP-296 / FP-296V
	PRQP0296LA-B	FP-296B / FP-296BV

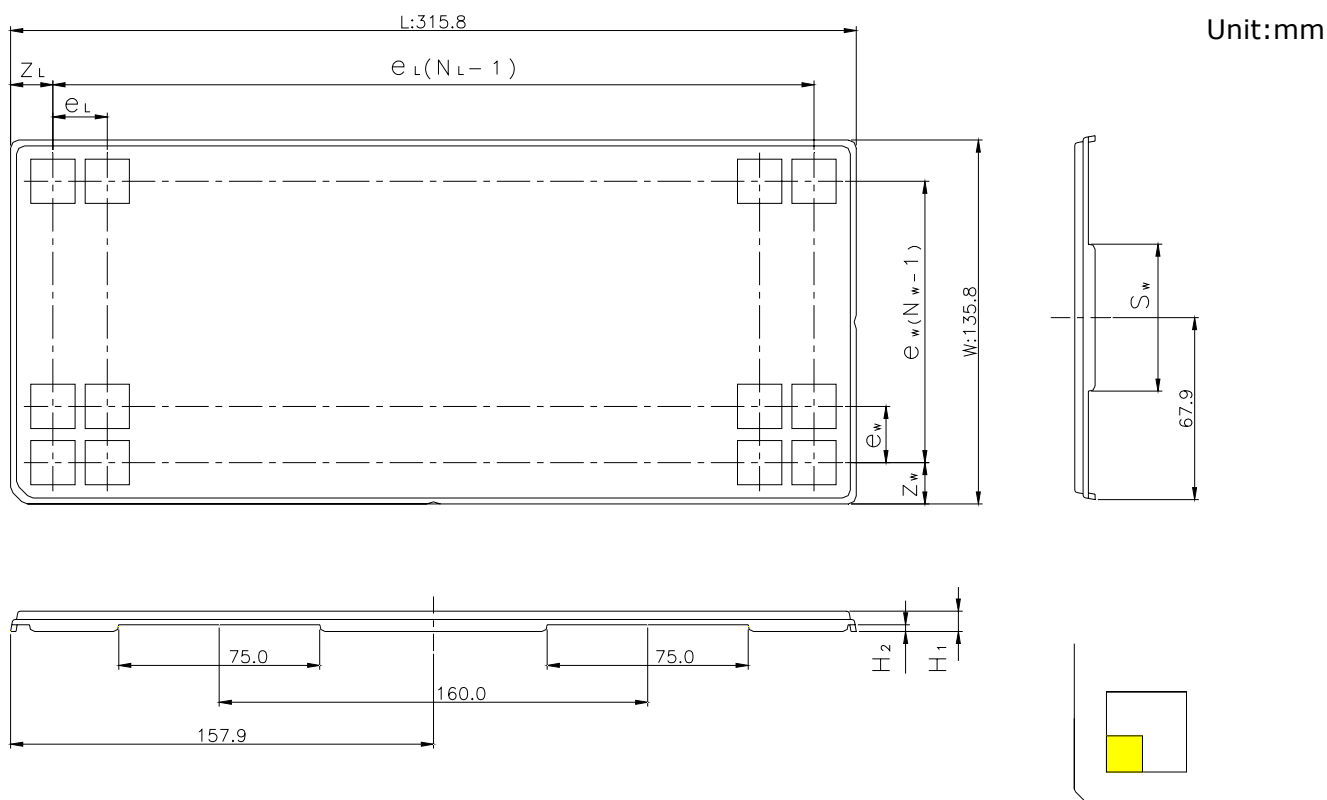

The pin1 is located in the hatching portion

Position dimension of cells (mm)	Z_w	27.1
	Z_L	32.9
	e_w	40.8
	e_L	50
	S_w	55
Thickness (mm)	H_1	8.7
	H_2	3
Number of cells	N_w	3
	N_L	6
Maximum storage No. IC/Tray		18
Maximum storage No. IC/Inner box		180
Material		Carbon PPE
Surface resistance		Less than $1 \times 10^{11} \Omega / \square$
Heat resistant temperature		125°C24h
Packing form		Dry pack