


# CUSTOM TRAY

| Tray Code | RENESAS Code | Previous Code |
|-----------|--------------|---------------|
| M095-31   | PRQP0044GA-A | 44P6N-A       |
|           | PRQP0056JA-A | 56P6S-A       |

Unit:mm

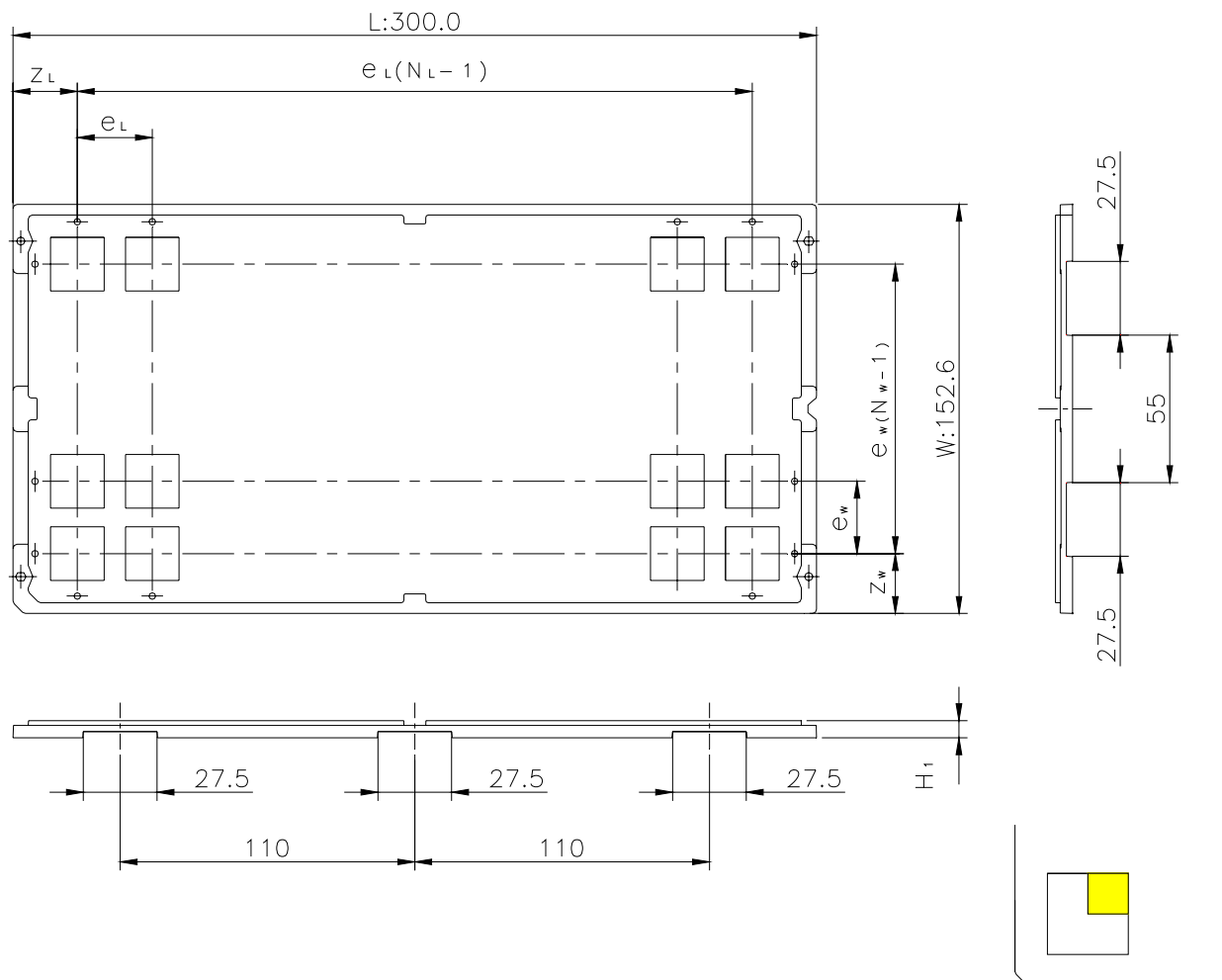

The pin1 is located in the hatching portion

|                                  |       |   |
|----------------------------------|-------|---|
| Position dimension of cells (mm) | $Z_w$ | 18.55   |
|                                  | $Z_L$ | 17  |
|                                  | $e_w$ | 16.5  |
|                                  | $e_L$ | 19  |
| Thickness (mm)                   | $H_1$ | 5.6   |
| Number of cells                  | $N_w$ | 8   |
|                                  | $N_L$ | 15  |
| Maximum storage No. IC/Tray      |       | 120   |
| Maximum storage No. IC/Inner box |       | 600   |
| Material                         |       | Carbon PP                                     |
| Surface resistance               |       | Less than $1 \times 10^{11} \Omega / \square$ |
| Heat resistant temperature       |       | 125°C MAX                                     |
| Packing form                     |       | Dry pack                                      |