


JEDEC TRAY

Tray Code	RENESAS Code	Previous Code
L196-95	PRBG0436GA-A	436F7S

Unit:mm

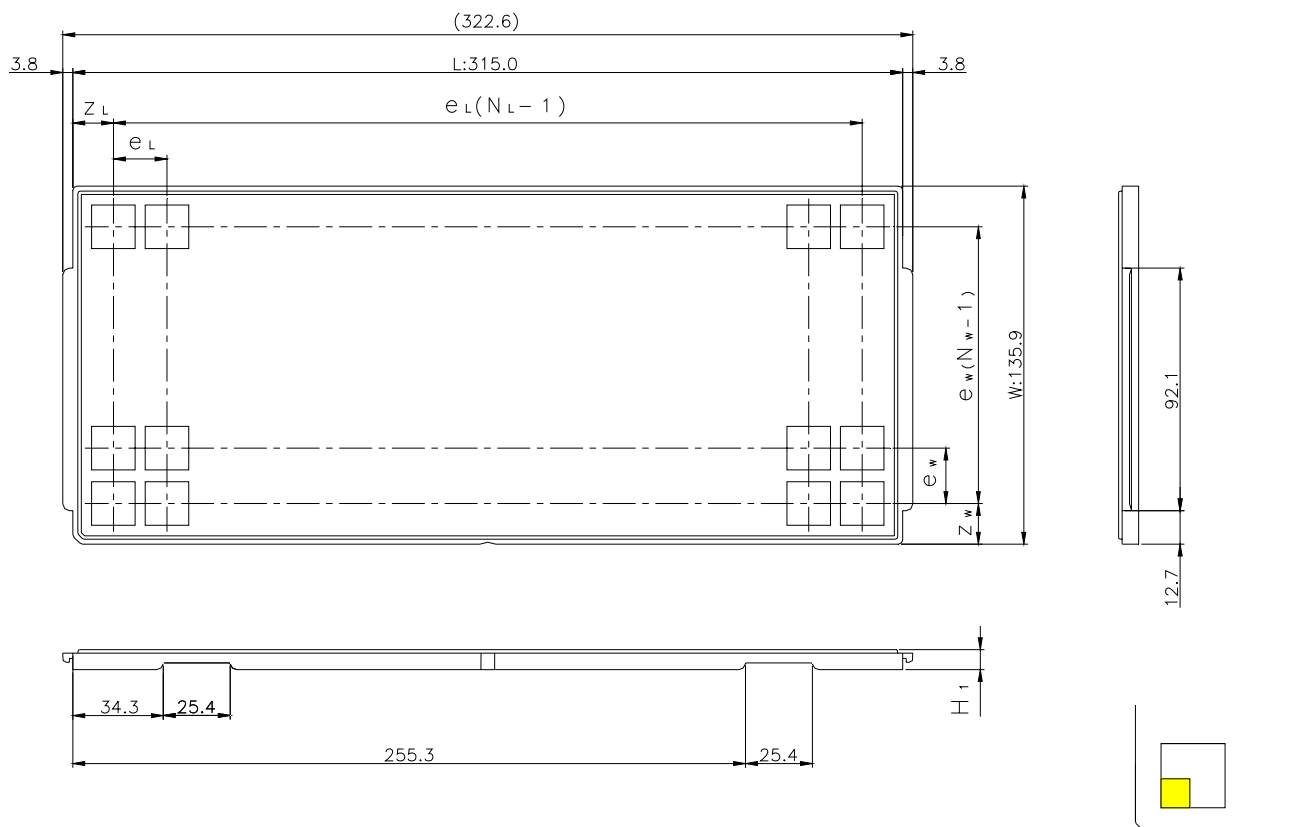

The pin1 is located in the hatching portion

Note : Numbers in parentheses are the numbers of ICs contained in five trays per inner box, and those without parentheses are the numbers of ICs contained in eight trays per inner box.

Position dimension of cells (mm)	Z_w	14.6
	Z_L	18.79
	e_w	21.34
	e_L	21.34
Thickness (mm)	H_1	7.62
Number of cells	N_w	6
	N_L	14
Maximum storage No. IC/Tray		84
Maximum storage No. IC/Inner box (Note)		672(420)
Material		Carbon PPE
Surface resistance		Less than $1 \times 10^{11} \Omega/\square$
Heat resistant temperature		125°C24h
Packing form		Dry pack