


JEDEC TRAY

Tray Code	RENESAS Code	Previous Code
FT87	PVQN0032KA-A	TNP-32 / TNP-32V
	PVQN0032KB-A	—

Unit:mm

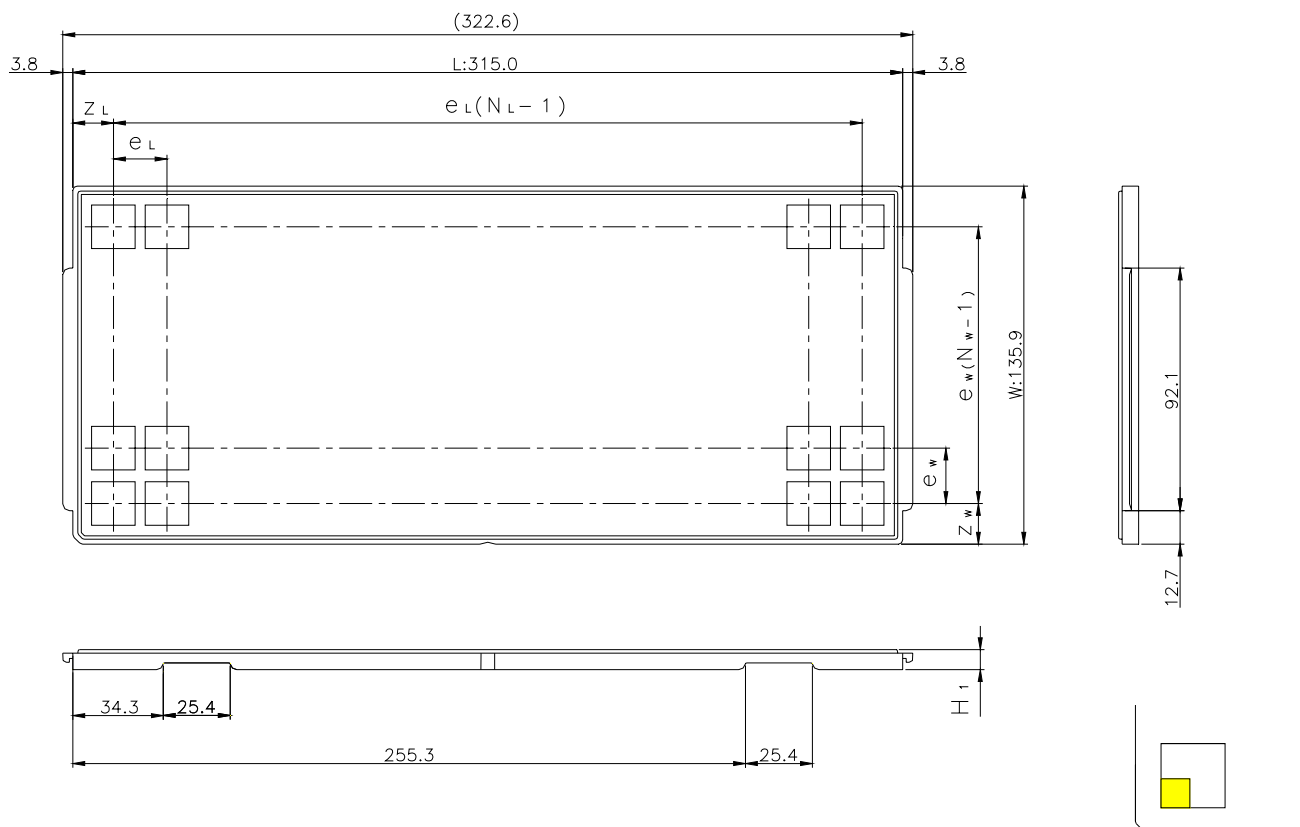

The pin1 is located in the hatching portion

Position dimension of cells (mm)	Z _w	11.25
	Z _L	11.1
	e _w	12.6
	e _L	12.2
Thickness (mm)	H ₁	7.62
Number of cells	N _w	10
	N _L	25
Maximum storage No. IC/Tray		250
Maximum storage No. IC/Inner box		2250
Material		Carbon PPE
Surface resistance		Less than 1x10 ¹¹ Ω/□
Heat resistant temperature		125°C24h
Packing form		Dry pack