


JEDEC TRAY

Tray Code	RENESAS Code	Previous Code
L196-06A	PLQP0176KB-A	176P6Q-A / FP-176E / FP-176EV
	PLQP0216LA-A	216P6R-B

Unit:mm

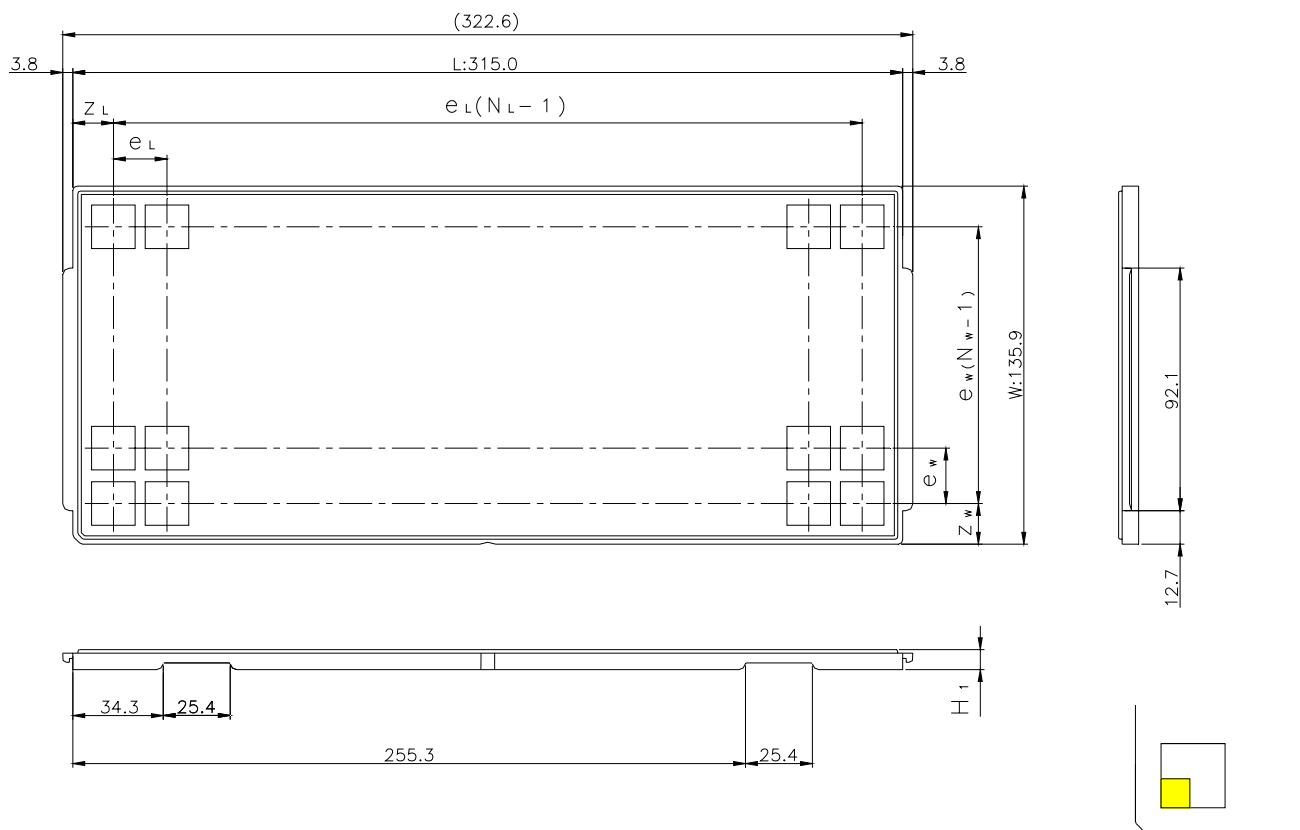

The pin1 is located in the hatching portion

Note : Numbers in parentheses are the numbers of ICs contained in five trays per inner box, and those without parentheses are the numbers of ICs contained in eight trays per inner box.

Position dimension of cells (mm)	Z_w	20.7
	Z_L	20.7
	e_w	31.5
	e_L	30.4
Thickness (mm)	H_1	7.62
Number of cells	N_w	4
	N_L	10
Maximum storage No. IC/Tray		40
Maximum storage No. IC/Inner box (Note)		320(200)
Material		Carbon PPE
Surface resistance		Less than $1 \times 10^{11} \Omega / \square$
Heat resistant temperature		125°C24h
Packing form		Dry pack