

无需准备开发板或工具！ 只需联网 PC 即可进行评估。

# Web Simulator

<https://www.renesas.com/websimulator-en>

## 在线 MCU 模拟器

在线 MCU 模拟器可供联网 PC 免费使用。通过预先导入的样例项目，立即进行初步评估。在线 MCU 模拟器提供了各种初步评估功能，包括虚拟板/编辑器/调试器、电流消耗测量等功能。它能够节省初步评估的时间和成本，并且在新常态下，是适用于全球远程工作者的理想工具。


- ✔ **无需安装！**  
免费搭建开发环境。
- ✔ 通过虚拟板，可视化验证程序运行。
- ✔ 已创建程序也可用于实物板。

»» 立即体验 [mcu-simulator.renesas.com/?locale=en](https://mcu-simulator.renesas.com/?locale=en)

支持 MCU

RA 家族 RL78 家族

有关支持微控制器的详细信息，请参阅：  
[www.renesas.com/websimulator-products-en](http://www.renesas.com/websimulator-products-en)

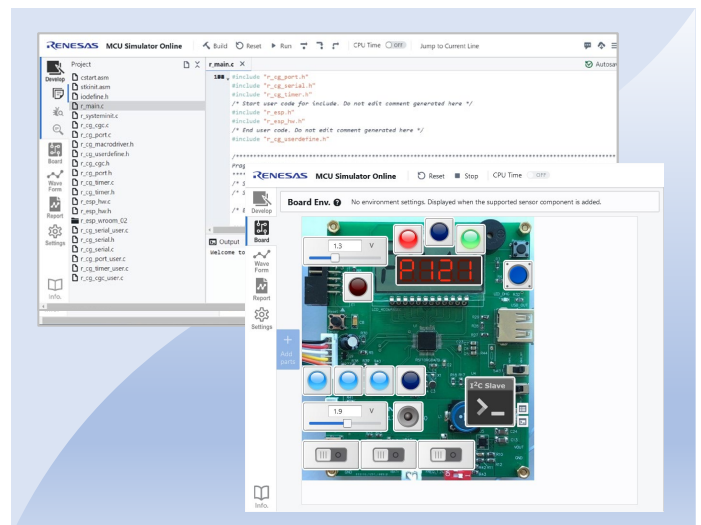

## 电流消耗计算工具

只需在本工具中设置低功耗 RL78 产品的外设功能，即可快速计算包括 MCU 外设功能在内的电源电流。这样，用户就能检查电流是否已调整到目标值，或尝试更改条件以进一步降低电流。


- ✔ **无需程序编码！**  
利用网页工具，轻松设置条件。
- ✔ 即时检查电池寿命
- ✔ 适用产品范围广，包括RL78家族通用产品以及BLE/LCD

»» 立即体验 [www.renesas.com/current-consumption-en](http://www.renesas.com/current-consumption-en)

支持 MCU

RL78 家族

有关支持微控制器的详细信息，请参阅：  
[www.renesas.com/websimulator-products-en](http://www.renesas.com/websimulator-products-en)

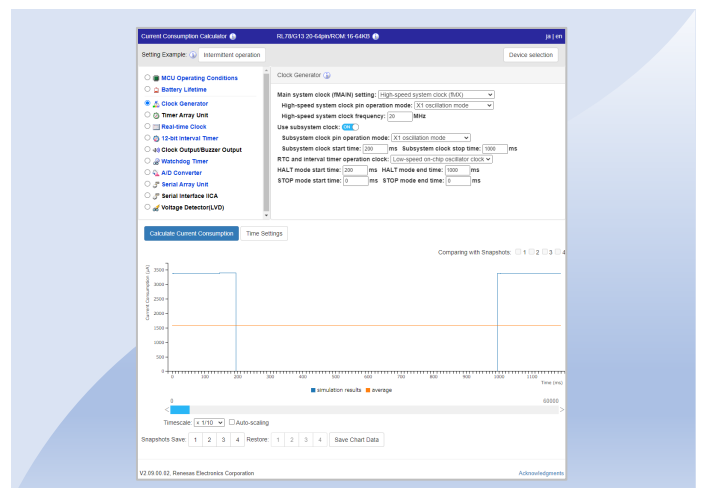

## 视频

[www.renesas.com/video/mcu-simulator-online-introduction](http://www.renesas.com/video/mcu-simulator-online-introduction)

[www.renesas.com/video/rl78-current-consumption-calculator](http://www.renesas.com/video/rl78-current-consumption-calculator)

❓ 常见问题 [en-support.renesas.com/knowledgeBase](https://en-support.renesas.com/knowledgeBase)

✔ 社区 [community.renesas.com](https://community.renesas.com)

**renesas.com**

Renesas Electronics Corporation | Toyosu foresia 3-2-24, Toyosu, Koto-ku, Tokyo. 135-0061, Japan | [www.renesas.com](http://www.renesas.com)

### Trademarks

Renesas and Renesas logo are trademarks of Renesas Electronics Corporation. All trademark and registered trademark are the property of their respective owners.

### Contact information

For further information on a product technology, to most up-to-date version of a document, or your nearest office, please visit [www.renesas.com/contact/](http://www.renesas.com/contact/)