


JEITA Package Code	RENESAS Code	Previous Code	MASS (TYP.) [g]
P-FQFP208-28x28-0.50	PRQP0208KG-J	P208GD-50-FAF	5.0

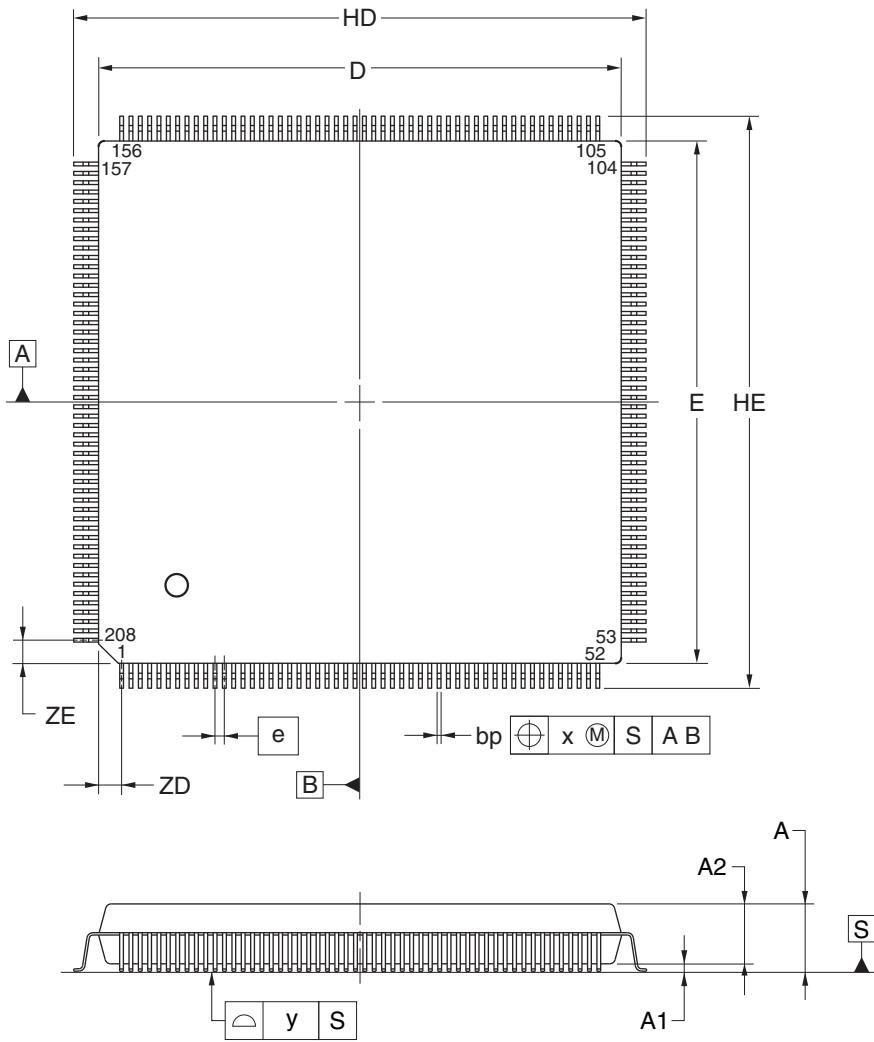

detail of lead end

Reference Symbol	Dimension in Millimeters		
	Min	Nom	Max
D	27.80	28.00	28.20
E	27.80	28.00	28.20
HD	30.40	30.60	30.80
HE	30.40	30.60	30.80
A	—	—	3.80
A1	0.30	0.40	0.50
A2	3.10	3.20	3.30
A3	—	0.25	—
bp	0.18	0.20	0.27
c	0.10	0.125	0.20
L	—	0.50	—
Lp	0.45	0.60	0.75
L1	1.10	1.325	1.50
θ	0°	3°	10°
e	—	0.50	—
x	—	—	0.10
y	—	—	0.10
ZD	—	1.25	—
ZE	—	1.25	—