


240 PIN PLASTIC QFP (FINE PITCH) (32x32)

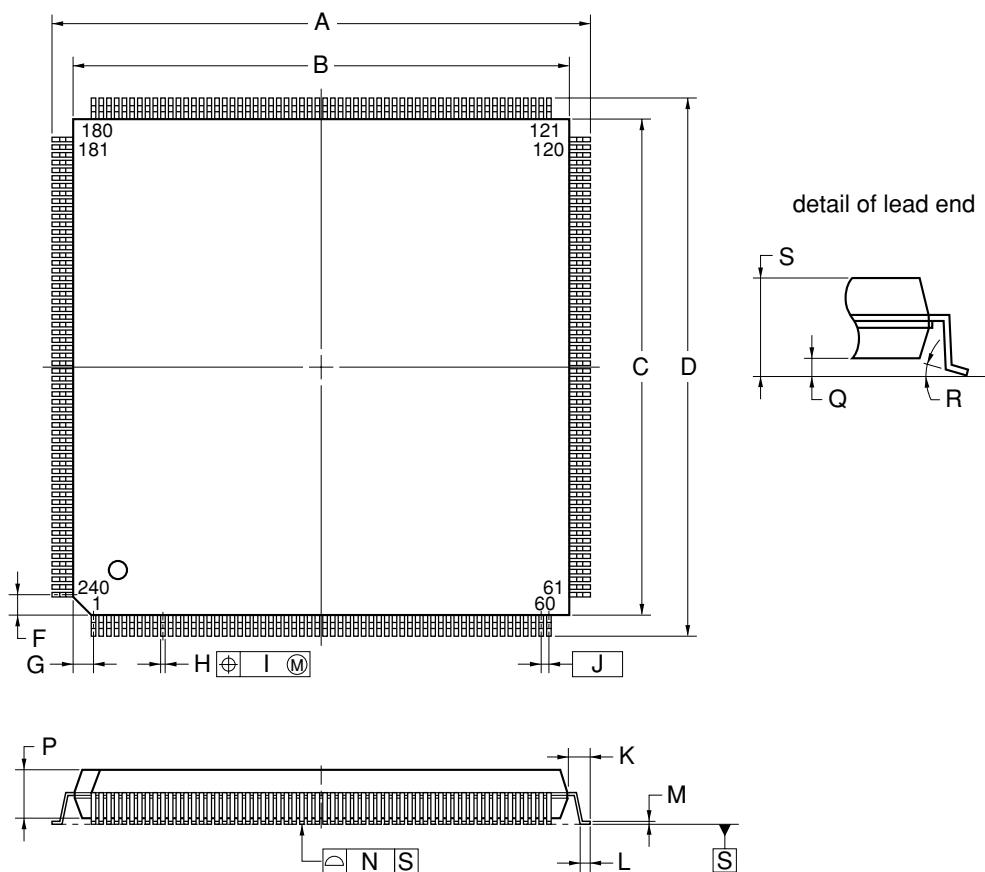

NOTE

Each lead centerline is located within 0.10 mm of its true position (T.P.) at maximum material condition.

ITEM	MILLIMETERS
A	34.6±0.2
B	32.0±0.2
C	32.0±0.2
D	34.6±0.2
F	1.25
G	1.25
H	0.22 ^{+0.05} _{-0.04}
I	0.10
J	0.5 (T.P.)
K	1.3±0.2
L	0.5±0.2
M	0.17 ^{+0.03} _{-0.07}
N	0.10
P	3.2±0.1
Q	0.4±0.1
R	3° ^{+7°} _{-3°}
S	3.8 MAX.

P240GN-50-WMU-1