


JEITA Package Code	RENESAS Code	Previous Code	MASS (TYP.) [g]
P-HFQFP256-28x28-0.40	PRQP0256LB-B	P256GD-40-MMV	5

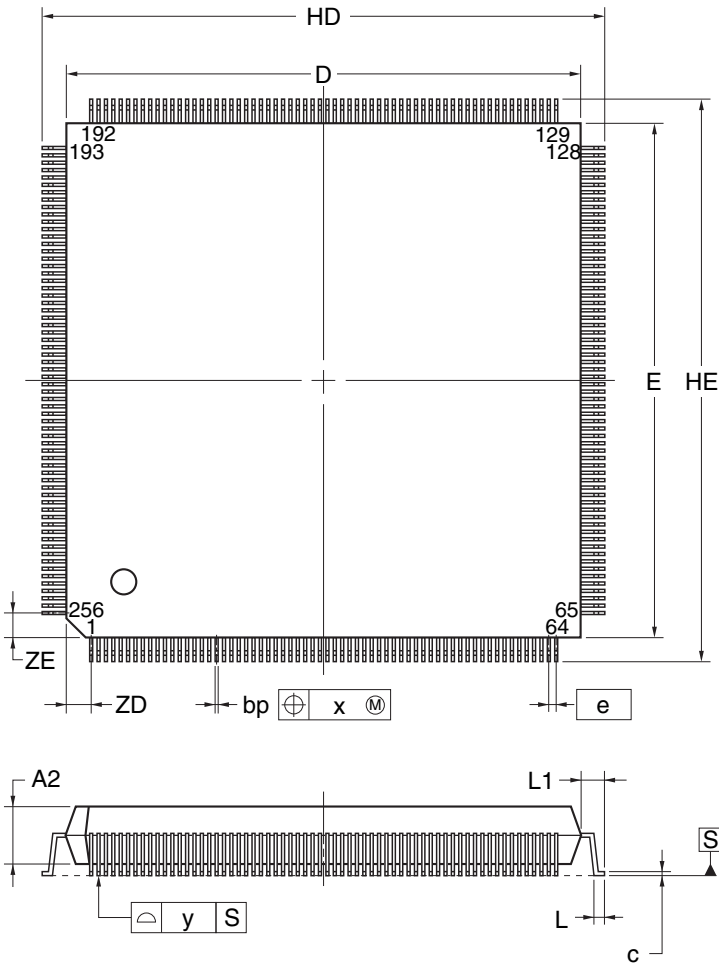

detail of lead end

(UNIT:mm)

ITEM	DIMENSIONS
D	28.00±0.20
E	28.00±0.20
HD	30.60±0.20
HE	30.60±0.20
A	3.80 MAX.
A1	0.40±0.10
A2	3.20
bp	0.18±0.05
c	0.145±0.05
L	0.50 ^{+0.20} _{-0.10}
L1	1.30±0.20
θ	3° ^{+7°} _{-3°}
e	0.40
x	0.09
y	0.08
ZD	1.40
ZE	1.40

NOTE

Each lead centerline is located within 0.09 mm of its true position (T.P.) at maximum material condition.