


外形図 Outline drawing
 Renesasコード PWQN0056KF-A

RDK-G-001786 1/1

ルネサス エレクトロニクス株式会社
 Renesas Electronics Corporation

| | | |
|--------------------|--------------|---------------|
| JEITA Package Code | RENESAS Code | MASS(Typ.)[g] |
| P-HWQFN56-8×8-0.50 | PWQN0056KF-A | 0.16 |

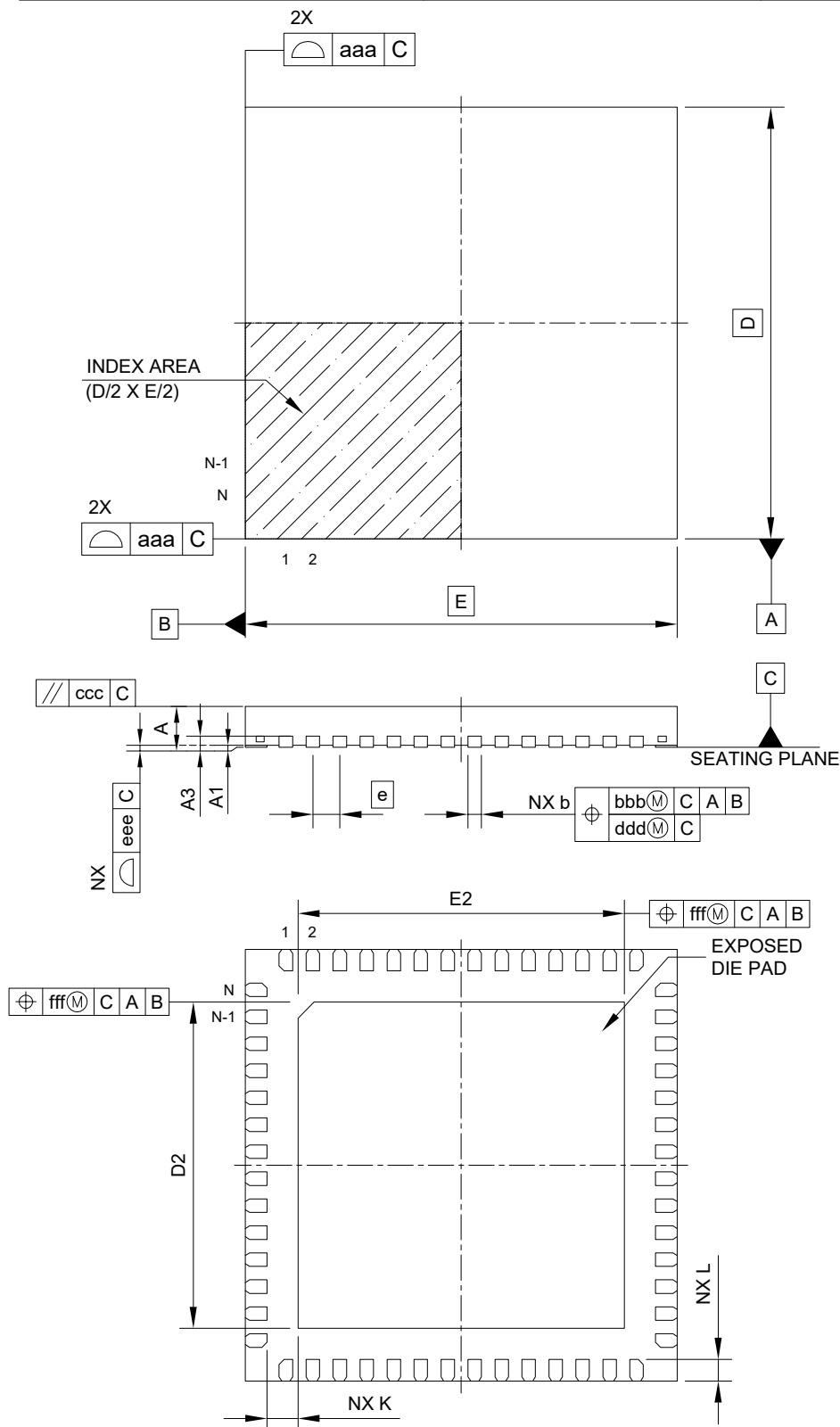

| Reference Symbol | Dimension in Millimeters | | |
|------------------|--------------------------|------|------|
| | Min. | Nom. | Max. |
| A | — | — | 0.80 |
| A ₁ | 0.00 | 0.02 | 0.05 |
| A ₃ | 0.203 REF. | | |
| b | 0.20 | 0.25 | 0.30 |
| D | — | 8.00 | — |
| E | — | 8.00 | — |
| e | — | 0.50 | — |
| N | 56 | | |
| L | 0.35 | 0.40 | 0.45 |
| K | 0.20 | — | — |
| D ₂ | 5.95 | 6.05 | 6.15 |
| E ₂ | 5.95 | 6.05 | 6.15 |
| aaa | 0.15 | | |
| bbb | 0.10 | | |
| ccc | 0.10 | | |
| ddd | 0.05 | | |
| eee | 0.08 | | |
| fff | 0.10 | | |