

外形図 Outline drawing


Renesasコード PLQP0100KN-A

RDK-G-001623

1/1

ルネサスエレクトロニクス株式会社
Renesas Electronics Corporation

JEITA Package code	RENESAS code	MASS(TYP.)[g]
P-LFQFP100-14x14-0.50	PLQP0100KN-A	0.65

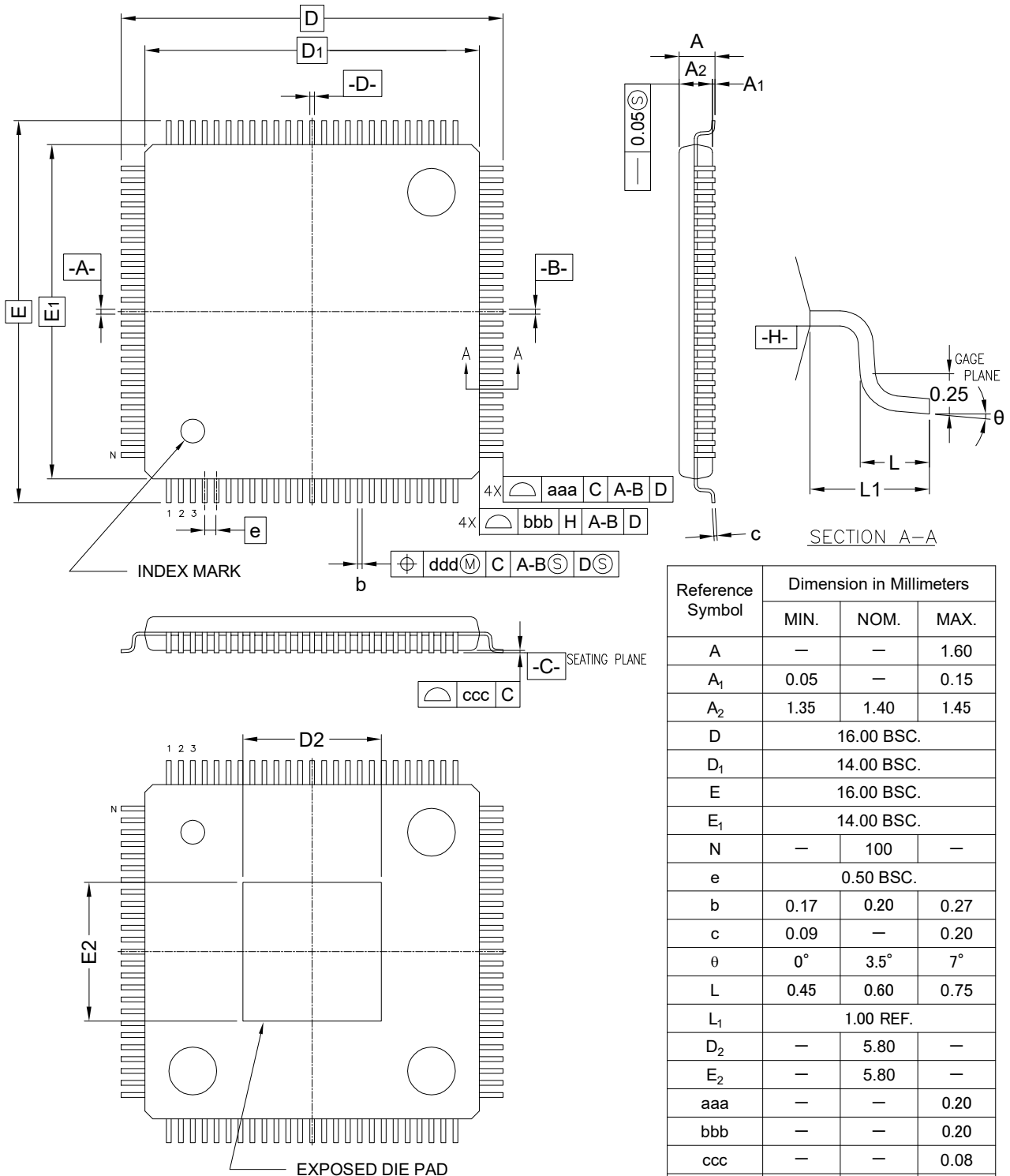

Reference Symbol	Dimension in Millimeters		
	MIN.	NOM.	MAX.
A	—	—	1.60
A ₁	0.05	—	0.15
A ₂	1.35	1.40	1.45
D	16.00 BSC.		
D ₁	14.00 BSC.		
E	16.00 BSC.		
E ₁	14.00 BSC.		
N	—	100	—
e	0.50 BSC.		
b	0.17	0.20	0.27
c	0.09	—	0.20
theta	0°	3.5°	7°
L	0.45	0.60	0.75
L ₁	1.00 REF.		
D ₂	—	5.80	—
E ₂	—	5.80	—
aaa	—	—	0.20
bbb	—	—	0.20
ccc	—	—	0.08
ddd	—	—	0.08