
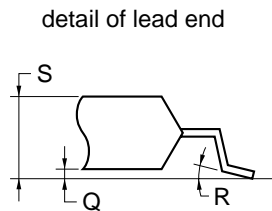


# 44-PIN PLASTIC QFP (10x10)

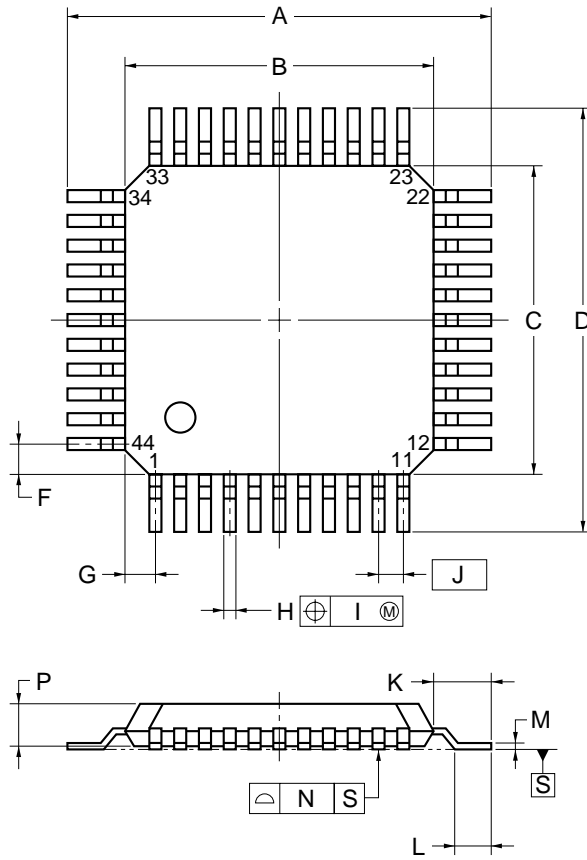

## NOTE

Each lead centerline is located within 0.15 mm of its true position (T.P.) at maximum material condition.

ITEM	MILLIMETERS
A	13.6±0.4
B	10.0±0.2
C	10.0±0.2
D	13.6±0.4
F	1.0
G	1.0
H	0.35±0.10
I	0.15
J	0.8 (T.P.)
K	1.8±0.2
L	0.8±0.2
M	0.17 <sup>+0.08</sup> <sub>-0.07</sub>
N	0.10
P	2.7±0.1
Q	0.22 <sup>+0.08</sup> <sub>-0.12</sub>
R	5°±5°
S	3.1 MAX.

S44GB-80-3S4-1