
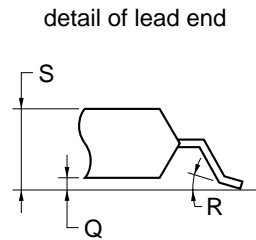


56-PIN PLASTIC QFP (10x10)

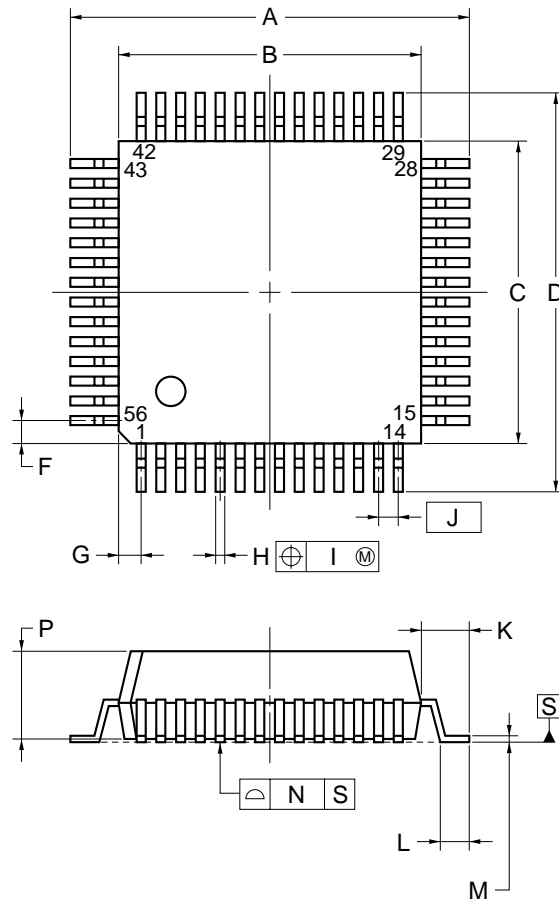

NOTE

Each lead centerline is located within 0.13 mm of its true position (T.P.) at maximum material condition.

ITEM	MILLIMETERS
A	12.8±0.4
B	10.0±0.2
C	10.0±0.2
D	12.8±0.4
F	0.8
G	0.8
H	0.30±0.10
I	0.13
J	0.65 (T.P.)
K	1.4±0.2
L	0.6±0.2
M	0.15 ^{+0.10} _{-0.05}
N	0.10
P	1.7±0.1
Q	0.125±0.075
R	5°±5°
S	2.0 MAX.

S56GB-65-1A7-5