
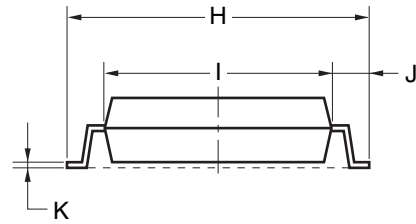
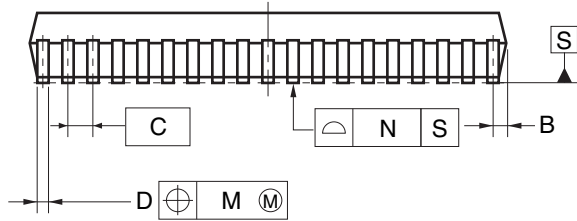
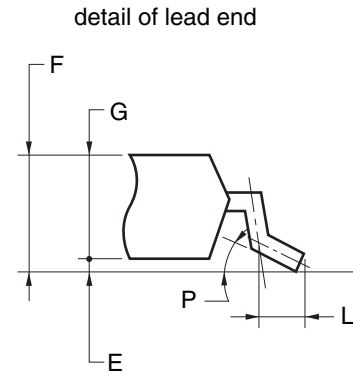


JEITA Package Code	RENESAS Code	Previous Code	MASS (TYP.) [g]
P-SSOP38-0300-0.65	PRSP0038JD-A	P38GS-65-BGG-2	0.29

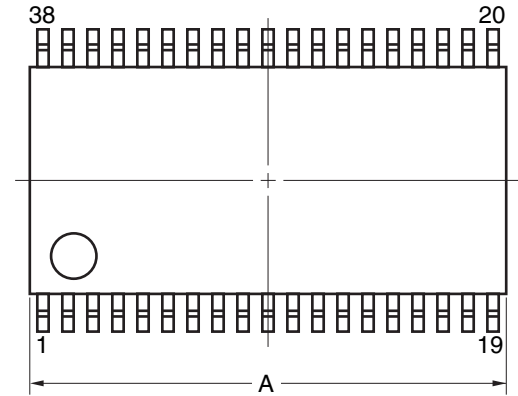

**NOTE**

Each lead centerline is located within 0.10 mm of its true position (T.P.) at maximum material condition.

ITEM	MILLIMETERS
A	12.7±0.3
B	0.65 MAX.
C	0.65 (T.P.)
D	0.37 <sup>+0.05</sup> <sub>-0.1</sub>
E	0.125±0.075
F	1.675±0.125
G	1.55
H	7.7±0.2
I	5.6±0.2
J	1.05±0.2
K	0.2 <sup>+0.1</sup> <sub>-0.05</sub>
L	0.6±0.2
M	0.10
N	0.10
P	3° <sup>+7°</sup> <sub>-3°</sub>