

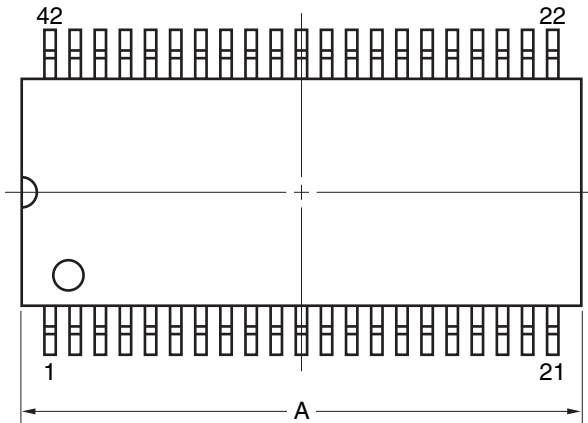


JEITA Package Code	RENESAS Code	Previous Code	MASS (TYP.) [g]
P-SSOP42-0375-0.80	PRSP0042GD-A	S42GT-80-375B-3	0.69

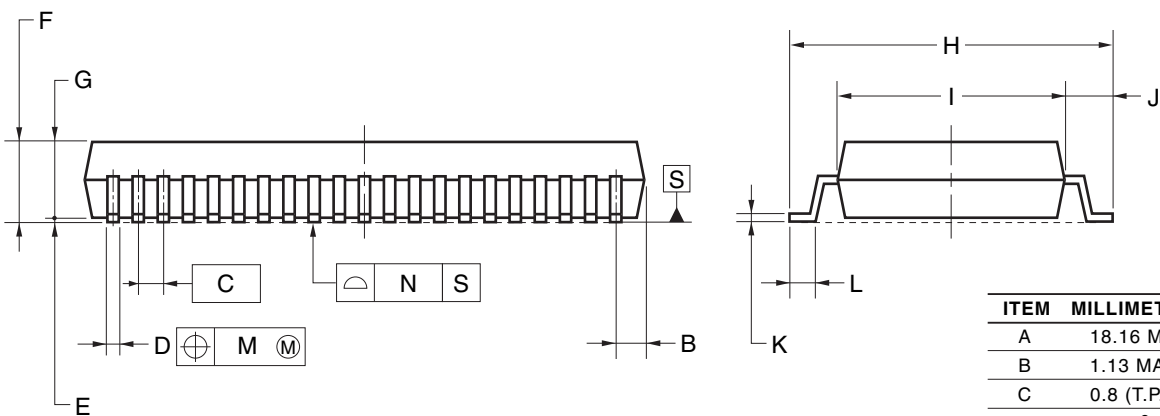

detail of lead end

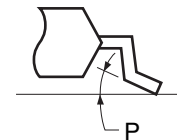

NOTE
Each lead centerline is located within 0.10 mm of its true position (T.P.) at maximum material condition.

ITEM	MILLIMETERS
A	18.16 MAX.
B	1.13 MAX.
C	0.8 (T.P.)
D	$0.35^{+0.10}_{-0.05}$
E	0.125 ± 0.075
F	2.9 MAX.
G	2.5 ± 0.2
H	10.3 ± 0.3
I	7.15 ± 0.2
J	1.6 ± 0.2
K	$0.15^{+0.10}_{-0.05}$
L	0.8 ± 0.2
M	0.10
N	0.10
P	$3^{\circ} \text{ to } 7^{\circ}$