
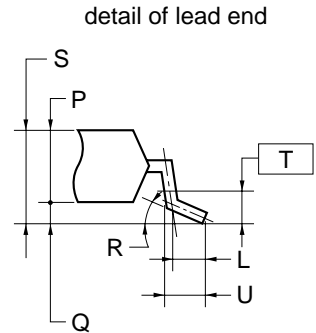


100-PIN PLASTIC TQFP (14x20)

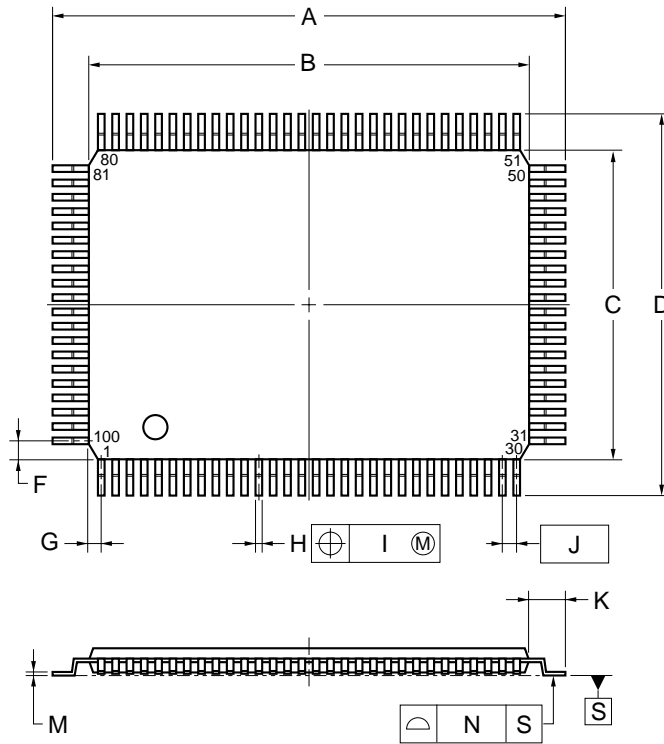

NOTE

Each lead centerline is located within 0.10 mm of its true position (T.P.) at maximum material condition.

ITEM	MILLIMETERS
A	23.2±0.2
B	20.0±0.2
C	14.0±0.2
D	17.2±0.2
F	0.825
G	0.575
H	0.32±0.06
I	0.10
J	0.65(T.P.)
K	1.6±0.15
L	0.8
M	0.17±0.05
N	0.10
P	1.0
Q	0.1±0.05
R	3° ^{+5°} / _{-3°}
S	1.10 ^{+0.10} / _{-0.05}
T	0.25
U	0.88±0.15

S100GF-65-9BT-1