


| | | | |
|--------------------|--------------|---------------|------------|
| JEITA Package Code | RENESAS Code | Previous Code | MASS[Typ.] |
| P-WSON8-3.6x3-0.65 | PWSN0008JA-B | TNP-8DAV | 0.022g |

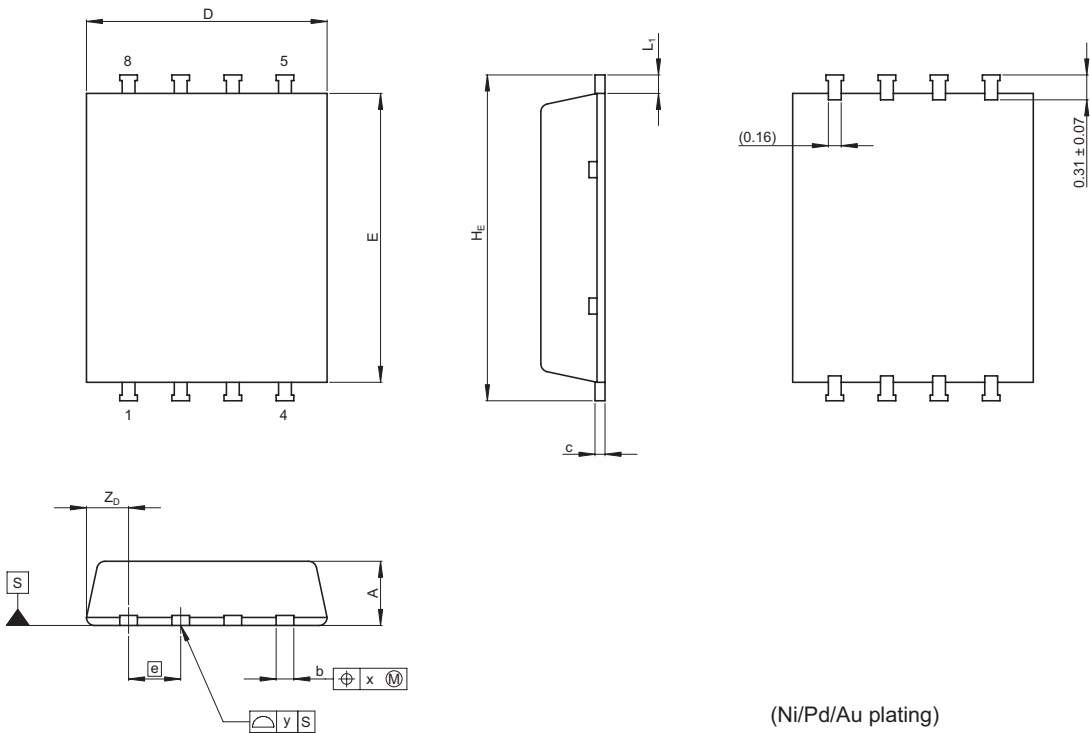

| Reference Symbol | Dimension in Millimeters | | |
|------------------|--------------------------|-------|-------|
| | Min | Nom | Max |
| D | 2.90 | 3.00 | 3.10 |
| E | 3.50 | 3.60 | 3.70 |
| A | — | — | 0.80 |
| A ₁ | — | — | — |
| A ₂ | — | — | — |
| b | 0.15 | 0.22 | 0.30 |
| b ₁ | — | — | — |
| e | — | 0.65 | — |
| L _p | — | — | — |
| x | — | — | 0.08 |
| y | — | — | 0.08 |
| Z _D | — | — | 0.675 |
| c | 0.075 | 0.125 | 0.175 |
| c ₁ | — | — | — |
| H _E | 3.94 | 4.04 | 4.14 |
| L ₁ | 0.14 | 0.22 | 0.30 |

(Ni/Pd/Au plating)