


CUSTOM TRAY

Tray Code	RENESAS Code	Previous Code
PT836B	PRQP0208KE-A	FP-208A / FP-208AV
	PRQP0208KE-B	FP-208E / FP-208EV
	PRQP0256LA-A	FP-256F / FP-256FV
	PRQP0256LA-B	FP-256G / FP-256GV

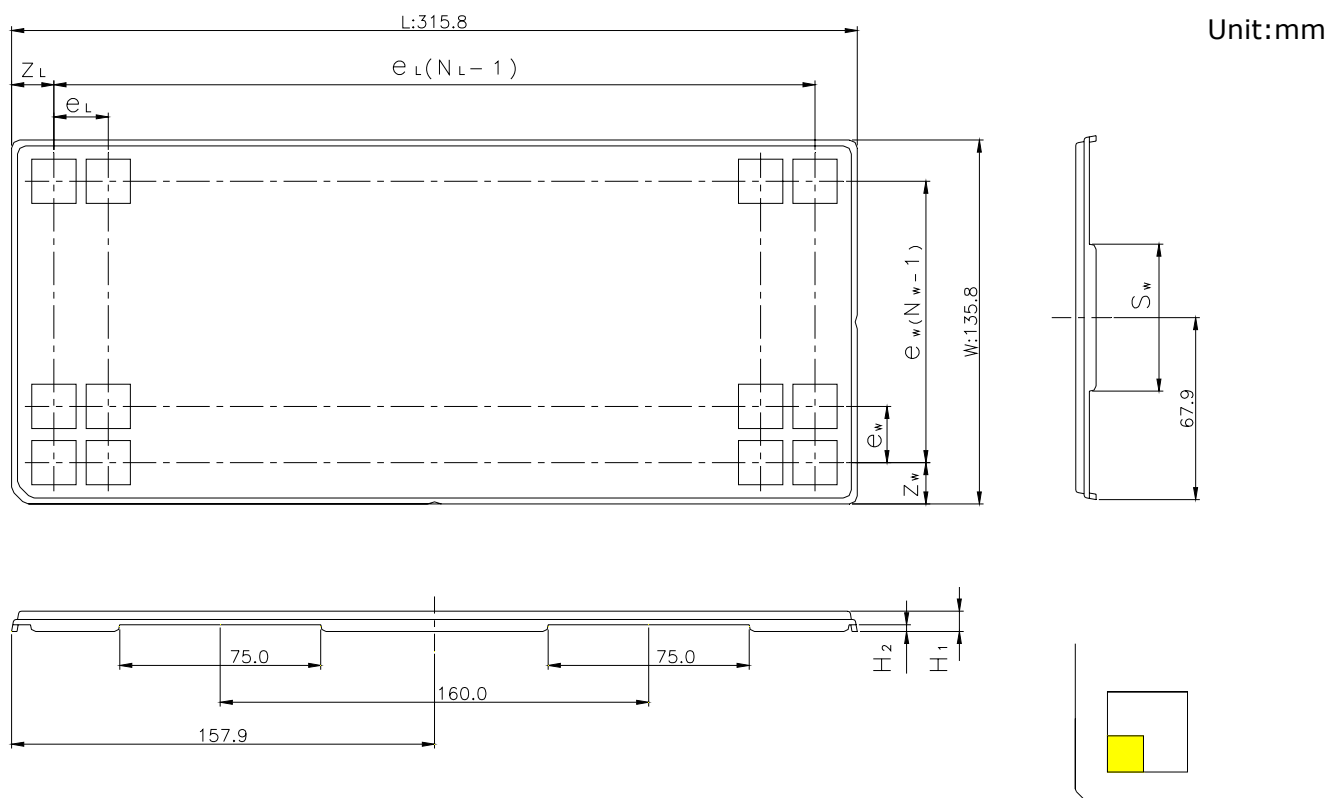

The pin1 is located in the hatching portion

Position dimension of cells (mm)	Z_w	27.1
	Z_L	25.25
	e_w	40.8
	e_L	37.9
	S_w	55
Thickness (mm)	H_1	8.7
	H_2	3
Number of cells	N_w	3
	N_L	8
Maximum storage No. IC/Tray		24
Maximum storage No. IC/Inner box		240
Material		Carbon PPE
Surface resistance		Less than $1 \times 10^{11} \Omega / \square$
Heat resistant temperature		125°C24h
Packing form		Dry pack