
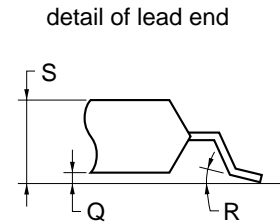


## 74-PIN PLASTIC QFP (20x20)

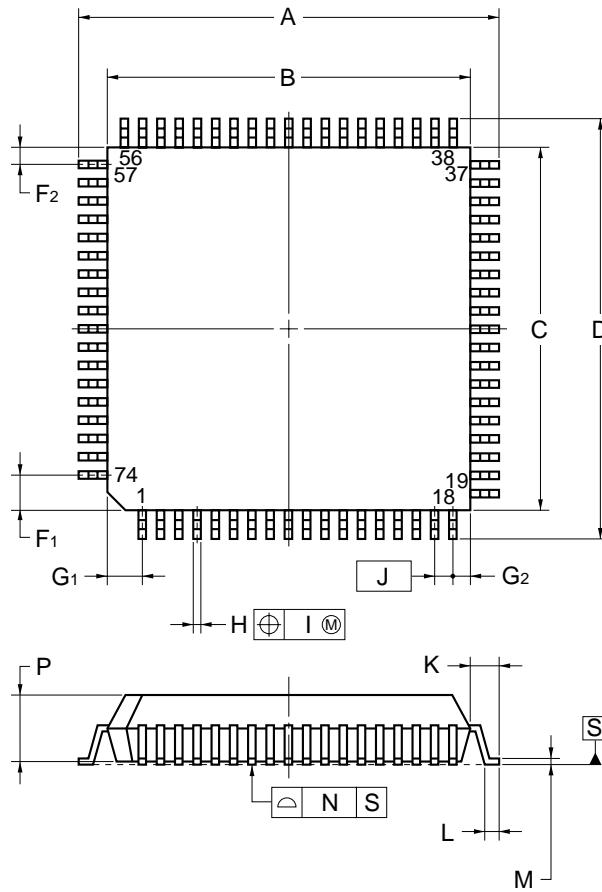

### NOTE

Each lead centerline is located within 0.20 mm of its true position (T.P.) at maximum material condition.

ITEM	MILLIMETERS
A	23.2±0.4
B	20.0±0.2
C	20.0±0.2
D	23.2±0.4
F <sub>1</sub>	2.0
F <sub>2</sub>	1.0
G <sub>1</sub>	2.0
G <sub>2</sub>	1.0
H	0.40±0.10
I	0.20
J	1.0 (T.P.)
K	1.6±0.2
L	0.8±0.2
M	0.15 <sup>+0.10</sup> <sub>-0.05</sub>
N	0.10
P	3.7
Q	0.1±0.1
R	5°±5°
S	4.0 MAX.

S74GJ-100-5BJ-4