
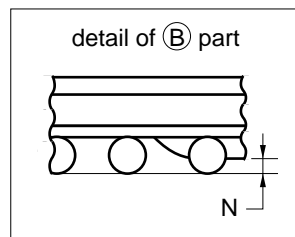
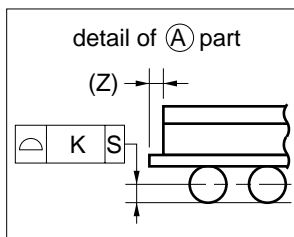
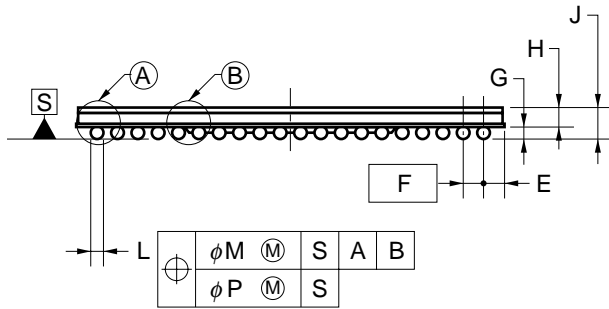


256-PIN TAPE BGA (HEAT SPREADER TYPE) (27x27)

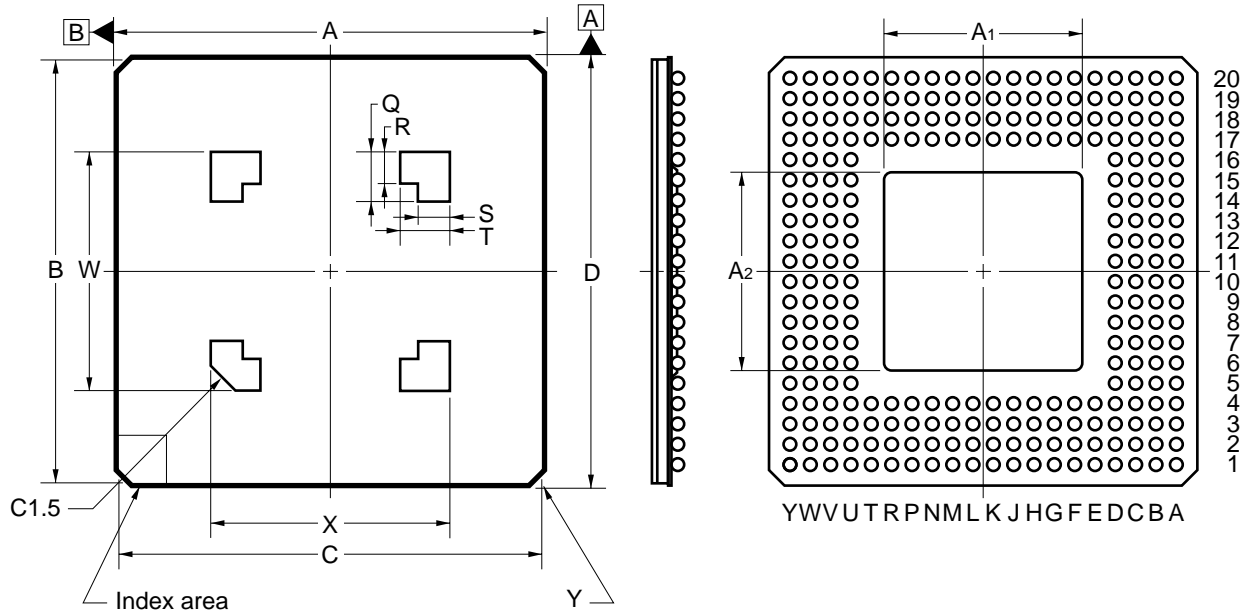

ITEM	MILLIMETERS
A	27.00±0.20
A1	15.50 MAX.
A2	15.50 MAX.
B	26.60±0.15
C	26.60±0.15
D	27.00±0.20
E	1.435
F	1.27 (T.P.)
G	0.60±0.10
H	0.80
J	1.40 ^{+0.30} _{-0.20}
K	0.15
L	φ0.75±0.15
M	0.30
N	0.25MIN.
P	0.10
Q	3.0
R	2.0
S	2.0
T	3.0
W	15.11
X	15.11
Y	C 0.4
Z	0.20

P256N7-127-B6