


CUSTOM TRAY

Tray Code	RENESAS Code	Previous Code
PT308C	PRQP0080GD-A	FP-80 / FP-80V
	PRQP0080GD-B	FP-80B / FP-80BV
	PRQP0100JE-A	FP-100 / FP-100V
	PRQP0100JE-B	FP-100A / FP-100AV
	PRQP0100JG-A	—

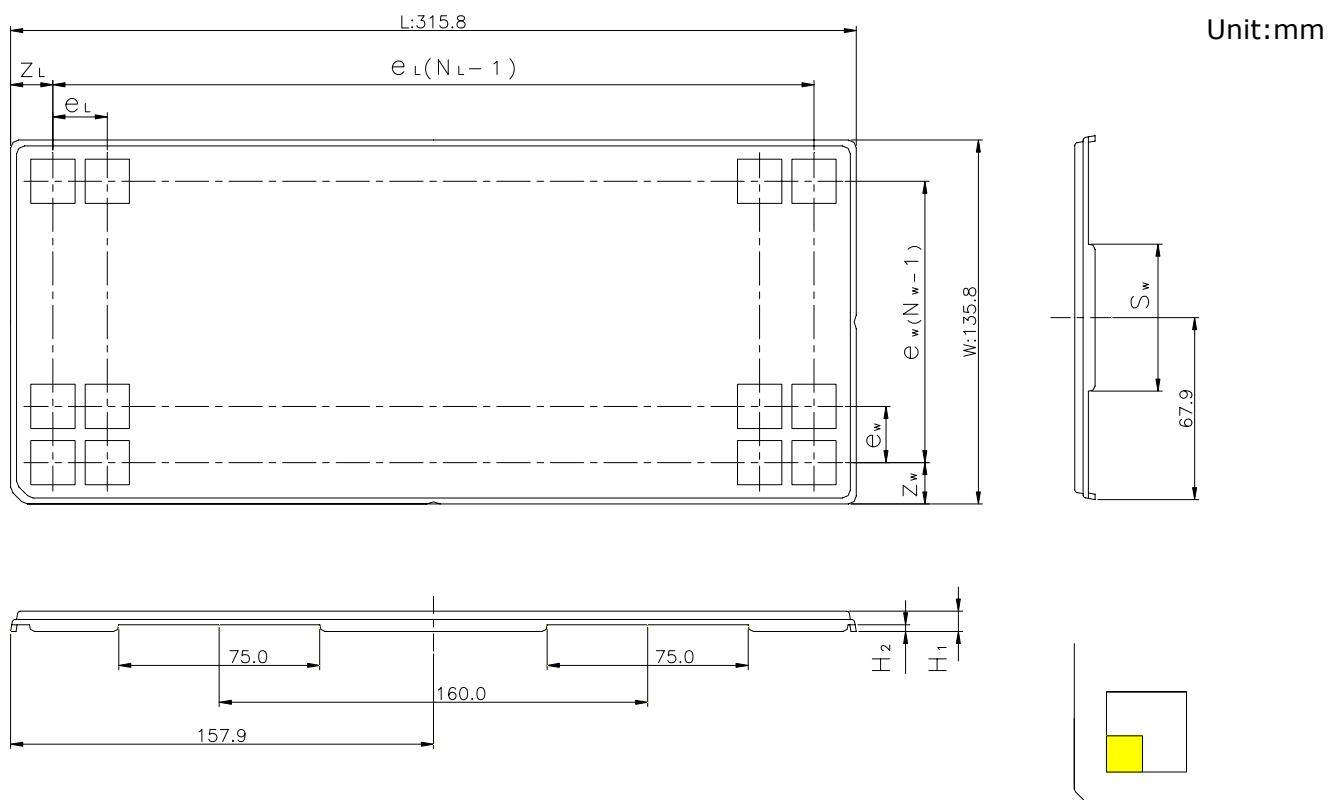

The pin1 is located in the hatching portion

Position dimension of cells (mm)	Z_w	17.9
	Z_L	18.4
	e_w	25
	e_L	31
	S_w	25
Thickness (mm)	H_1	7.6
	H_2	2.5
Number of cells	N_w	5
	N_L	10
Maximum storage No. IC/Tray		50
Maximum storage No. IC/Inner box		500
Material		Carbon PPE
Surface resistance		Less than $1 \times 10^{11} \Omega / \square$
Heat resistant temperature		125°C24h
Packing form		Dry pack