


40-PIN PLASTIC DIP (15.24mm(600))

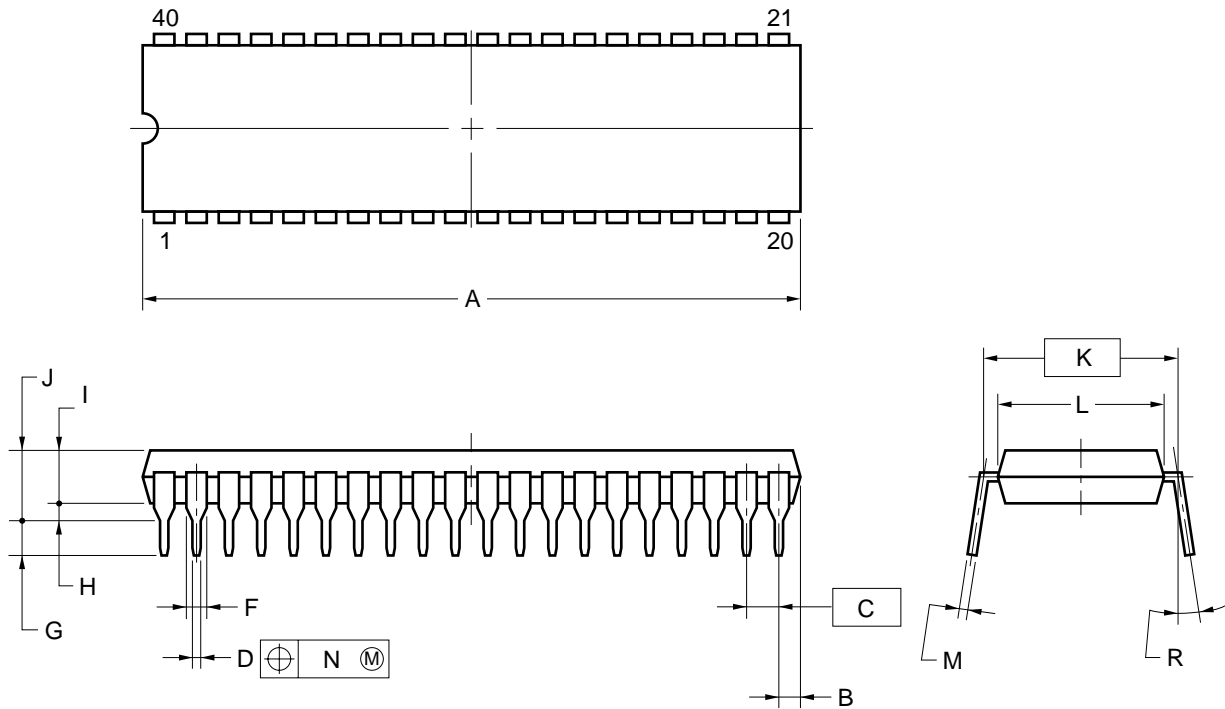

NOTES

- Each lead centerline is located within 0.25 mm of its true position (T.P.) at maximum material condition.
- Item "K" to center of leads when formed parallel.

ITEM	MILLIMETERS
A	53.34 MAX.
B	2.54 MAX.
C	2.54 (T.P.)
D	0.50±0.10
F	1.1 MIN.
G	3.3±0.3
H	0.38 MIN.
I	4.31 MAX.
J	5.72 MAX.
K	15.24 (T.P.)
L	13.72
M	0.25 ^{+0.10} _{-0.05}
N	0.25
R	0-15°

P40C-100-600A1-2