



JEITA Package Code	RENESAS Code	Previous Code	MASS (TYP.) [g]
P-FQFP272-36x36-0.50	PRQP0272KA-A	P272GP-50-LMU	8.8

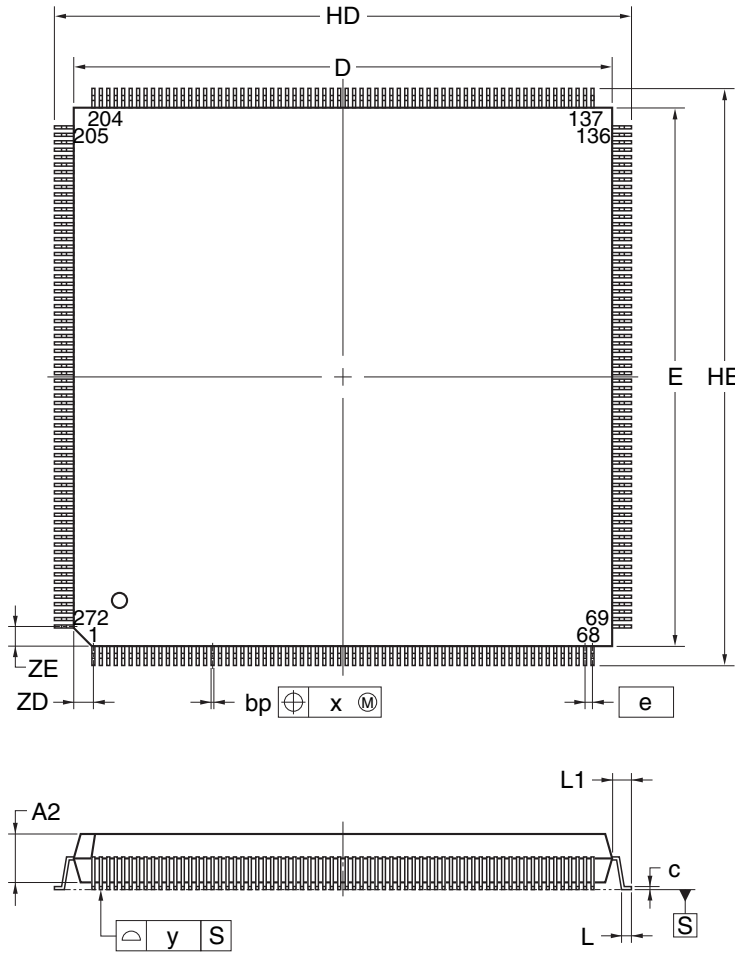

detail of lead end

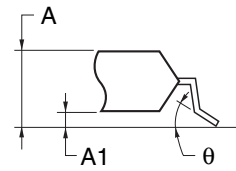

(UNIT:mm)

ITEM	DIMENSIONS
D	36.00±0.20
E	36.00±0.20
HD	38.60±0.20
HE	38.60±0.20
A	3.80 MAX.
A1	0.40±0.10
A2	3.20±0.10
bp	0.22 <sup>+0.05</sup> <sub>-0.04</sub>
c	0.145 <sup>+0.055</sup> <sub>-0.045</sub>
L	0.50±0.20
L1	1.30±0.20
θ	3° <sup>+7°</sup> <sub>-3°</sub>
e	0.50
x	0.10
y	0.10
ZD	1.25
ZE	1.25

**NOTE**

Each lead centerline is located within 0.10 mm of its true position (T.P.) at maximum material condition.