


JEITA Package Code	RENESAS Code	Previous Code	MASS (TYP.) [g]
P-HFQFP272-36x36-0.50	PRQP0272KA-B	P272GP-50-MMU	8.8

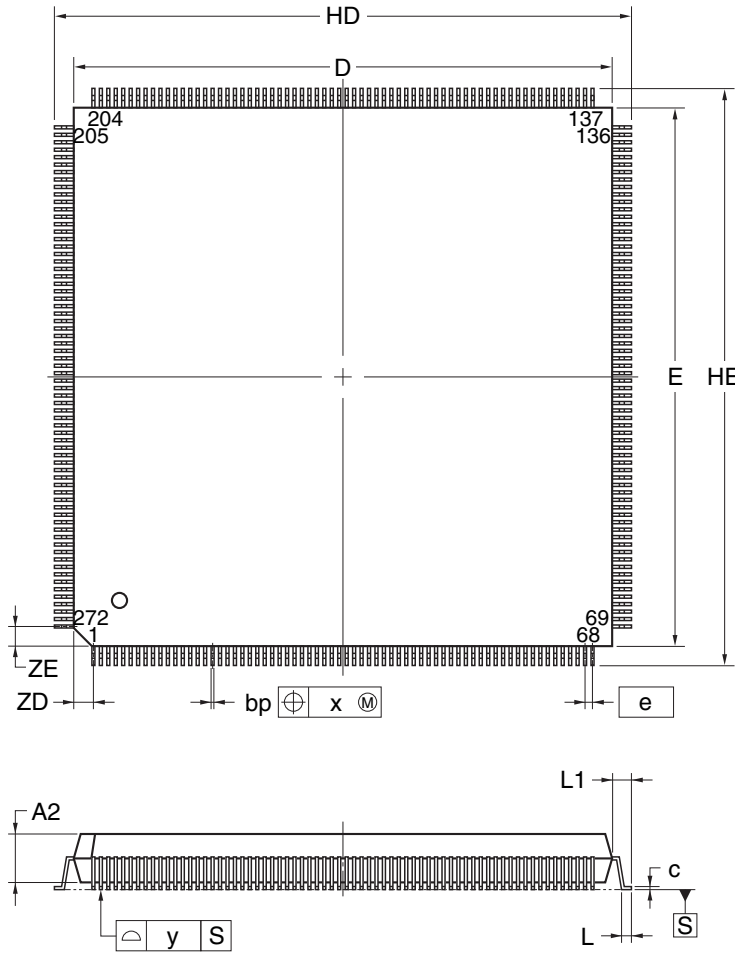

detail of lead end

(UNIT:mm)

ITEM	DIMENSIONS
D	36.00±0.20
E	36.00±0.20
HD	38.60±0.20
HE	38.60±0.20
A	3.80 MAX.
A1	0.40±0.10
A2	3.20±0.10
bp	0.22 ^{+0.05} _{-0.04}
c	0.145 ^{+0.055} _{-0.045}
L	0.50±0.20
L1	1.30±0.20
θ	3° ^{+7°} _{-3°}
e	0.50
x	0.10
y	0.10
ZD	1.25
ZE	1.25

NOTE

Each lead centerline is located within 0.10 mm of its true position (T.P.) at maximum material condition.