


JEITA Package Code	RENESAS Code	Previous Code	MASS (TYP.) [g]
P-HFQFP376-40x40-0.40	PRQP0376LA-B	P376GL-40-MMV	10

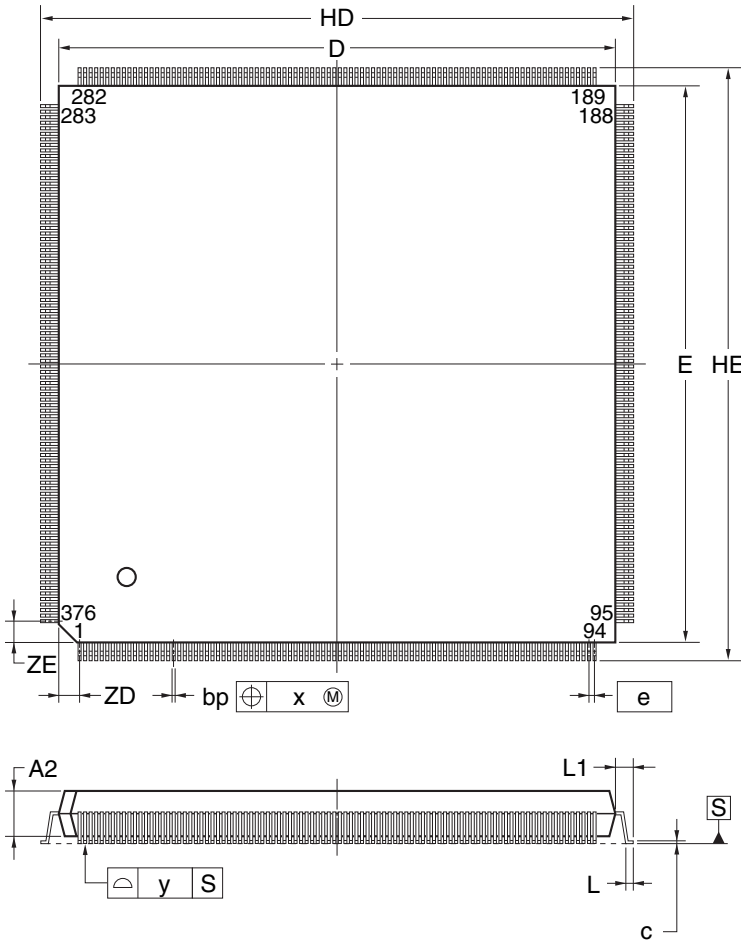

detail of lead end

(UNIT:mm)

ITEM	DIMENSIONS
D	40.00±0.20
E	40.00±0.20
HD	42.60±0.20
HE	42.60±0.20
A	3.80 MAX.
A1	0.40±0.10
A2	3.20
bp	0.18 ^{+0.03} _{-0.06}
c	0.145±0.045
L	0.50±0.20
L1	1.30±0.20
θ	5°±5°
e	0.40
x	0.10
y	0.08
ZD	1.40
ZE	1.40

NOTE

Each lead centerline is located within 0.10 mm of its true position (T.P.) at maximum material condition.