



JEITA Package Code	RENESAS Code	Previous Code	MASS (TYP.) [g]
P-LFQFP100-14x14-0.50	PLQP0100KI-B	P100GC-50-8EU	0.68

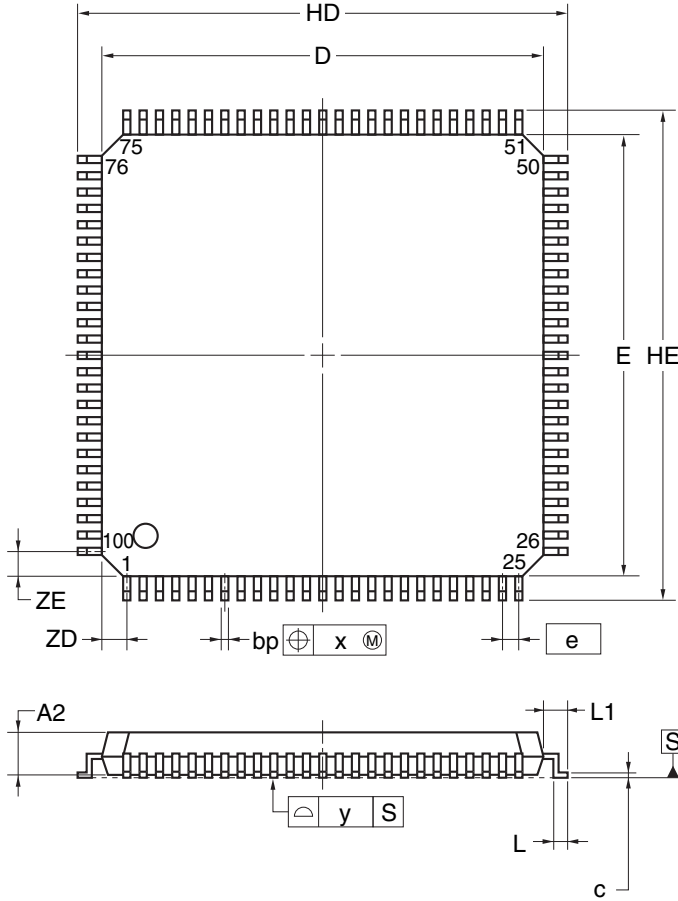

detail of lead end

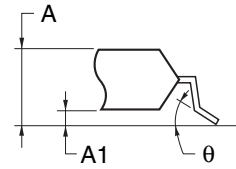

(UNIT:mm)

ITEM	DIMENSIONS
D	14.00±0.20
E	14.00±0.20
HD	16.00±0.20
HE	16.00±0.20
A	1.60 MAX.
A1	0.10±0.05
A2	1.40±0.05
bp	0.22 ^{+0.05} _{-0.04}
c	0.17 ^{+0.03} _{-0.07}
L	0.50±0.20
L1	1.00±0.20
θ	3° ^{+7°} _{-3°}
e	0.50
x	0.08
y	0.08
ZD	1.00
ZE	1.00

NOTE

Each lead centerline is located within 0.08 mm of its true position (T.P.) at maximum material condition.