



56 PIN PLASTIC QFP (□10)

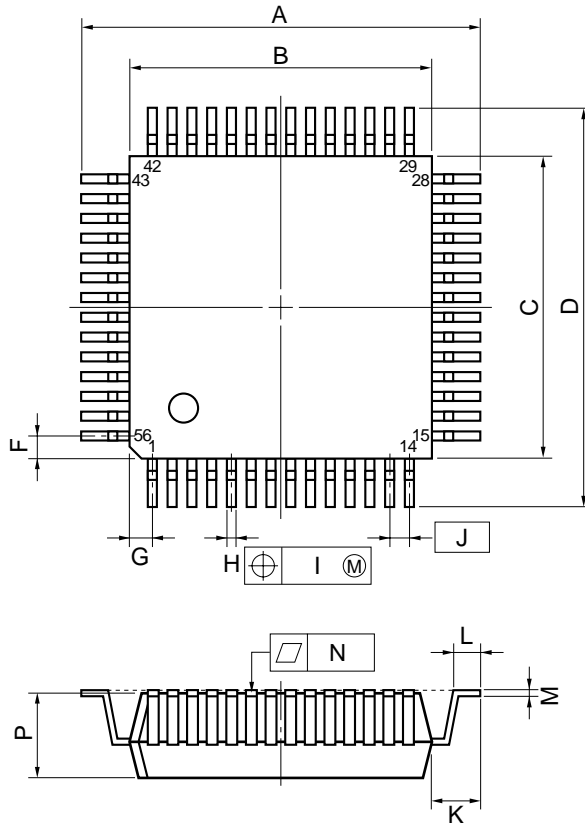

detail of lead end

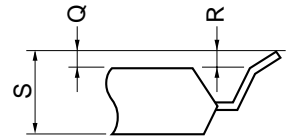

NOTE

Each lead centerline is located within 0.15 mm (0.006 inch) of its true position (T.P.) at maximum material condition.

ITEM	MILLIMETERS	INCHES
A	12.8±0.4	0.504±0.016
B	10.0±0.2	0.394±0.008
C	10.0±0.2	0.394±0.008
D	12.8±0.4	0.504±0.016
F	0.8	0.031
G	0.8	0.031
H	0.30±0.10	0.012±0.004
I	0.15	0.006
J	0.65 (T.P.)	0.026 (T.P.)
K	1.4±0.2	0.055±0.008
L	0.6±0.2	0.024 ^{+0.008} _{-0.009}
M	0.15 ^{+0.10} _{-0.05}	0.006 ^{+0.004} _{-0.003}
N	0.15	0.006
P	1.7	0.067
Q	0.1±0.1	0.004±0.004
R	0.1±0.1	0.004±0.004
S	2.0 MAX.	0.079 MAX.