
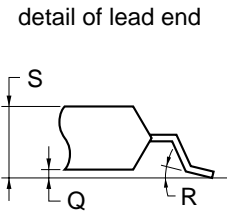


80-PIN PLASTIC QFP (THREE DIRECTIONS) (14x20)

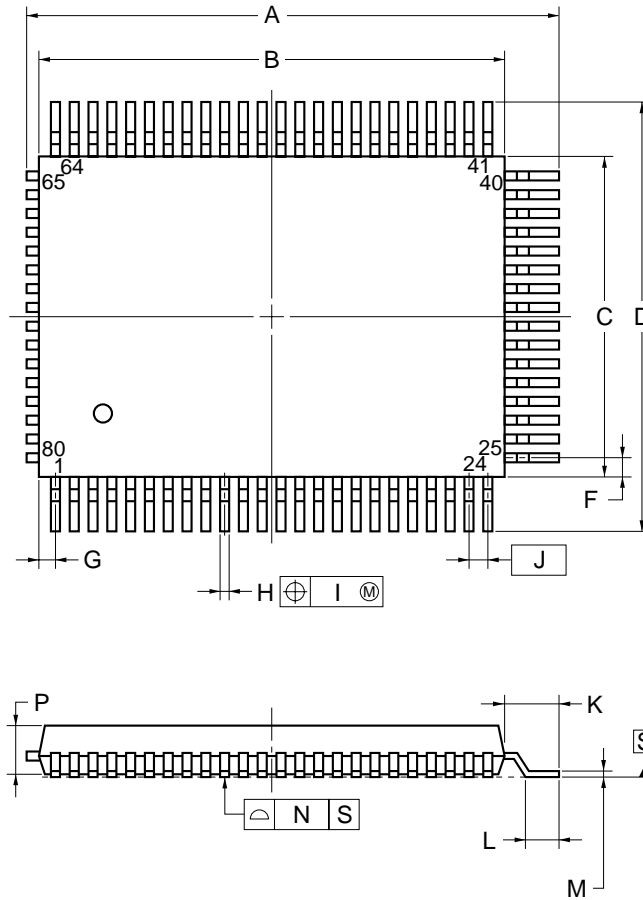

NOTE

Each lead centerline is located within 0.15 mm of its true position (T.P.) at maximum material condition.

ITEM	MILLIMETERS
A	22.3±0.4
B	20.0±0.2
C	14.0±0.2
D	17.6±0.4
F	1.0
G	0.8
H	0.35±0.10
I	0.15
J	0.8 (T.P.)
K	1.8±0.2
L	0.8±0.2
M	0.15 ^{+0.10} _{-0.05}
N	0.10
P	2.7
Q	0.1±0.1
R	5°±5°
S	3.0 MAX.

P80GF-80-3L9-3